


LED SL-RGBW 140 S-PUd-M8-65

Art. Nr. 1-000000-07379

Ktl. Nr. 15071063

EAN Nr. 4260654164497

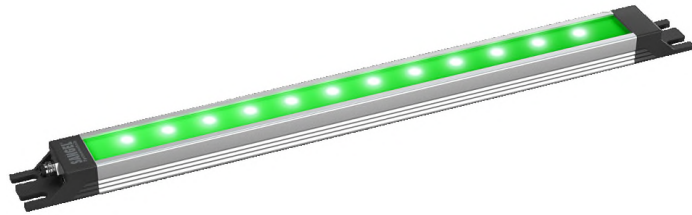

Normen / Norms

DIN EN 60598-1 :2021/A11:2022

DIN EN 60529 :1991/A2:2013/AC:2019-02

DIN EN 55015:2019+A11:2020

DIN EN IEC 63000:2018

DIN EN 61547:2009

DIN EN 62471:2009




Elektrische Rahmenbedingungen / Electrical characteristic

Netzanschluss / Main Supply	24 VDC
Leistung / Power (W/R/G/B)	4,3W / 2W / 2W / 1,9W
Dimmbar / Dimmable	extern PWM
Anschluss / Connection Type	Flansch, M8, 5-Pol, B-Codiert
Kaskadierbar / Cascadable	Nein
Polbild	


Licht / Light

Bestückt / Fitted With	LED
Lichtfarbe / Light Colour	6500 K
Lichtstrom / Luminous Flux (W/R/G/B)	224lm / 33lm / 85lm / 19lm
Effizienz / Efficiency	35 lm/W
Abstrahlwinkel / Beam Angle	100°
Farbtreue / Colour Rendering	RA / CRI 80
Photobiological Safety	RG-1

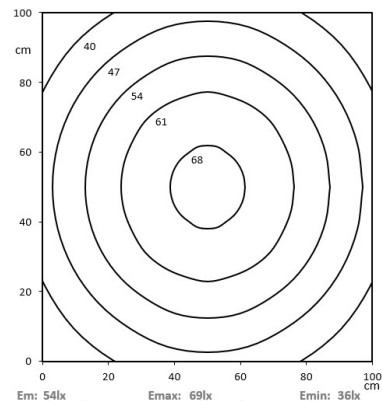

Mechanik / Mechanics

Gehäuse / Housing	Aluminium
Abdeckung / Cover	PU, Diffus
Befestigung / Fastening	Starr
Gewicht(Netto) / Weight(Net)	0,15 kg
Betriebstemperatur / Operating Temp.	-20°C / +50°C
Lebensdauer / Lifetime	min. 60000 h
Zubehör / Equipment	-

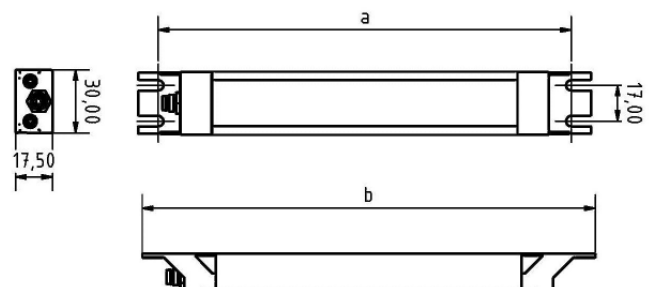

a= 203mm b= 215mm