


LED SL-RGBW 1400 S-PUd-M8-65

Art. Nr. 1-000000-07060

Ktl. Nr. 15071027

EAN Nr. 4260654164053

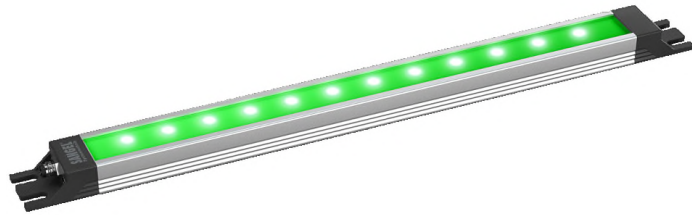

Normen / Norms

DIN EN 60598-1 :2021/A11:2022

DIN EN 60529 :1991/A2:2013/AC:2019-02

DIN EN 55015:2019+A11:2020

DIN EN IEC 63000:2018

DIN EN 61547:2009

DIN EN 62471:2009




Elektrische Rahmenbedingungen / Electrical characteristic

Netzanschluss / Main Supply	24 VDC
Leistung / Power (W/R/G/B)	43,1W / 20,1W / 19,7W / 19,2W
Dimmbar / Dimmable	extern PWM
Anschluss / Connection Type	Flansch, M8, 5-Pol, B-Codiert
Kaskadierbar / Cascadable	Nein
Polbild	


Licht / Light

Bestückt / Fitted With	LED
Lichtfarbe / Light Colour	6500 K
Lichtstrom / Luminous Flux (W/R/G/B)	2238lm / 327lm / 847lm / 192lm
Effizienz / Efficiency	35 lm/W
Abstrahlwinkel / Beam Angle	100°
Farbtreue / Colour Rendering	RA / CRI 80
Photobiological Safety	RG-1

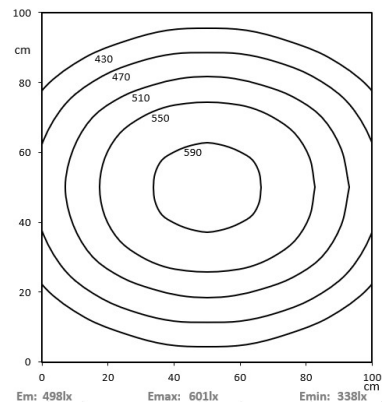

Mechanik / Mechanics

Gehäuse / Housing	Aluminium
Abdeckung / Cover	PU, Diffus
Befestigung / Fastening	Starr
Gewicht(Netto) / Weight(Net)	1,29 kg
Betriebstemperatur / Operating Temp.	-20°C / +50°C
Lebensdauer / Lifetime	min. 60000 h
Zubehör / Equipment	-

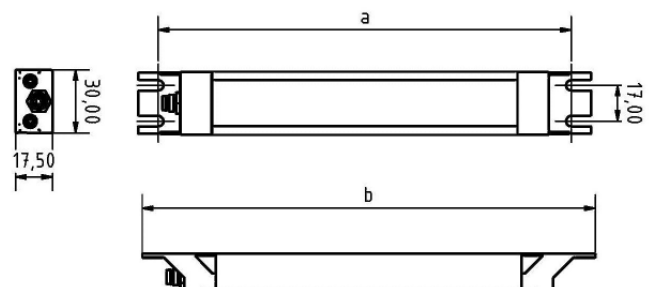

a= 1463mm b= 1475mm

*Technische Änderungen vorbehalten | technical modifications reserved

rev.17.12.2024