

LED LR40-RGBW 610 ESGd-M12d-57

Art. Nr. 1-000000-06976

Ktl. Nr. 15071008

EAN Nr. 4260654163797

Normen / Norms

DIN EN 60598-1 :2021/A11:2022


DIN EN 60529 :1991/A2:2013/AC:2019-02

DIN EN 55015:2019+A11:2020

DIN EN IEC 63000:2018

DIN EN 61547:2009

DIN EN 62471:2009

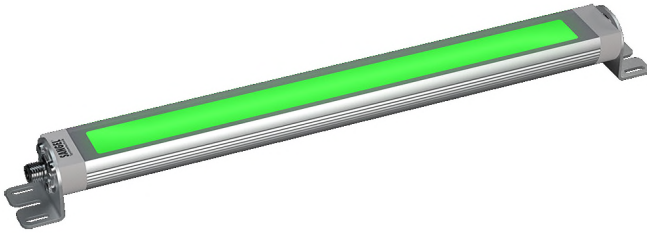


Elektrische Rahmenbedingungen / Electrical characteristic

Netzanschluss / Main Supply	24 VDC
Leistung / Power (W/R/G/B)	11,5W / 6,2W / 5,2W / 5,2W
Dimmbar / Dimmable	extern PWM
Anschluss / Connection Type	Flansch, M12, 5-Pol, A-Codiert
Kaskadierbar / Cascadable	Ja
Polbild	


Licht / Light

Bestückt / Fitted With	LED
Lichtfarbe / Light Colour	5700 K
Lichtstrom / Luminous Flux (W/R/G/B)	1178lm / 175lm / 430lm / 120lm
Effizienz / Efficiency	67 lm/W
Abstrahlwinkel / Beam Angle	100°
Farbtreue / Colour Rendering	RA / CRI 80
Photobiological Safety	RG-1

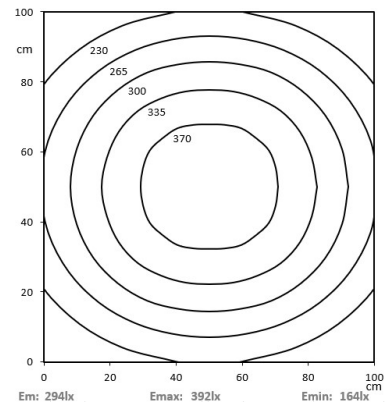

Mechanik / Mechanics

Gehäuse / Housing	Aluminium
Abdeckung / Cover	ESG, Diffus
Befestigung / Fastening	Drehbar
Gewicht(Netto) / Weight(Net)	0,82 kg
Betriebstemperatur / Operating Temp.	-20°C / +50°C
Lebensdauer / Lifetime	min. 60000 h
Zubehör / Equipment	Winkel inkl.

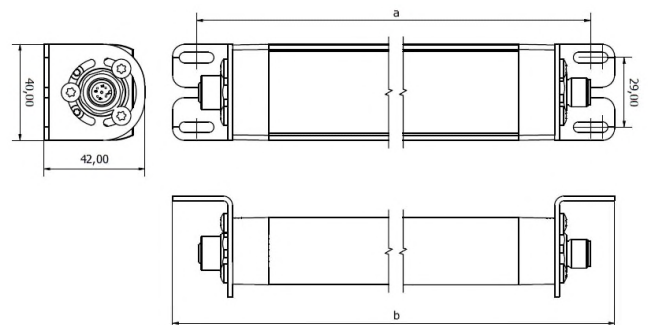

a= 640mm b= 660mm