

Technical specification/




Technische Daten:

Working voltage/ <i>Betriebsspannung:</i>	60 V AC/DC
Insulation resistance/ <i>Isolationswiderstand:</i>	min. 3000 MOhm
Dielectric withstanding voltage/ <i>Spannungsfestigkeit:</i>	1000 V AC / minute
Operating temperature/ <i>Betriebstemperatur:</i>	- 55 °C ... + 105 °C
Current rating/ <i>Strombelastbarkeit:</i>	3 A
Contact Resistance/ <i>Durchgangswiderstand:</i>	max. 15 mOhm

Materials/

Werkstoffe:

Contact/ <i>Kontakt:</i>	Cu alloy, Underplate/ 50 µin Nickel <i>Beschichtung:</i>
	Contact area/ <i>Kontaktbereich:</i> Gold flash
	Solder tails area/ <i>Lötbereich:</i> Gold flash
Shell/ <i>Gehäuse:</i>	Steel, Nickel plated
Rivet, Boardlock/ <i>Befestigungsniet:</i>	Copper alloy
Insulator/ <i>Isolierkörper:</i>	Thermal plastic UL 94 V-0

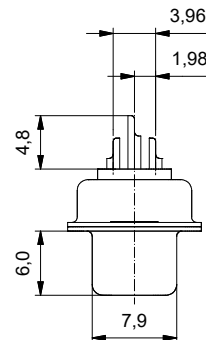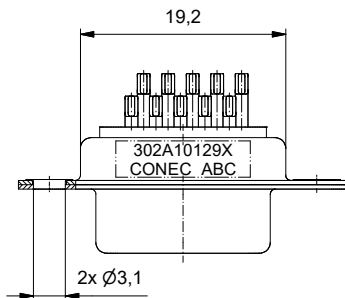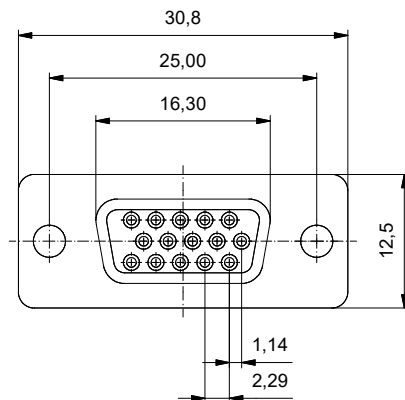

Part no. / Part marked/
Art.-Nr. / Bedruckung:

302A10129X

		 dim. in mm	D-SUB HD Female 15pos. solder cup stamped contacts	
general tolerance/ <i>Allgemeintoleranz:</i>			Date/Datum	Name
0, ±0,5 ,0 ±0,3 ,00 ±0,2			04.07.2022	Bub
Index: a Original			appd./ gepr.	Lehmenkühler
RoHS compliant/ <i>konform</i>		Scale/ Maßstab: 2:1	dwg no / Z.-nr.: 16K1A782	
			DIN-A3	
			1 / 1	