


01 产品介绍

使用产品前请仔细阅读本说明书，并妥善保管。
感谢使用小猴手电筒Lite。

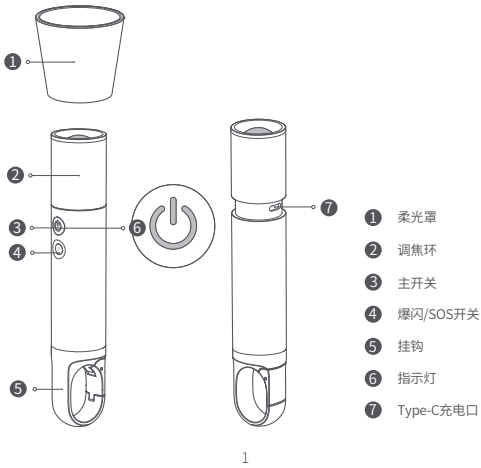

02 使用说明

调焦

- 上下推动调焦环可以实现聚光和泛光效果。

主开关

- 日常使用状态：短按开启，默认低亮挡，再次短按调为中亮挡，再短按为高亮挡，再次短按关机，以此循环。
- 充电时：短按开启低亮挡；再次短按关机；以此循环。

爆闪/SOS开关

- 短按开启爆闪模式；再短按切换为SOS模式；再短按关机；以此循环。
- 爆闪模式：在此模式下，可通过高频率爆闪强光刺激，对威胁者造成视线干扰，进行防卫。
- SOS模式：在此模式下，手电筒自动通过三短、三长、三短的规律灯光闪烁，向外界发送求救信号。

指示灯状态


运行状态

- 电量60%以上：显示绿灯。
- 电量在30%-60%之间：显示橙灯。
- 电量在10%-30%中间：显示红灯。
- 电量低于10%：红灯闪烁。（注意，红灯闪烁一段时间后，手电筒主灯会闪烁，约2分钟后强制关机，请及时充电）

充电状态

- 充电中：红灯呼吸。
- 充满后：绿灯常亮。

备注：本产品配一根充电线，Type-C 充电口。

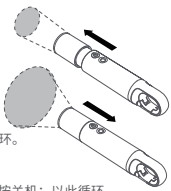

⚠ 03 安全警告

安全事项

- 合理使用** 请按本文档的描述正常使用设备。
- 维修服务** 本产品不可拆解，只有本公司授权的维修人员可以对产品进行维修，请勿自行维修，避免安全伤害。
- 充电须知**
 - 仅可使用满足本设备充电参数的充电器进行充电；
 - 长时间未使用，再次充电时如果状态指示灯不正常显示，请持续充电30分钟后再观察。
- 使用需知**
 - 本产品可发射强光，请避免光线直射人、动物眼睛及光学设备镜头；
 - 为了减少受伤的危险，儿童请在家长陪同下使用；
 - 为减少电击的风险，请勿将设备放在水中或其他液体中；
 - 请勿将设备放置或存放在可能掉落浴缸或水槽的地方；
 - 爆闪模式长时间开启后，调焦环可能产生高温，为减少烫伤危险，请勿触摸。

警告

- 请使用满足本设备充电参数的充电器进行充电，其他类型的充电器和配件，可能违反产品保修条款，并可能导致危险。
- 高亮模式开启15分钟后，温度会升高20°C左右，对温度敏感的用户请做好隔热。（25分钟后，温度会慢慢降低）。
- 本产品检测电池达到45°C后，会触发充电保护功能，停止充电。建议充电环境温度为0°C-30°C。
- 此灯具的光源是不可替换的；当光源到其寿终时，应替换整个灯具。

一般故障及排除方法

故障	原因	排除方法
按主开关或爆闪/SOS开关，红灯闪烁	锂电池电量低	充电
按主开关或爆闪/SOS开关，手电筒不亮	锂电池电量耗尽	充电
电池充电时主开关上指示灯不亮	充电线未插好，或未使用规定的充电线	使用规定充电线，电源适配器需使用5V，检查指示灯是否亮起

04 产品参数

产品型号: QWSDT001	电池类型: 锂离子电池
产品尺寸: 164.5x 30 x 30mm	电池容量: 2600mAh
产品净重: 约160g	额定电压: 3.7V ==
输入参数: 5V==1A	充电时间: 约210min
执行标准: Q/310107QW002-2021	

主开关三挡参数

	高亮挡	中亮挡	低亮挡
亮度	1000LM	350LM	50LM
续航时间	2H	3.5H	24H

05 产品中有害物质的名称及含量

部件名称	有害物质					
	铅 (Pb)	汞 (Hg)	镉 (Cd)	六价铬 (Cr(VI))	多溴联苯 (PBB)	多溴二苯醚 (PBDE)
挂钩	○	○	○	○	○	○
内部金属部分	○	○	○	○	○	○
内部非金属部分	○	○	○	○	○	○
电路板	×	○	○	○	○	○
锂电池	○	○	○	○	○	○
充电线	○	○	○	○	○	○
其他部件	○	○	○	○	○	○

本表格依据 SJ/T 11364-2014 的规定编制。

○：表示该有害物质在该部件所有均质材料中的含量均在 GB/T 26572-2011 规定的限量要求以下。

×：表示该有害物质至少在该部件的某一均质材料中的含量超出 GB/T 26572-2011 规定的限量要求。

因生产工艺和技术等原因产品中以上列举部件某些有害物质超限制要求，但都在欧盟有害物质管控豁免之列，请放心使用。



06 保修说明

保修条例

小猴手电筒Lite产品售后服务严格依据《中华人民共和国消费者权益保护法》、《中华人民共和国产品质量法》实行售后三包服务，服务内容如下：

- 自您签收次日起7日内，本产品出现《小猴手电筒Lite产品性能故障表》所列性能故障的情况，经由器外售后服务中心检测确定，可免费享受退货或换货服务。
- 自您签收次日起8日-15日内，本产品出现《小猴手电筒Lite产品性能故障表》所列性能故障的情况，经由器外售后服务中心检测确定，可免费享受换货或者维修服务。
- 自您签收次日起12个月内，本产品出现《小猴手电筒Lite产品性能故障表》所列性能故障的情况，经由器外售后服务中心检测确定，可免费享受维修服务。

小猴手电筒Lite产品性能故障表

名称	故障
小猴手电筒Lite	1. 无法正常充电
	2. 充电时，指示灯不亮
	3. 开关无法使用

非保修条例

- 未经授权的维修、误用、碰撞、疏忽、滥用、进液、事故、改动、不正确的使用非本产品配件，或撕毁、涂改标贴、防伪标记。
- 已超过三包有效期。
- 因不可抗力造成的损坏。
- 不符合《小猴手电筒Lite产品性能故障表》所列性能故障的情况。
- 因人为原因导致本产品及其配件产生《小猴手电筒Lite产品性能故障表》所列性能故障。

提示

- 因运输过程中需使用包装箱保证产品运输安全，建议您自签收之日起至少保留包装箱30天。
- 本产品仅限中国地区（不含港澳台地区）销售，故本产品仅在中国地区（不含港澳台地区）提供售后服务，本保修条例仅适用于中国地区（不含港澳台地区）。


服务热线：400-021-8696

制 造 商：上海器外文化科技有限公司

地 址：上海市普陀区莫干山路50号45幢

01 Product Overview

Read this manual carefully before use, and retain it for future reference.
Thank you for using HOTO flashlight Lite

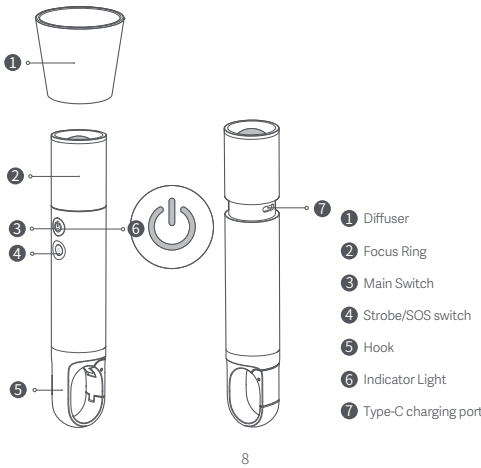

02 How to Use

Focusing

- Push the focus ring up and down to achieve the effect of focusing and flooding.

Main Switch

- Daily use: short press to turn it on (low light mode by default). Short press again to adjust to medium light mode; again to high light mode; and again to shut it down. Repeat the operation.
- During charging: Short press to turn it on to low light mode; short press again to shut it down. Repeat the operation.


Strobe/SOS switch

- Short press to turn on the strobe mode; short press again to switch to SOS mode; short press again to shut down; Repeat the operation.
- The strobe mode: in this mode, high-frequency flashing and strong light stimulation can be used to disturb the line of sight of any potential perpetrators for defense.
- SOS mode: in this mode, the flashlight automatically flashes with three dits, three dats, and three dits to signal for help to the outside world.

Indicator status

Operating status

- Battery is above 60%: green light is on.
- Battery is between 30%-60%: orange light is on.
- Battery is between 10%-30%: red light is on.
- Battery is less than 10%: red light flashes. (Attention: After the red light flashes for a while, the main lamp of the flashlight will flash and be forced to turned off in about 2 minutes. In that case, please charge the device.)

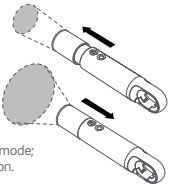

Charging status

- Charging: red light breathes;
- Fully charged: green light is on.

This flashlight is equipped with a Type-C charging port, and a USB charging cable is included.

⚠ 03 General Power Tool Safety Warnings

Safety matters

• Correct use

- Please use the tool properly as guided in this document.

• Maintenance service

This product cannot be disassembled. Only the maintenance personnel authorized by our company can repair the product. Please do not repair it yourself to avoid possible harms.

• Charging instructions

- Only use the charger that is in line with the charging parameters of the tool for charging;
- If the status indicator does not display normally when it is not used for a long time, please continue to charge for 30 minutes and check it again.

• Instructions for use

- This product can emit strong light. Please avoid having it emit direct light to human, animal eyes and optical equipment lens;
- In order to reduce the risk of harm, children should use the flashlight when with their parents;
- To reduce the risk of electric shock, do not put the tool in water or other liquids;
- Do not place or store the tool where it may fall into the bathtub or sink;
- After the strobe mode is turned on for a long time, the focus ring may generate high temperature. To reduce the risk of burns, please do not touch it.

Warning

- Please use a charger that is in line with the charging parameters of the tool for charging. Other types of chargers and accessories may violate the product warranty and may cause danger.
- 15 minutes after the highlight mode is turned on, the temperature will increase by about 20°C. For users who are sensitive to temperature, please implement heat insulation measures. (After 25 minutes, the temperature will slowly decrease.)
- After the product detects that the battery reaches 45°C, it will trigger the charging protection function and stop charging. The recommended charging environment temperature is 0°C-30°C.
- The light source of this luminaire is not replaceable; when the light source reaches its end of life the whole luminaire shall be replaced.

General malfunction and troubleshooting methods

Issue	Possible Causes	Solution
Press the main switch or strobe/SOS switch, the red light flashes.	Low li-ion battery power	Charging
Press the main switch or strobe/SOS switch, the flashlight does not light up.	No li-ion battery power	Charging
The indicator light on the main switch does not light up during charging.	The USB cable is not plugged in, or the specified charging cable is not used.	Use the specified charging cable; use 5V power adapter; check whether the indicator light is on.

04 Specifications

Model: QWSDT001	Battery Type: Lithium-ion battery
Item Dimensions: 164.5x 30 x 30 mm	Battery Capacity: 2600 mAh
Net Weight: Approx.160 g	Rated Voltage: 3.7V ==
Input: 5V==1A	Charging Time: Approx.210 min

Main switch three-mode parameters

	High light mode	Medium light mode	Low light mode
Brightness	1000LM	350LM	50LM
Run time	2H	3.5H	24H



Manufactured by: Shanghai HOTO Technology Co., Ltd.
Address: Building 45, No.50 Moganshan Road, Shanghai, China

小猴手电筒Lite使用说明书 • 1

HOTO Flashlight Lite User Manual • 8



扫码关注公众号
领一年延保及新人福利

Scan to follow us on WeChat
Get 1Y+ warranty and new follower benefits