

# PHILIPS

Kinno IR  
9290041414



 
User manual  
Benutzerhandbuch  
Notice d'emploi  
Manual de usuario  
Manual do usuário  
Manuale d'uso  
Gebruiksaanwijzing

Incl.

**A**



**B**




x2



x2

ST4.2\*30mm

 
Excl.



**B**




 
IP44



3/8"



  
8mm




E27



 
MAX. 25 W



 MIN 30 LUX MIN 5 SEC  
MAX 200 LUX MAX 12 MIN




MAX  
4 m

 






2m


 
00m 10m




110°

 

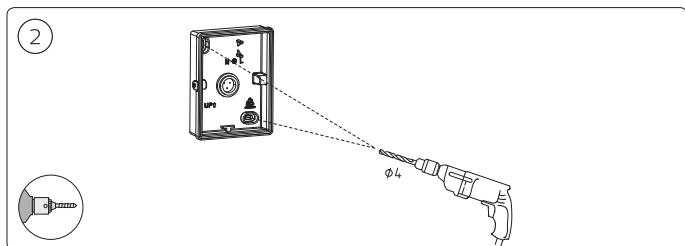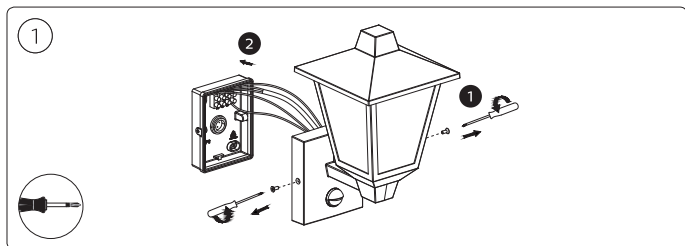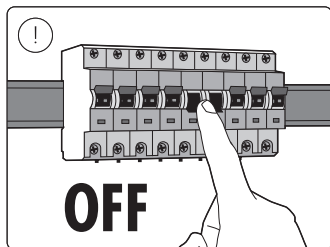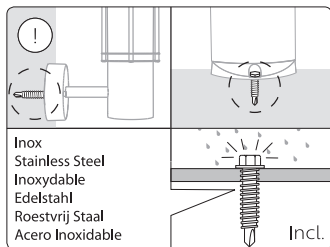



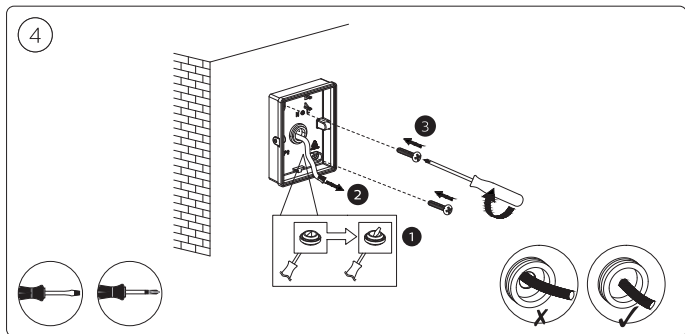
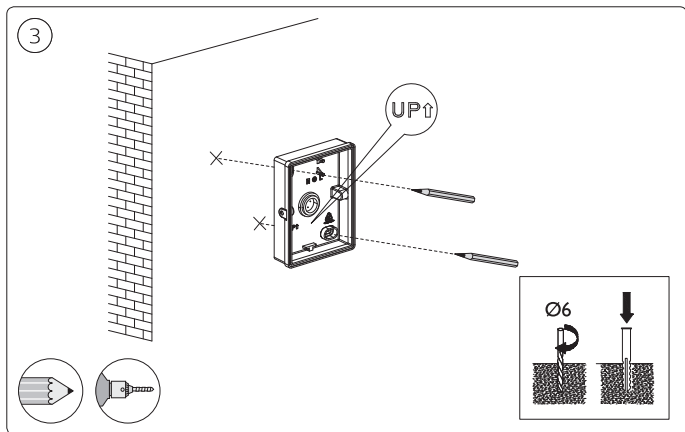


5

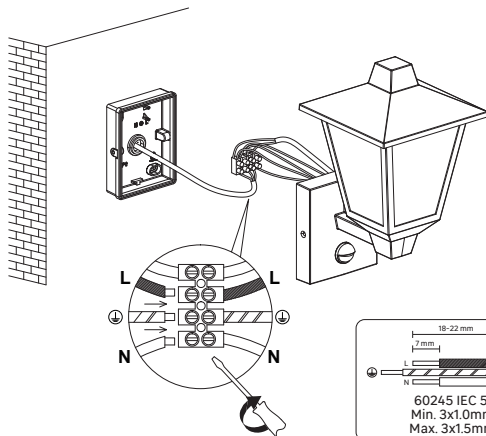


6

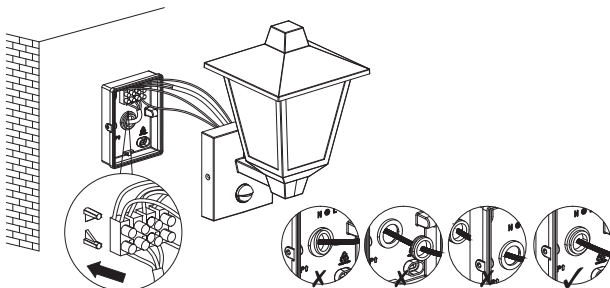


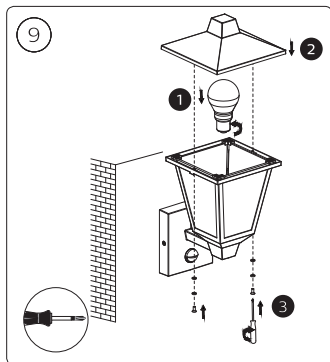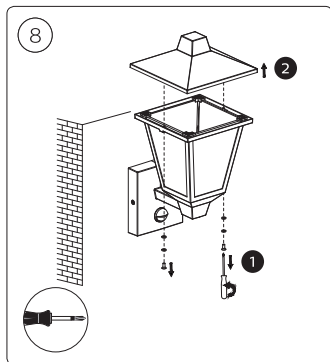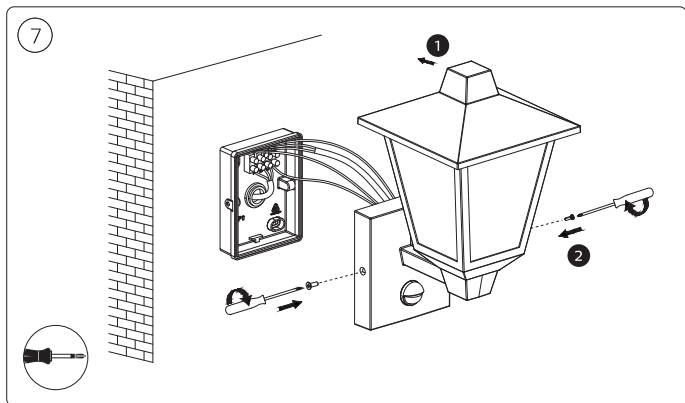


10

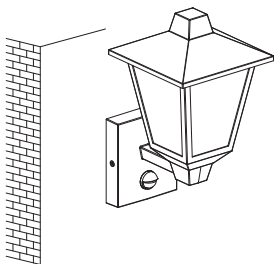

11a

 


11b

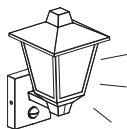


5 Sec  $\pm$  2 Sec

12 Min  $\pm$  3 Min

!

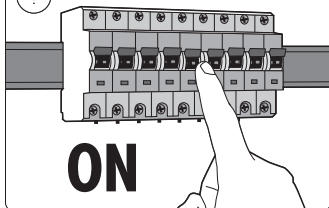

11c

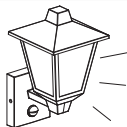

0 200Lux



0 30Lux



Signify Commercial UK Limited  
Unit 3, Guildford Business Park,  
Guildford, Surrey, GU2 8XG, UK

Signify  
B.R.S. / C.C.R.I. Numéro 10461  
600 VB Eindhoven,  
the Netherlands  
00800-74454775

Philips and the Philips Shield Emblem are registered trademarks  
of Koninklijke Philips N.V. and are used under license

**3241 662 13391**  
[www.philips.com/lighting](http://www.philips.com/lighting)

© 2024 Signify Holding

**Signify**