


GP Batteries

Product Specification

Model no.: B20B

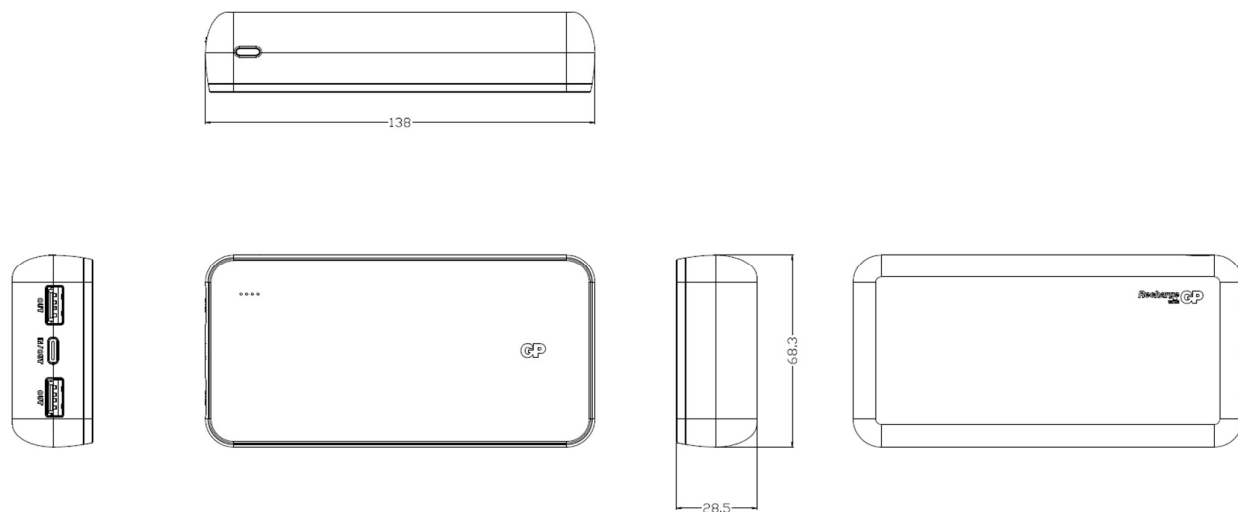

Product Name	: GP Portable PowerBank B20B
Description	: Back up power for USB powered electronic devices (e.g. smartphones, tablet PCs)
Battery Rating	: Lithium Polymer 3.7V 20000mAh 74.0Wh
Input	: [USB-C] DC 5V/3A
Output	: [USB-C] DC 5V/3A [USB-A1] or [USB-A2] DC 5V/3A [USB-A1 + USB-A2] DC 5V/3A [USB-C + USB-A1 + USB-A2] DC 5V/3A
Application	: Charge mobile and electronic devices with USB input
Recharging Time	: Approx. 9 hours by 5V/3A via USB-C port
Operation Temperature	: 5°C to 35°C



Member
Gold Peak Group

Manufacturer reserves the right to alter or amend the design, model and specification without prior notice.

GP Batteries

Product Specification

Model no.: B20B

Safety protection : 1) Over voltage protection
2) Under voltage protection
3) Over charging protection
4) Over discharging protection
5) Over current protection
6) Short circuit protection
7) Over & under temperature protection
8) Loop back protection

LED Indication : **Charging & Discharging the Portable PowerBank**

Table 1

Charging & Discharging Condition	LED Indicator
Charging	Last LED flashing
Discharging	Refer to battery status (Table 2)
Fully charged	All LEDs On

Press button to show battery status :

Table 2

Battery Strength	LED indicator
Good	Four LED on
Good to average	First Three LED on
Average	First Two LED on
Weak	One LED on
Very Weak	One LED Flash
No Power	No LED

Dimensions : 138 (L) x 68.3 (W) x 28.5 (H) mm +/-0.5mm
Weight : 410g +/- 10g
Certification : CE, UKCA, RoHS, UN38.3, IEC62133, IEC62368
Warranty Period : 12 months from ex-factory date



Member
Gold Peak Group

Manufacturer reserves the right to alter or amend the design, model and specification without prior notice.