

Comfort Waterwheel M/L



ATTENTION:
Please read the manual before using
Please include all documents when
handing over the product to others

Free-standing horizontal placement with 360° access offers wide watering area.

- Includes everything you need to get started.
- Total reach 21,5 meters in M-size model and 31,5 meters in L-size model.
- Turning support leg for upright and horizontal usage.
- Telescopic handle for better ergonomics with intuitive locking mechanism.
- Textured wheels and telescoping handle offer easy moving
- Built-in storage locker.
- Easy to use and store.
- Universal fit. Fits with other brands
- High pressure tested
- UV resistant.

Waterwheel M/L instructions for use:

- 1. Install the tap connector on the outdoor tap.** Take the tap connector from the compartment and choose the right thread size. The included tap connector has 3 thread sizes.
- 2. Connect the Waterwheel with your tap.** Pull out the inlet hose from the bottom of the Waterwheel and connect it to the tap connector.
- 3. Attach the hose nozzle.** Pull out the hose from the Waterwheel and connect the adjustable hose nozzle to the hose.
- 4. You're ready!** Open the tap and simply turn the nozzle to start watering.
- Before retracting the outlet hose, close the water source from the tap. Retract the hose manually by rotating the knob.

Tips: For additional stability, turn the support leg downwards to support the reel to the ground.

- Nominal pressure: 4 bar.
- Reel in the hose tightly before transporting the hose reel.
- If needed, you can replace the hose. The Waterwheel features a maximum outlet hose capacity of 13mm (1/2") 30m.

Maintenance:

- When not in use, please turn off the water source and release the water pressure by turning on the nozzle for a few seconds.
- Rinse dirt and debris with water.
- Use the product only for water transfer.

PLEASE READ ALL SAFETY ADVICE AND INSTRUCTIONS BEFORE USING THE PRODUCT

Warning:

- Always close the water source (water tap) after use of garden watering products.
- Do not direct the water jet towards electrical equipment!
- Do not direct the water jet towards persons or animals!
- No drinking water.

Warranty terms:

The manufacturer shall repair or replace, through the dealer, any parts of the product found to be faulty due to manufacturing defects, for a period of 24 months as of the date of purchase. The warranty does not cover defects due to tampering, improper use or wear. The warranty is valid only if the customer returns the product to the dealer complete in all its parts together with the receipt or other document proving the date of purchase.

Store in a frost-free environment

Fiskars UK Limited, Wedgwood Drive, Barlaston, Stoke-on-Trent, Staffordshire, ST12 9ER, ukconsumercare@fiskars.com
 Fiskars Australia Pty Ltd, australia.orders@fiskars.com, +61300 852 022 kuluttajapalvelu.suomi@fiskars.com
 +46 42 36 11 00 +47 23 00 64 40 +45 38 14 48 48, customerservice.dk@fiskars.com +33 169 75 15 15,
 serviceconsommateurs@fiskars.com +34 91 767 65 81 +34 91 767 65 81 +49 800 0051810, service.de@fiskars.com
 consumerservice.netherlands@fiskars.com Fiskars Italy s.r.l., c/o Copernico Centrale, via Copernico 38, 20125 Milano.
 www.fiskars.it/suporto/assistenza-clienti. Raccolta differenziata. Verifica le disposizioni del tuo comune. fiskars.com/pack
 Fiskars Polska Sp. z o.o., ul. Komitetu Obrony Robotników 45B, 02-146 Warszawa. +48 22 310 85 00 Fiskars Polska Sp.
 z o.o. Magyarországi Fióktelepe, 1119 Budapest Fehérvári út 97-99, +36 1 453 0945 +372 60 17 010 +358 204 3910
 +358 204 3910 +358 204 3910 +358 204 3910 office@fiskars.com

Fiskars Finland Oy Ab
Keilaniementie 10, P.O. Box 91
FI-02151 Espoo, Finland
Tel. +358 (0)204 3910

Fiskars brand is a registered trademark of Fiskars Corporation.

For packaging recycling information: fiskars.com/pack

Comfort Waterwheel M/L


- A. Foldable support leg
- B. Knob
- C. Storage locker
- D. Hose
- E. Hose holder
- F. Telescopic handle with SoftGrip™
- G. Locking latch for telescopic handle
- H. Textured wheels



M 1071639
L 1071670

Parts

- Tap Connector, Multi
- Quick Hose Connector 13-15 mm (1/2-5/8")
 - 1 pc – outlet hose "STOP connector"
 - 3 pc – inlet hose
- CF Hose Nozzle
- Outlet Hose 20 m and Inlet Hose 1.5 m
 - Hose 13 mm (1/2")

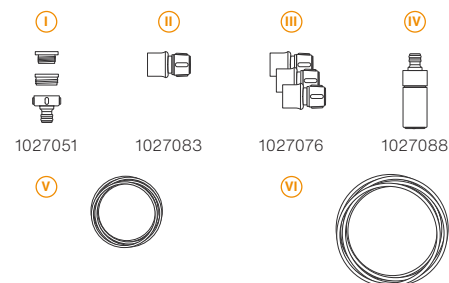


Use

ON OFF 5



1 Install the tap connector on the outdoor tap.

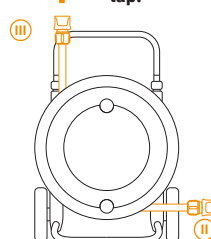

2 Connect Waterwheel with your tap.

3 Attach the spray gun nozzle.

4 You're ready!