


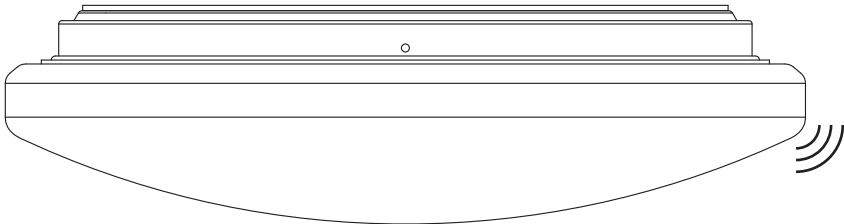
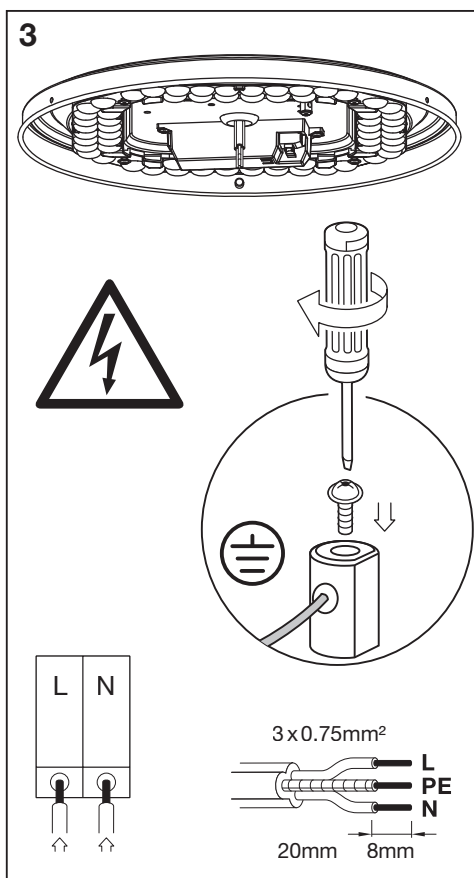
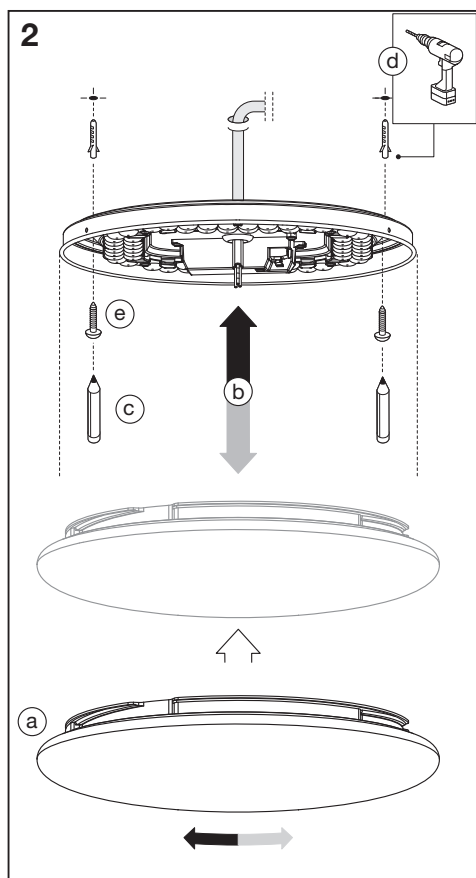
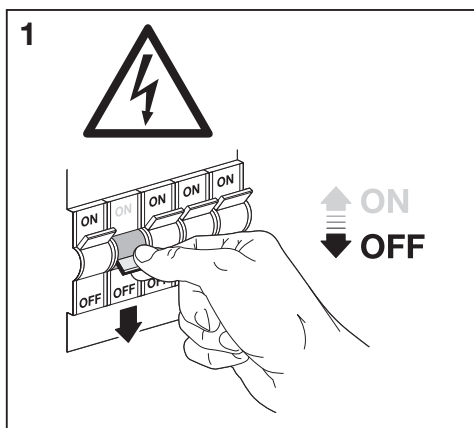
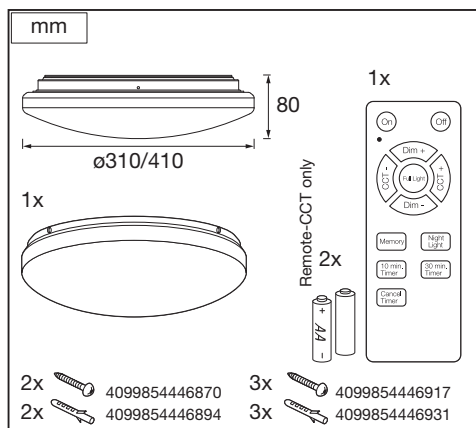
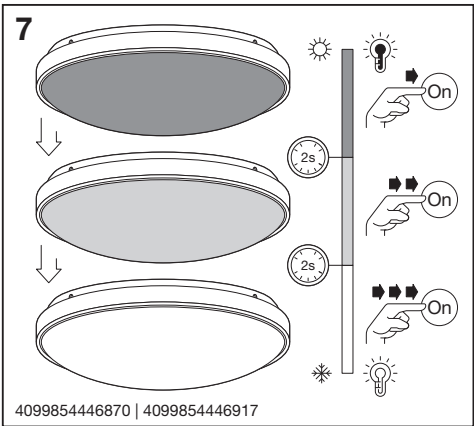


ORBIS® CCT

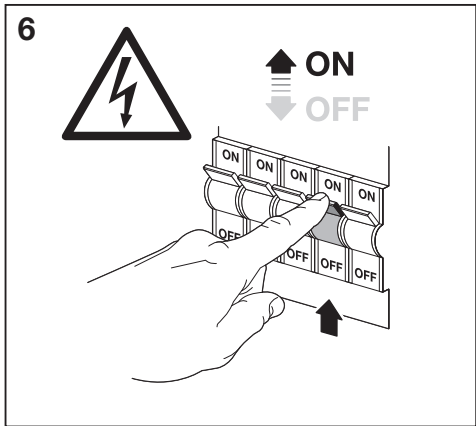


	EAN	W	lm light source	lm output	K	°C	V~	mA	Hz	DF	(g)	°)	
ORBIS 310MM 15W 827-865 CLICK-CCT	4099854446870	15	1700	1000	2700/ 4000/ 6500	-20...+40	220-240	68	50/60	>0.7	540	120	12500
ORBIS 410MM 24W 827-865 CLICK-CCT	4099854446917	24	3000	1800	2700/ 4000/ 6500	-20...+40	220-240	105	50/60	>0.7	860	120	12500
ORBIS 310MM 17W 827-865 REMOTE-CCT	4099854446894	17	1800	1000	2700- 6500	-20...+40	220-240	113	50/60	>0.7	550	120	12500
ORBIS 410MM 25W 827-865 REMOTE-CCT	4099854446931	25	3000	1800	2700- 6500	-20...+40	220-240	171	50/60	>0.7	870	120	12500

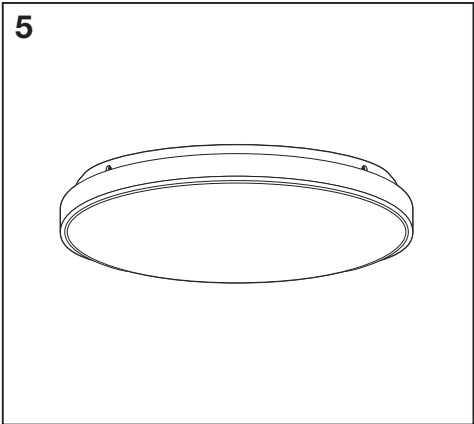

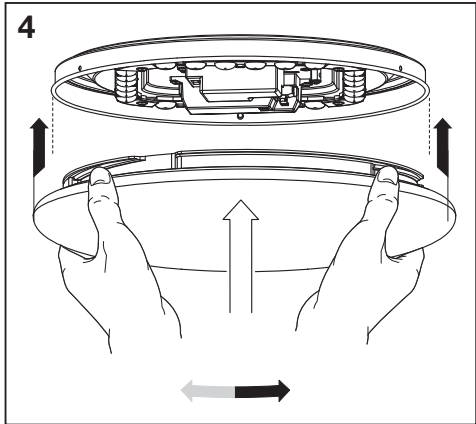

4099854446870 | 4099854446917

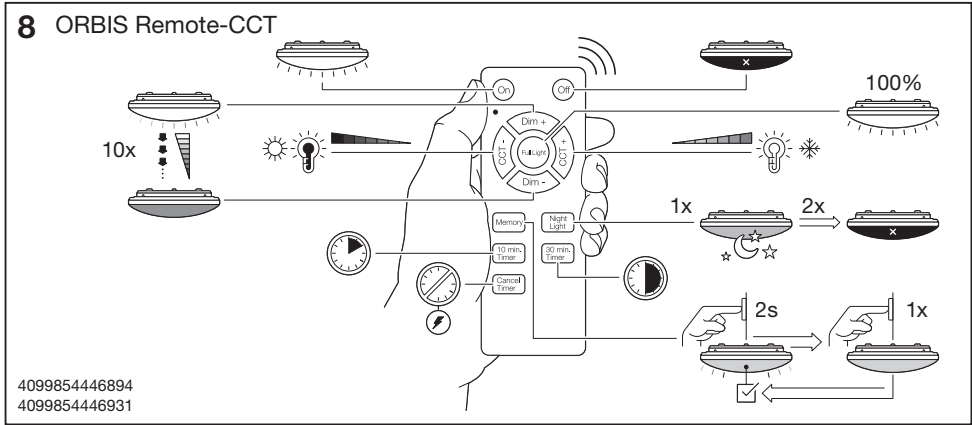

4099854446894
4099854446931

