








ENDURA® STYLE

SOLAR BOUQUET

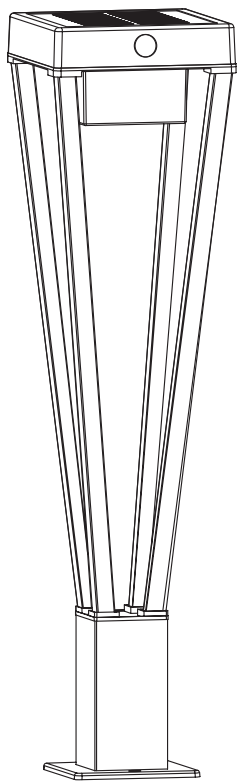


	EAN	W	Im Mode A	Im Mode B	Im Mode C	K	θ_{amb} (°C)	V	IP	
ENDURA STYLE SOL BOUQUET 50CMSEN BK	4099854455650	6	200	steady 75 + PIR 300	550	3000	-20...+40	3.7	44	12500

ENDURA® STYLE
SOLAR BOUQUET

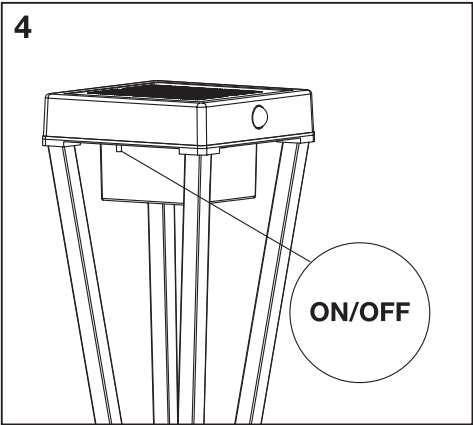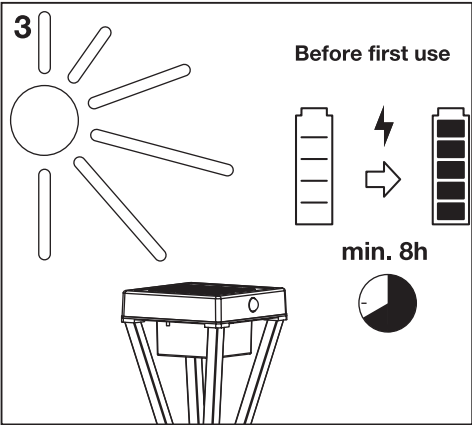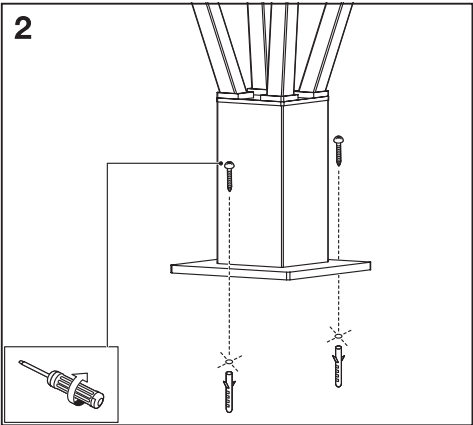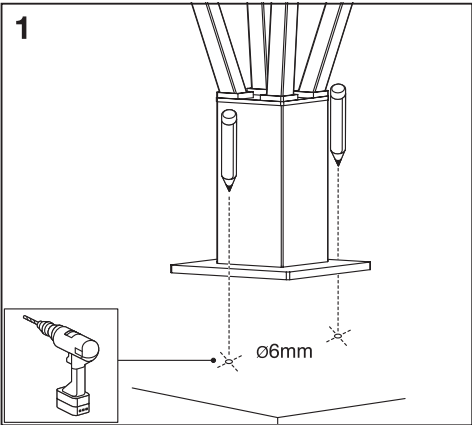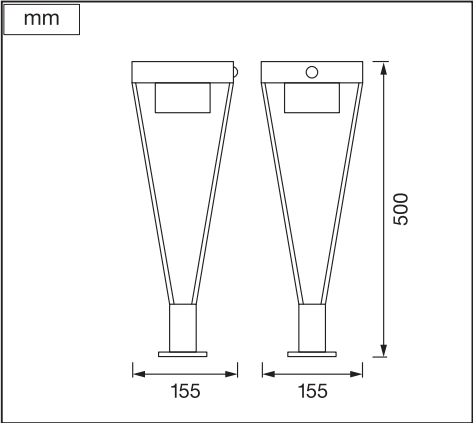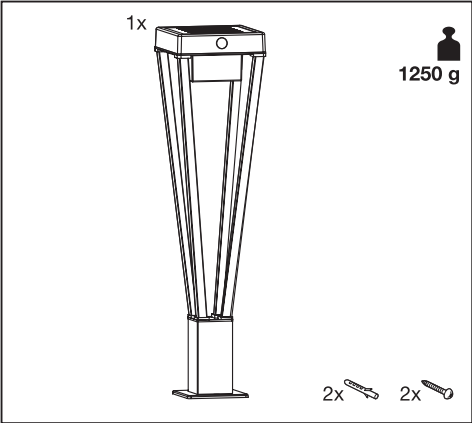

5

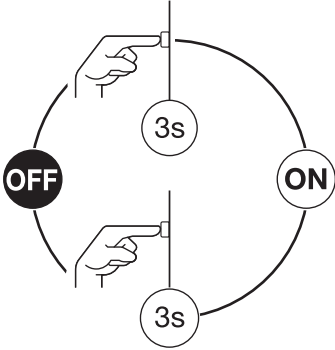


Mode A




200lm

 2.5h  >12h


Mode B

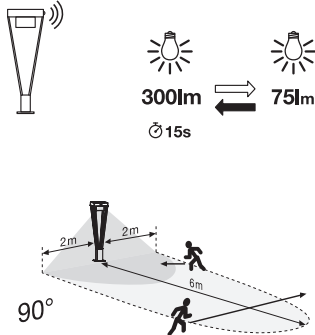


300lm → 75lm
⌚ 15s

 PIR: 100x
STEADY: 7-8h  >12h

Mode C

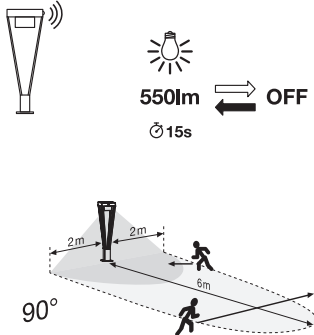


550lm → OFF
⌚ 15s

 100x  >12h

6



7



3



LEDVANCE SASU
CQM, 5 rue d'Altorf
67120 Molsheim France
www.ledvance.com

GB LEDVANCE Ltd, Sterling House,
810 Mandarin Court, Warrington,
Cheshire, WA1 1GG, United Kingdom

G11219128
23.01.2025