


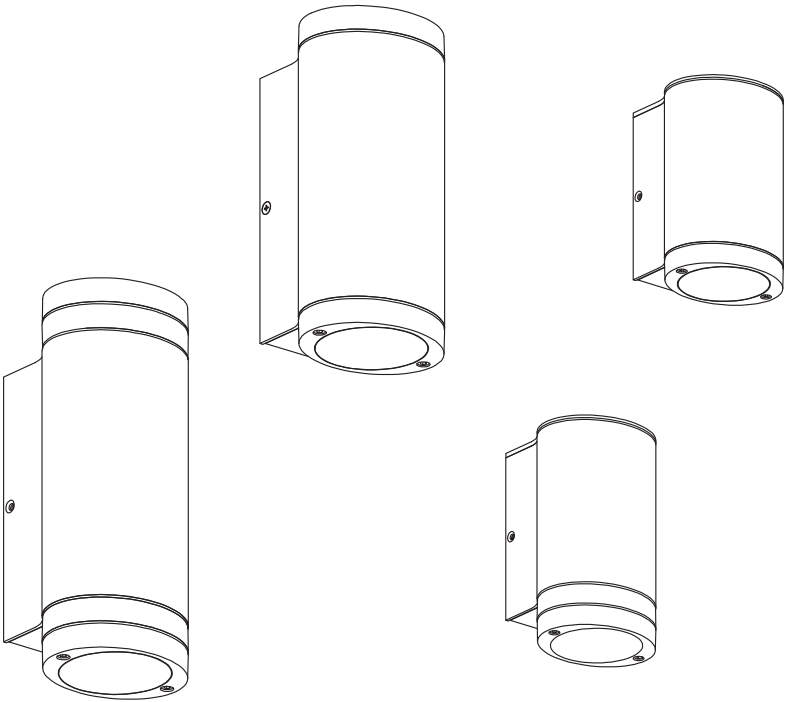
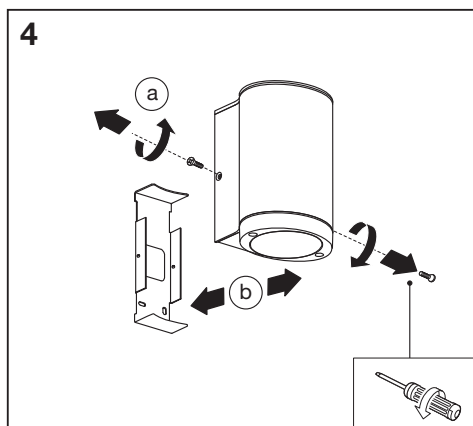
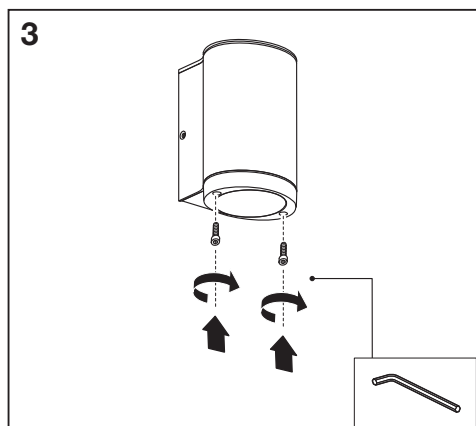
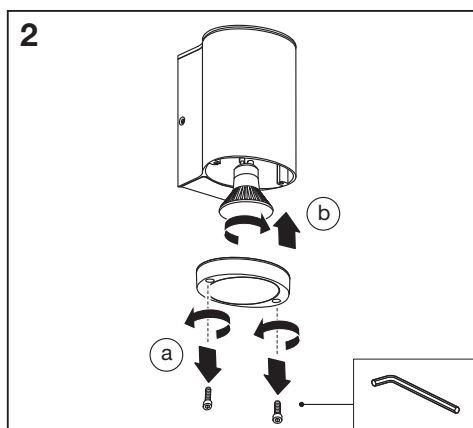
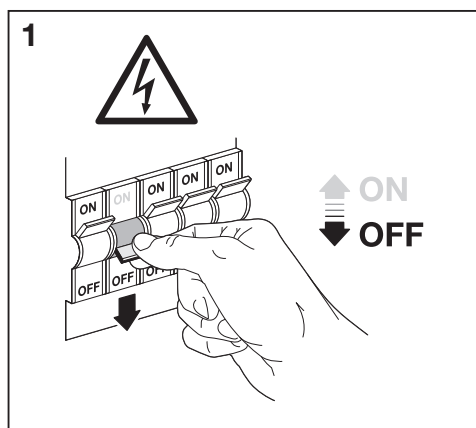
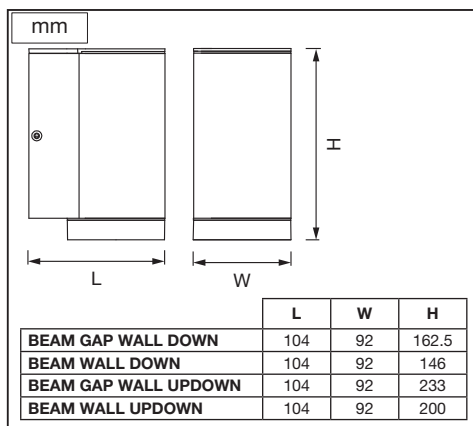
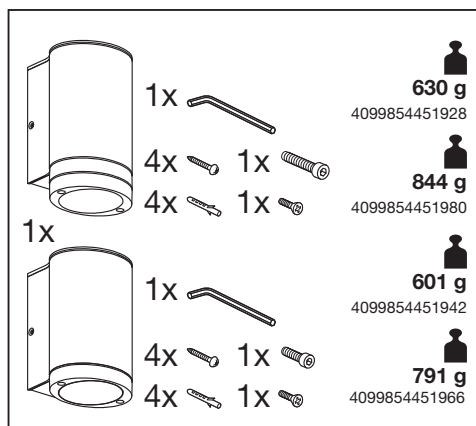
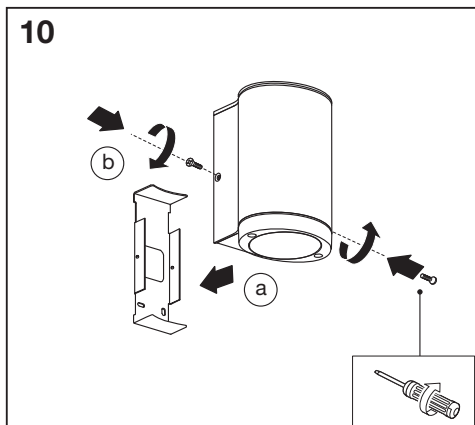
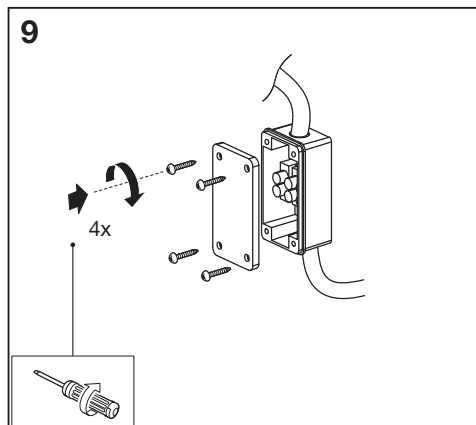
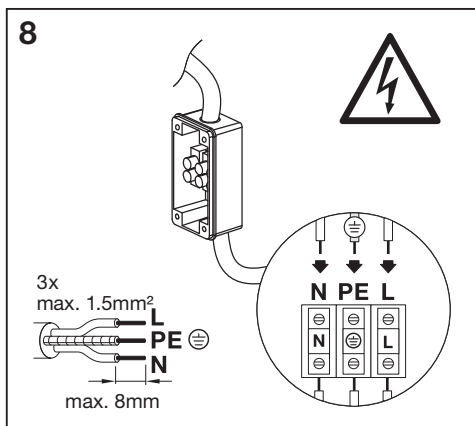


ENDURA® CLASSIC BEAM

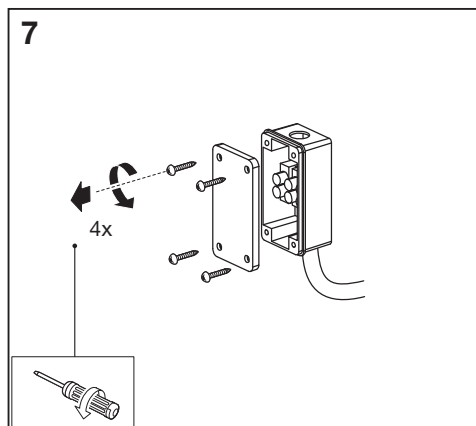


	EAN	W _{max.}	ⓘ (°C)	V~	Hz
ENDURA CLASSIC BEAM GAP GU10 DG	4099854451928	35	-20...+40	220-240	50/60
ENDURA CLASSIC BEAM GU10 DG	4099854451942	35	-20...+40	220-240	50/60
ENDURA CLASSIC BEAMGAPUPDOWN GU10DG	4099854451980	2x 35	-20...+40	220-240	50/60
ENDURA CLASSIC BEAM UPDOWN GU10 DG	4099854451966	2x 35	-20...+40	220-240	50/60

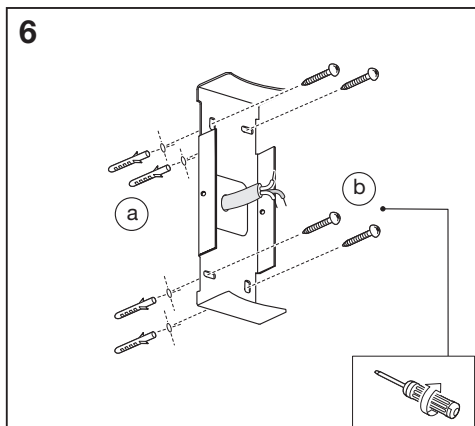


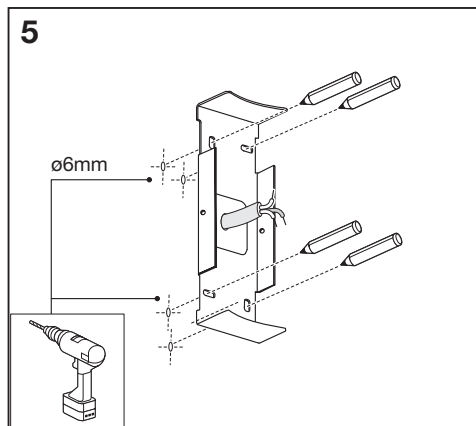

11

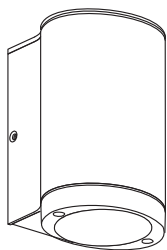

12

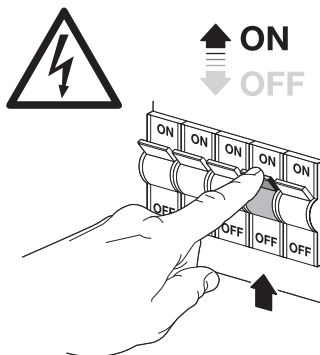

13



Points de collecte sur www.quefairedemesdechets.fr



LEDVANCE SASU
CQM, 5 rue d'Altorf
67120 Molsheim France
www.ledvance.com

© LEDVANCE Ltd, Sterling House,
810 Mandarin Court, Warrington,
Cheshire, WA1 1GG, United Kingdom

G11219072
12.02.2025