


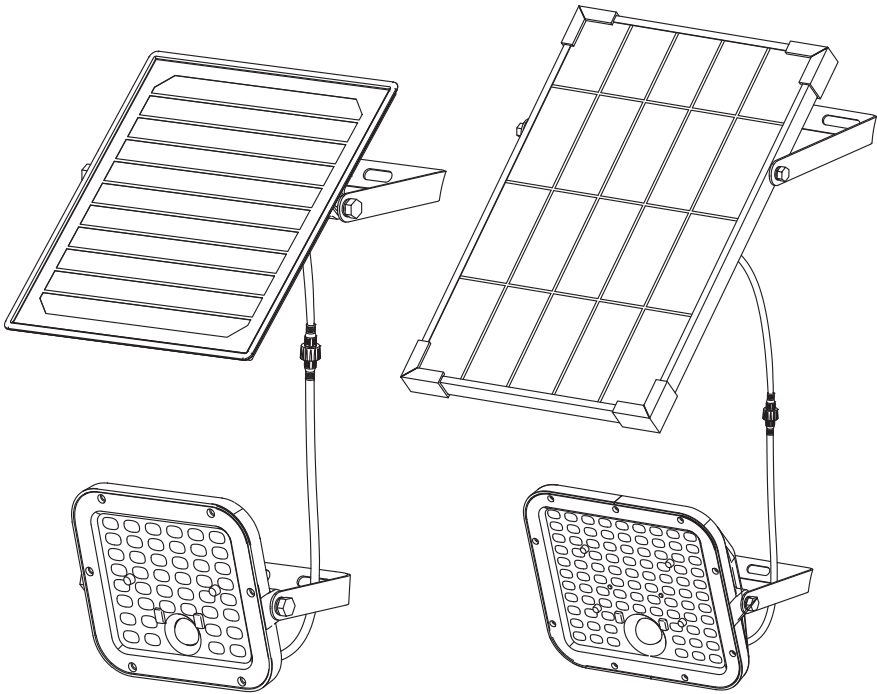
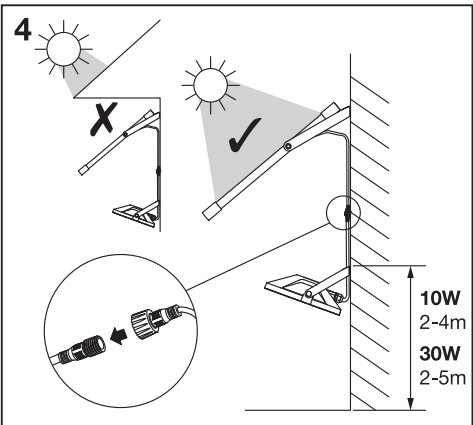
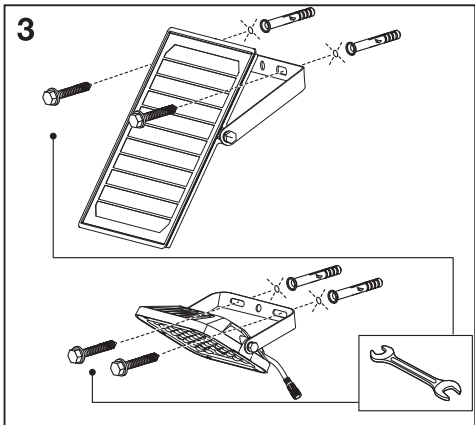
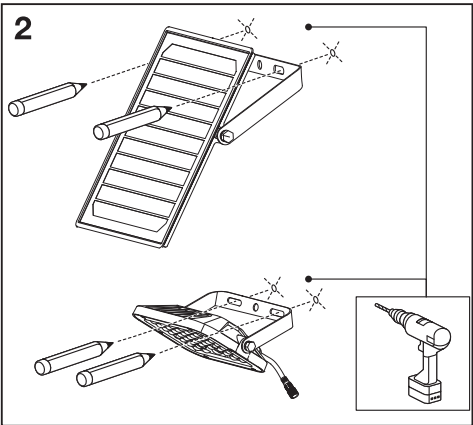
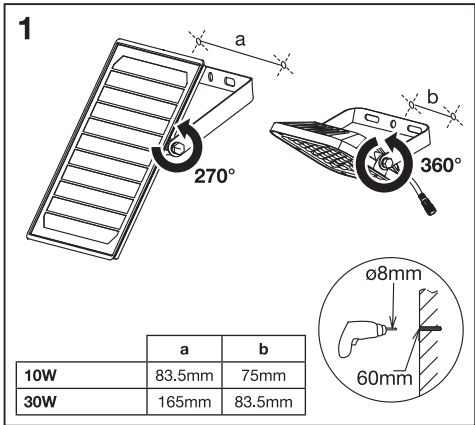
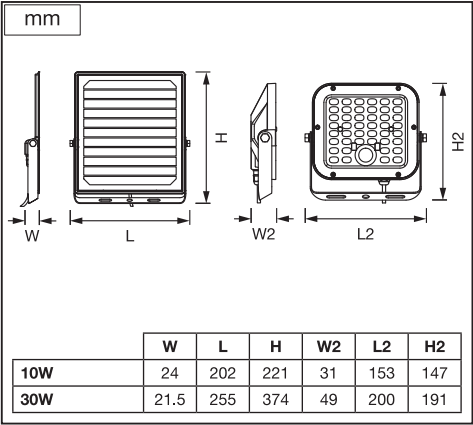
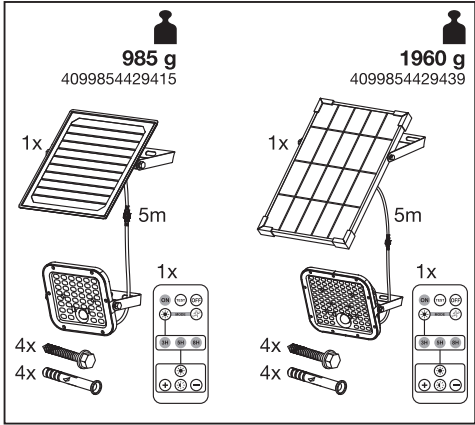
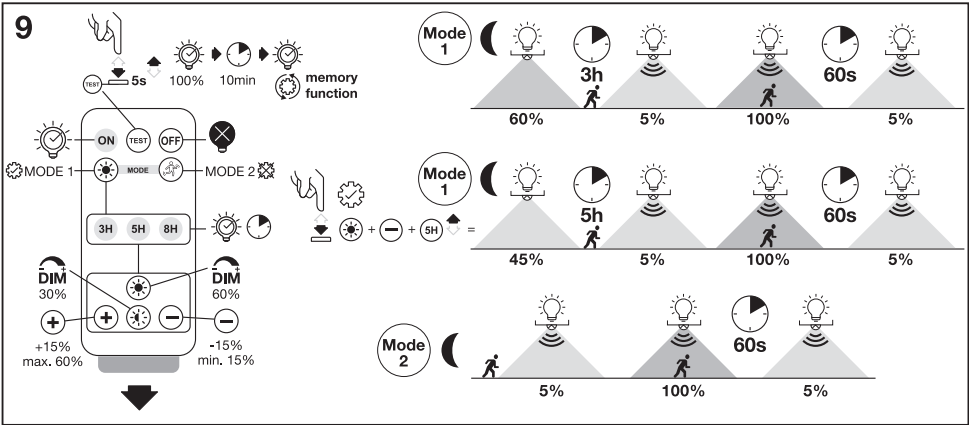
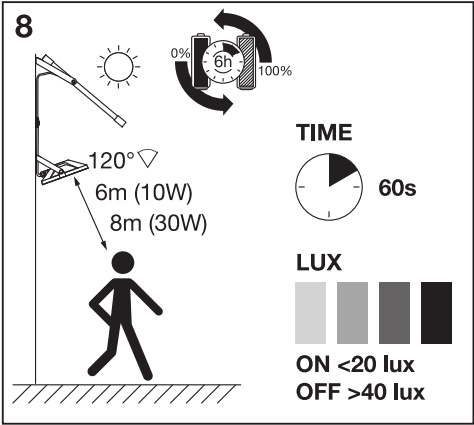




ENDURA® FLOOD SPLIT

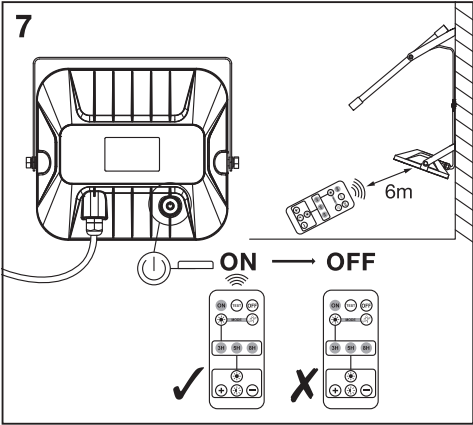

	EAN	W	lm light source	lm output	K	°C	V _{DC}	IP	°	
ENDURA FL SPLIT SOL SEN 10W 840 RC	4099854429415	10	1450	1400	4000	-20...+40	4.2	65	120 x 60	10000
ENDURA FL SPLIT SOL SEN 30W 840 RC	4099854429439	30	4550	4500	4000	-20...+40	6.4	65	120 x 60	10000

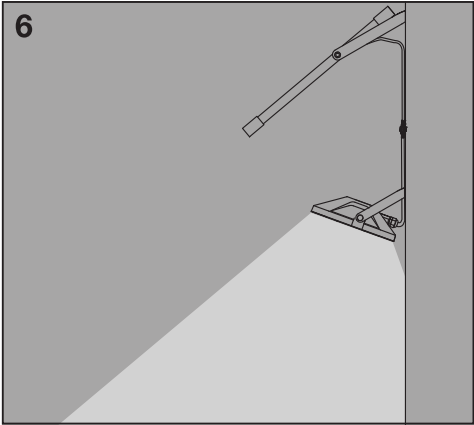

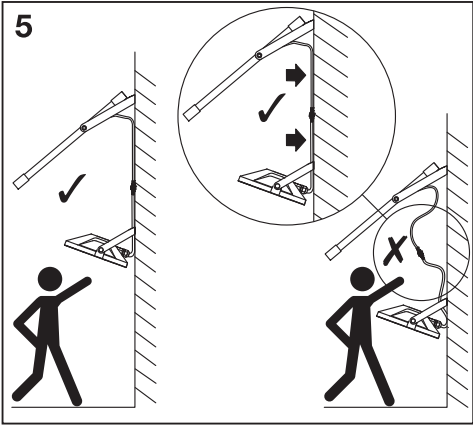

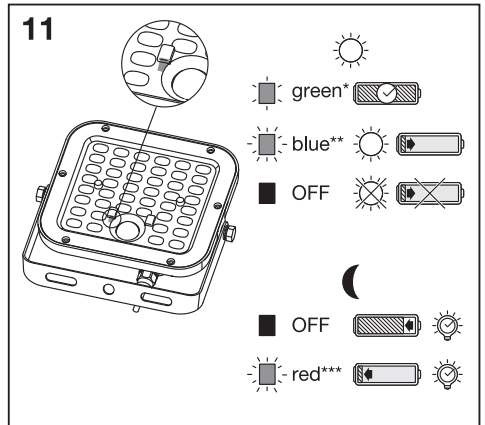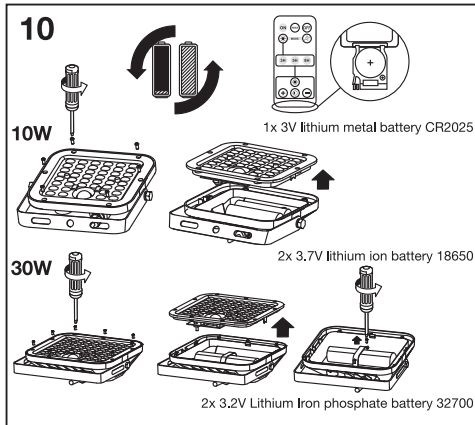

* ① grön ② vert ③ verde ④ verde ⑤ verde ⑥ πράσινο ⑦ groen ⑧ grön ⑨ vihreä ⑩ grønn ⑪ grøn ⑫ zelená ⑬ зелёный ⑭ zöld ⑮ zielony ⑯ zelená ⑰ zelena ⑱ yeşil ⑲ zelena ⑳ verde ㉑ Зелено ㉒ roheline ㉓ žalias ㉔ zaiš ㉕ zelena ㉖ zeleniy ㉗ жасыл

** ① blau ② bleu ③ blu ④ azul ⑤ azul ⑥ μπλε ⑦ blauw ⑧ blá ⑨ sininen ⑩ blá ⑪ blá ⑫ modrá ⑬ синий ⑭ kék ⑮ niebieski ⑯ modrá ⑰ modra ⑱ mavi ㉒ plava ㉓ albastru ㉔ син ㉕ sinine ㉖ melyn ㉗ zils ㉘ plava ㉙ синий ㉚ kek

*** ① rot ② rouge ③ rosso ④ rojo ⑤ vermelho ⑥ κόκκινο ⑦ rood ⑧ ród ⑨ punainen ⑩ red ⑪ red ⑫ červená ⑬ красный ⑭ piros ⑮ czerwony ⑯ červená ⑰ rdeča ⑱ kırmızı ⑲ crvena ⑳ roșu ㉑ Червено ㉒ punane ㉓ raudonas ㉔ sarkans ㉕ crvena ㉖ червоний ㉗ қызыл



Points de collecte sur www.quefairedemesdechets.fr



LEDVANCE SASU
CQM, 5 rue d'Altorf
67120 Molsheim France
www.ledvance.com

GB LEDVANCE Ltd, Sterling House,
810 Mandarin Court, Warrington,
Cheshire, WA1 1GG, United Kingdom

G11211046
07.02.2025