 




WM6654 Universal TV wall mount

Ultra Slim

180°
TURN



32 - 90"
81 - 229 cm

TV size




Wall distance



Max. weight




Max. 600 x 400

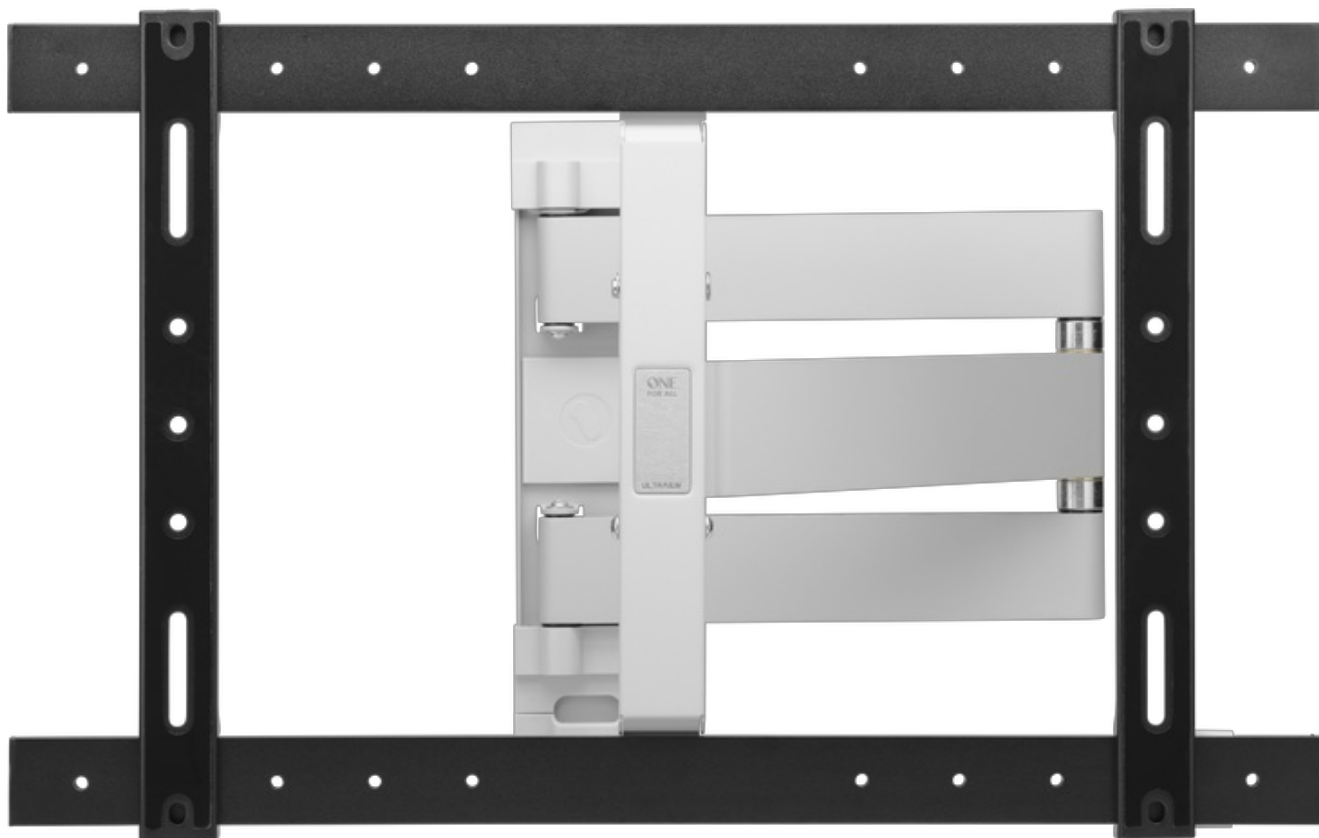


Enjoy your new viewing experience

Experience the unobtrusive design, smart engineering and high quality of the Ultra Slim Line made with durable materials.


Consumer benefits

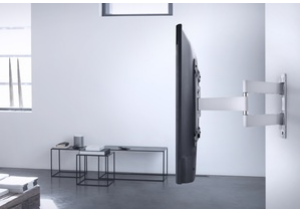


Unaufdringliches Design

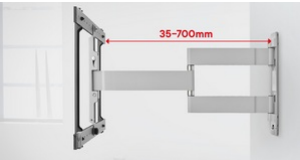

Außerordentlich großer Abstand zur Wand

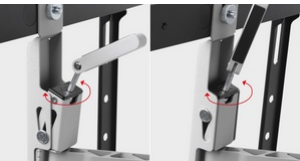

Präzise Neigungsverstellung

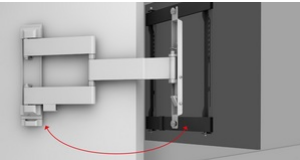

Ideal für Ecken und angrenzende Räume



Kabelmanagement

Logistical information

Version Number	WM6654-000-0001
Model name	WM6654
Product dimensions cm (LxWxH)	3.8x67.4x42.3
Product dimensions inch (LxWxH)	1.5x26.54x16.65
Packaging dimensions cm (LxWxH)	8x75.5x43.5
Packaging dimensions inch (LxWxH)	3.15x29.72x17.13
Packed product weight gross (pounds)	17.199
EAN-13 Packaging	8716184075766
Inner dimensions cm (LxWxH)	n/a
Quantity master (EA)	2
Master dimensions cm (LxWxH)	77x45x18
Master weight gross (pounds)	36.824
EAN-13 Master	8716184075773



Specifications

Specifications

- Funktion: Turn
- Neigung (°): 5
- Backward tilt (°): -1
- Total Tilt (°): 6
- Drehung (°): 180
- Maximales Gewicht (kg): 40
- Max weight (pounds): 88.2
- Mindestgröße (Zoll): 32
- Mindestgröße (cm): 81
- Maximale Größe (Zoll): 90
- Maximale Größe (cm): 229
- Wandabstand D minimal (mm): 35
- Wandabstand D maximal (mm): 700

Compatibility

- VESA-kompatibel
- Universal einstellbar
- Vesa-Größen: 100x100, 100x200, 200x100, 200x200, 300x200, 300x300, 400x200, 400x300, 400x400, 600x400, Universally Adjustable
- Maximale Montage B (mm): 600
- Maximale Montage H (mm): 400

Features

- Innovatives Nivellierungssystem
- Soft-Touch-Gummi
- Neigungssperre in Nullstellung
- Einstellbare Neigungssperre
- Kabelmanagement
- Wasserwaage
- Ideal für Ecken
- Kann mit einer Schraube gesichert werden.
- Fischer-Dübel



Questions? Send us an email:

info@oneforall.com

———— www.oneforall.com ————