
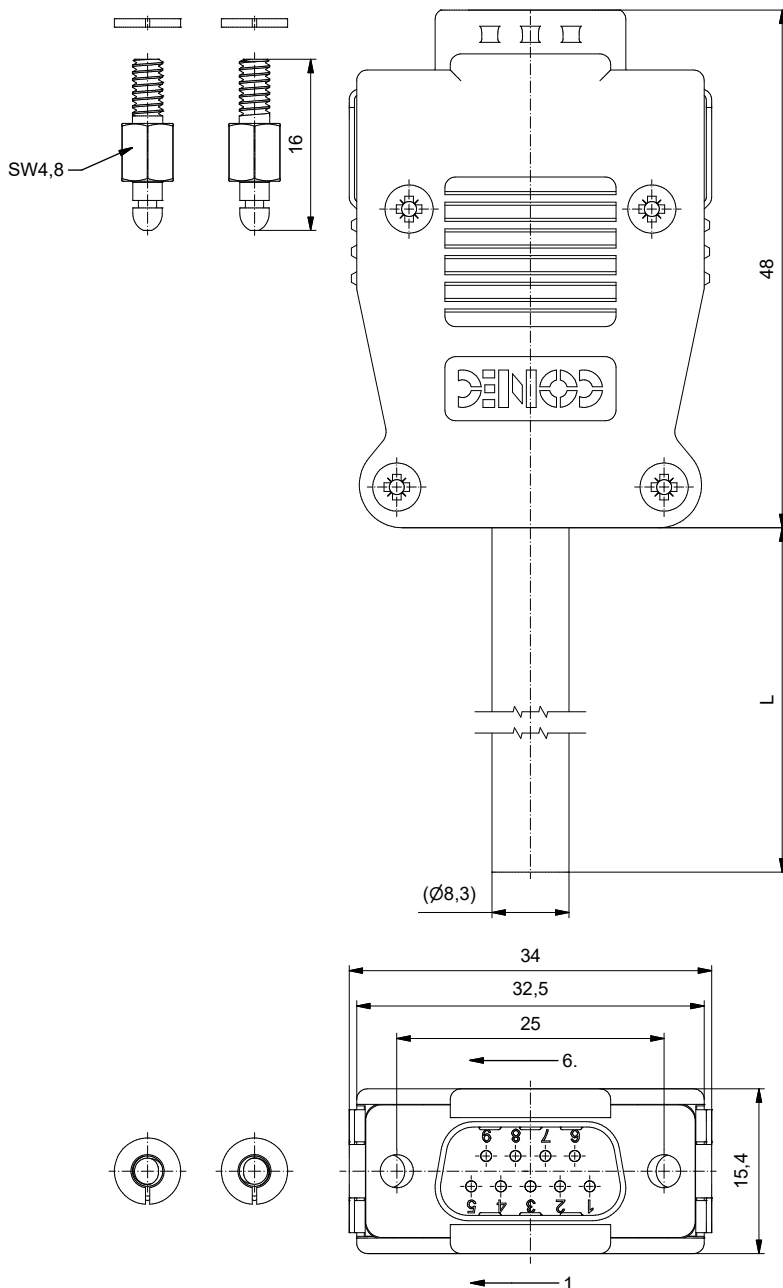


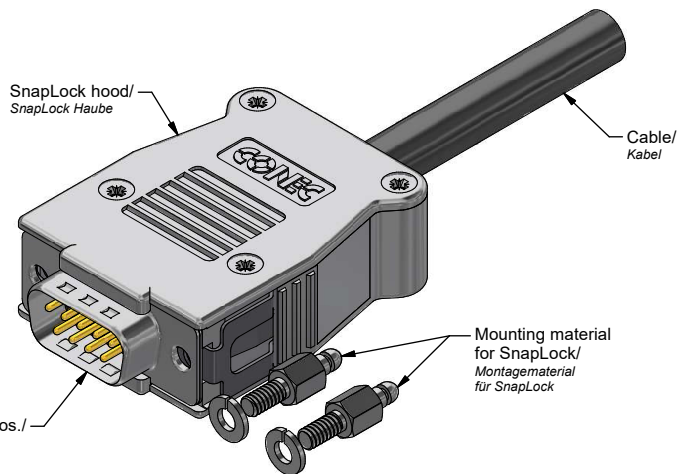

Materials SnapLock hood/ Werkstoffe SnapLock Haube:

Hood/ Haube:	ABS UL 94 V-0, Ni
Blanking plug/ Blindstopfen:	ABS UL 94 V-0, Ni
Cable strain relief/ Zugentlastung:	Steel, Ni
Clip/ Clip:	Stainless Steel/ Edelstahl
Countersunk-head screw/ Linsenkopfschraube:	Steel, Ni
Mounting material/ Montagematerial:	Steel, Ni

Materials D-SUB Male 9pos./ Werkstoffe D-SUB Stift 9pol.:

Insulator/ Isolierkörper:	PA 66 GF UL 94 V-0
Shell/ Gehäuse:	Steel, Sn over Ni
Crimp contact/ Crimpkontakt:	Copper alloy, Au over Ni

Contact assignment/ Kontaktbelegung:

D-Sub

1	black/schwarz
2	brown/braun
3	red/rot
4	orange/orange
5	yellow/gelb
6	green/grün
7	blue/blau
8	violett/violett
9	grey/grau
	white/weiss

Shielding
cable strain relief/
Schirmauflage
Zugentlastung

Part no/ Art.-Nr.:	Length L/ Länge L:	Cable/ Kabel:
16-512330	1,8 m	PVC, grey/grau, 10x0,34 mm ² , LiYCY Cable/Kabel: 781-GN31000
16-512340	3 m	
16-512350	5 m	

tolerance of cable/ Kabeltoleranz:		L <= 4 m: L + 40 mm L > 4 m: L + 1 %			dim. in mm		D-Sub Male 9pol. in SnapLock hood with cable and mounting material		
general tolerance/ Allgemeintoleranz:		0 ± 0,50 mm 0,0 ± 0,25 mm 0,00 ± 0,10 mm ± 5°			Date/Datum	Name	D-Sub Stift 9pol. in SnapLock Haube mit Kabel und Befestigungsmaterial		
				drawn/ gez.	25.11.2024	Lehmenkühler			
				appd./ gepr.	29.11.2024	Koch			
Index: b 09.04.2025 JLE		scale/maßstab:		2:1		dwg no / Z.-nr.:		16K1A4393	DIN- A3
						Customer specific product		1 / 1	