

LogiLink®

Gaming Chair With Headrest Lumbar Support & RGB Lights

Art. No.: EO0076



BUILT FOR DURABILITY AND SUPREME COMFORT

Designed for gamers/workers for ergonomically and sitting comfort. Providing removable headrest and adjustable lumbar cushions, RGB lights, up to 150° reclining angle as well as sturdy base and back constructions.


Designed For All-Day Gaming

Wide seat base ensure optimal weight distribution for long-lasting comfort during gaming marathons.



Dynamic RGB Light Effects

Preloaded dynamic RGB lighting effects creates stylish gaming ambience with breathing, static, wave effects and more.

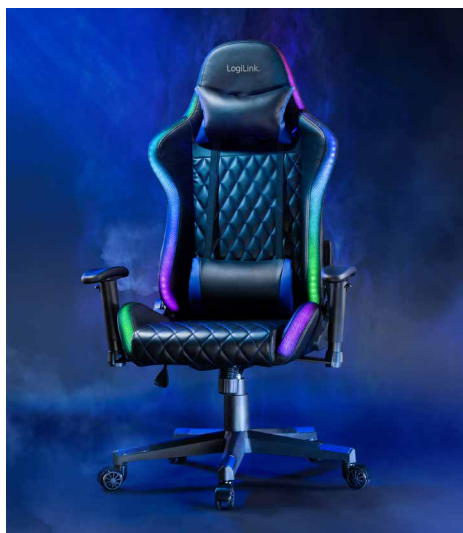

Breathable quilted PU leather seat with diamond pattern

Removable headrest cushion

Adjustable lumbar cushion

2D armrest

Ergonomic wide seat

Rocking angle controller

Shock-absorbing nylon casters

Rocking start lever

Ergonomic and Supreme Comfort

Wide seat base ensure optimal weight distribution for long-lasting comfort with easy height adjustable.



Reclining up to 150°

Lean back, sit upright or rock with built-in tilt tension lever underneath the seat.



2D Armrest

2-direction adjustment relieves wrist and forearm stress and pressure.



Extra Storage Space

Pocket under the seat for storing accessories.



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.



EO0076



Made in China

Specifications:

Dimensions	74 x 67 x 125–133 cm
Weight Capacity	150 kg
Surface Material	PVC leather
Frame Material	Steel
Base Type	Nylon plastic base
Caster Type	Nylon caster
Pneumatic Lever Type	80 mm Class 4 Gas Lift
Tilt Range of Back	150°
Armrest Type	2D Armrest
Ambient Lighting	RGB
Power (Lighting)	USB powered (5 V/2 A, 10 W max.)
Remote's Battery	CR2025 button cell battery
Color	Black and blue

Package Contents:

- » 1 x Gaming Chair
- » 1 x Remote Control
- » 1 x Screw Package
- » 1 x User Manual

Package Information:

- » Packing Dimension: 825 x 645 x 316 mm
- » Packing Weight: 19.3 kg
- » Carton Dimension: 825 x 645 x 316 mm
- » Carton Q'ty: 1 pc
- » Carton Weight: 19.3 kg



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.



EO0076



Made in China