 



QUICK START GUIDE

TUNE 720 BT



WHAT'S IN THE BOX

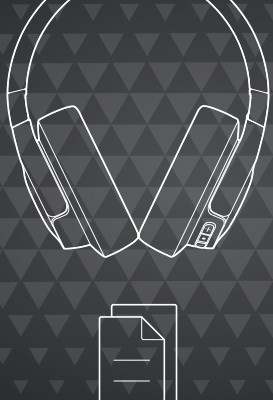

SCAN ME

APP



JBL HEADPHONES

GET EVEN MORE CONTROL AND PERSONALIZATION OF YOUR LISTENING EXPERIENCE WITH THIS FREE APP.






(FOR CHINA ONLY)



POWER ON & CONNECT



HOLD (2s)

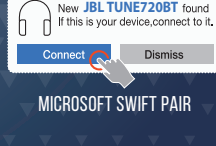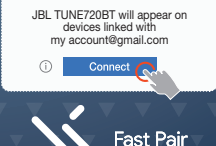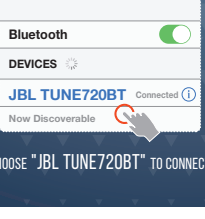

* TO ENTER PAIRING MODE AGAIN, POWER OFF AND HOLD FOR 5 SECONDS.


CHOOSE "JBL TUNE720BT" TO CONNECT

Fast Pair

MULTI-POINT CONNECTION



(MAXIMUM 2 DEVICES)

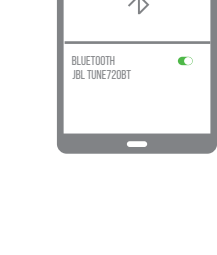

PRESS x 2


CONTROLS

• PRESS x 1
— HOLD (2s)






* ENABLE ADVANCE CONTROLS BY CONNECTING YOUR JBL TUNE720BT TO JBL HEADPHONES APP



WIRED LISTENING MODE

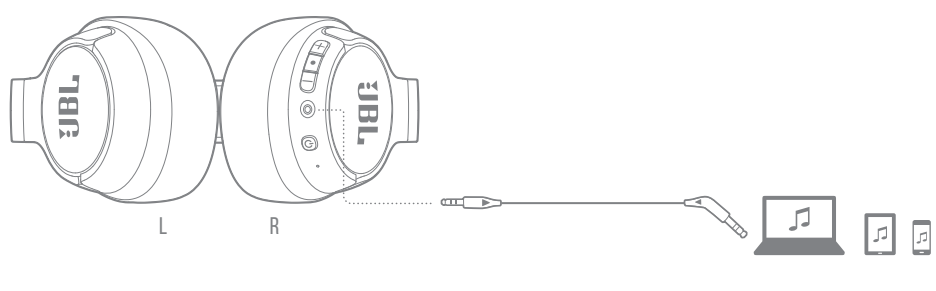


DO MORE WITH THE APP

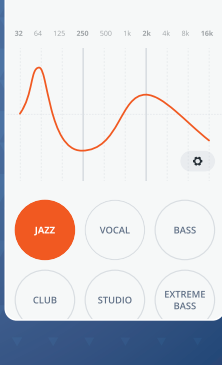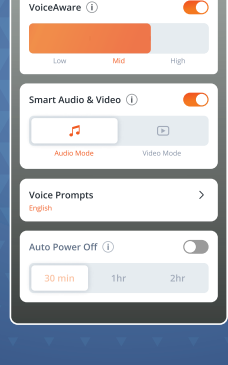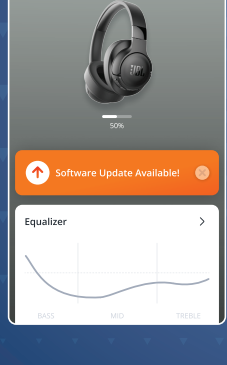

CHARGING



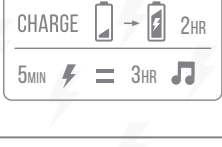
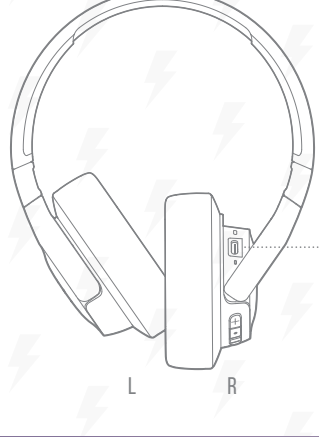


FACTORY RESET

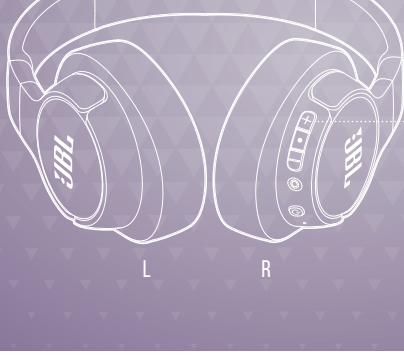

HOLD (5s)

LED BEHAVIORS

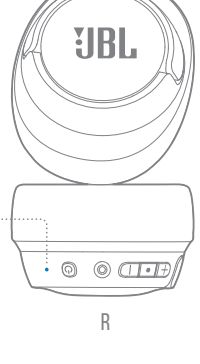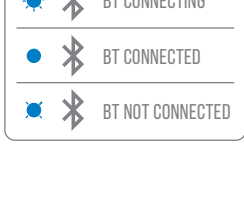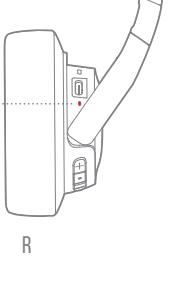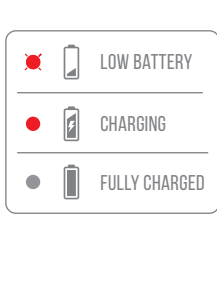

TECH SPEC



Model:	TUNE720BT	Maximum SPL:	95 dB
Driver size:	40 mm/ 1.57" Dynamic Driver	Microphone sensitivity:	-40 dBV/Pa@1 kHz
Power supply:	5V --- 1A	Bluetooth version:	5.3
Weight:	220 g/ 0.485 lbs	Bluetooth profile version:	A2DP v1.3.2, AVRCP v1.6.2, HFP v1.7.2
Battery type:	Lithium-ion Battery (500 mAh/ 3.7 V)	Bluetooth transmitter frequency range:	2.400 GHz - 2.4835 GHz
Charging time:	2 hrs from empty	Bluetooth transmitter power:	≤ 10 dBm (EIRP)
Music playtime with BT on:	Up to 76 hrs	Bluetooth transmitter modulation:	GFSK, π/4-DQPSK, 8-DPSK
Talk time:	Up to 45 hrs	Maximum operation temperature:	45 °C
Frequency response:	20 Hz - 20 kHz		
Impedance:	32 ohm		
Sensitivity:	101 dB SPL@1 kHz		

