

MAGCurve 360 Ultra ARGB CPU AIO Liquid Cooler

P/N: CL-W453-PL12SW-A CL-W454-PL12SW-A

MAGCurve 360 Ultra **ARGB** CPU AIO Liquid Cooler

Release the full CPU Horsepower



thermaltake

**Requires motherboard sync for ARGB lighting effect*

MAGCurve 360 Ultra ARGB CPU AIO Liquid Cooler

• Specification

MAGCurve 360 Series

Product	P/N	CL-W453-PL12SW-A (Black) CL-W454-PL12SW-A (Snow Edition)
Compatibility	CPU Socket	Intel LGA 2066/2011-3/2011/1851/1700/ 1200/1156/1155/1151/1150 AMD AM5/AM4/AM3+/AM3/AM2+/AM2/FM2/FM1
Water Block	Material	Copper
Pump	Motor Speed	PWM 1500~3300 RPM
	Rated Voltage	12V
	Rated Current	0.43A
	Power Input	5.16W
CPU Display	Rated Voltage	5V
	Rated Current	0.45A
	Power Input	2.25W
	Display Type	6.67"OLED
	Display Resolution	2240x1080 (SPR)
Display Support	Interface	Micro USB to USB (9PIN)
	System Compatibility	Windows 10 / 11
Fan	Dimension	120 x 120 x 25 mm
	Fan Speed	PWM 500~2500 R.P.M
	Rated Voltage	12V/5V
	Rated Current	0.27 A & 0.72 A (one fan)
	Power Input	3.24 W & 3.6 W (one fan)
	Air Flow	Standard Fan Blade : 63.25 CFM (one fan) Reverse Fan Blade : 62.40CFM (one fan)
	Static Pressure	Standard Fan Blade :2.68 mm-H2O (one fan) Reverse Fan Blade : 2.31mm-H2O (one fan)
	Noise Level	Standard Fan Blade : 27.2 dB-A (one fan) Reverse Fan Blade : 29.1 dB-A (one fan)
Radiator	Dimension	396 x 120 x 27 mm
	Material	Aluminum
Tube	Length	460mm
	Material	Rubber
TDP		365W


*Requires motherboard sync for ARGB lighting effect

MAGCurve 360 Ultra ARGB CPU AIO Liquid Cooler

• Detailed Features :

- 6.67" Curved AMOLED Screen with a resolution of 2240 x 1080 pixels
- Features TOUGHFAN EX ARGB Sync with Magforce 2.0 Quick Connection Design
- High-Efficiency Pump with Powerful Cooling Performance
- Supports Real-Time System Information Display and JPG, GIF, PNG, MP4, AVI, MOV file types
- Controlled by TT RGB PLUS 3.0 and TT PlayLink app

• Appearance

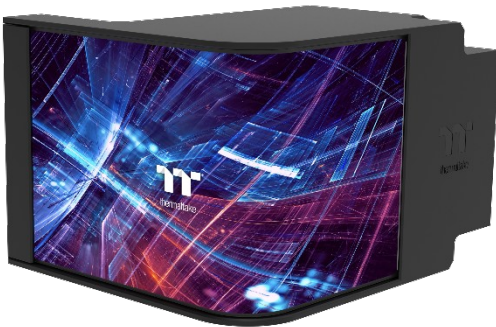


6.67" OLED
Monitor Water Block Design

Built-in 6.67" OLED display



Temperature

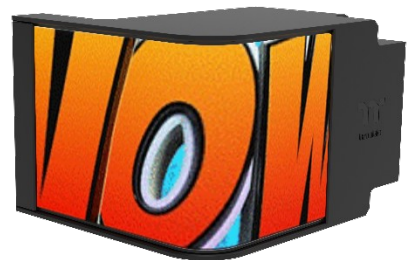


JPG, GIF, PNG, MP4,
AVI, MOV


MAGCurve 360 Ultra ARGB CPU AIO Liquid Cooler

- **Appearance**

Black

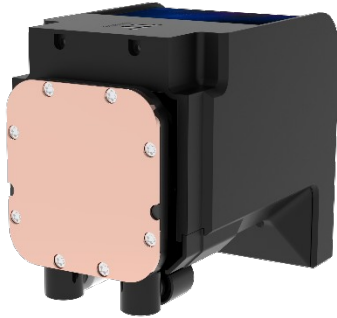

High Performance
Water Block

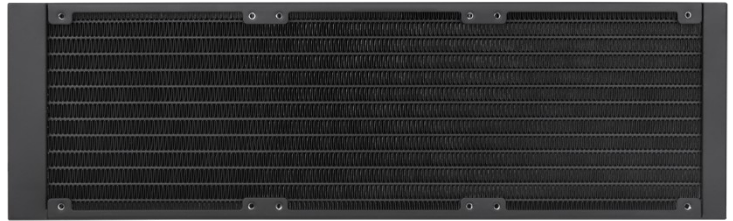

High Efficiency Radiator




MAGForce 2.0 Cable




Powerful Cooling Fan

- **Airflow Direction**

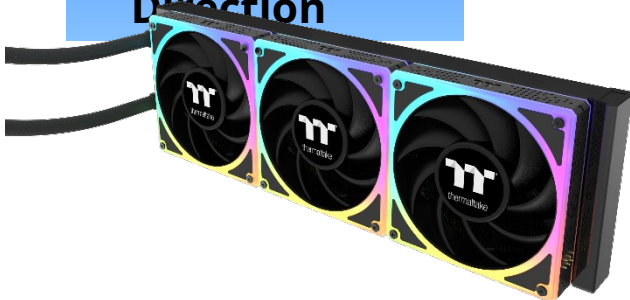

Standard Fan Blade
Air Exhaust

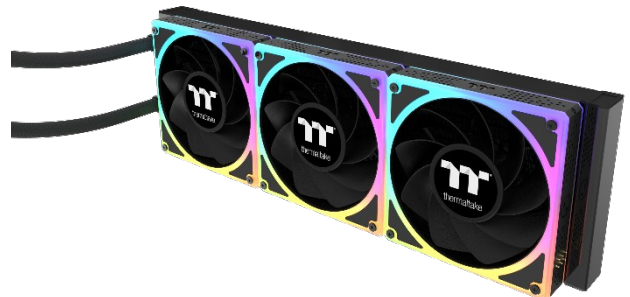


Reverse Fan Blade
Air Intake


MAGCurve 360 Ultra ARGB CPU AIO Liquid Cooler

- **Appearance**

Snow Edition

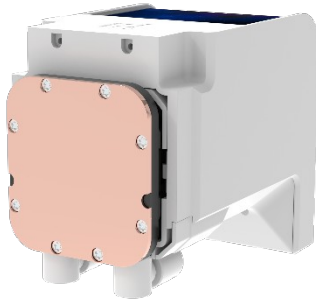

High Performance
Water Block

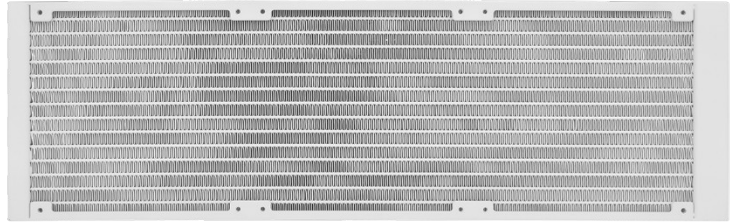

High Efficiency Radiator




MAGForce 2.0 Cable




Powerful Cooling Fan

- **Airflow Direction**

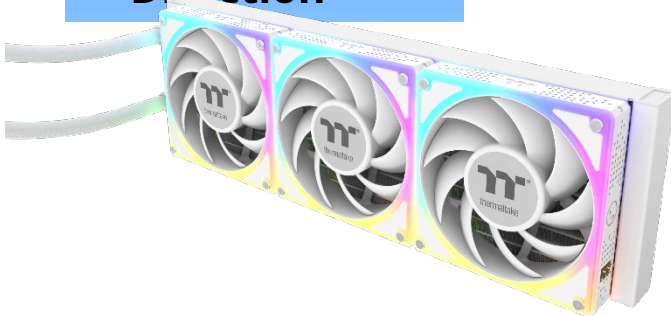

Standard Fan Blade
Air Exhaust

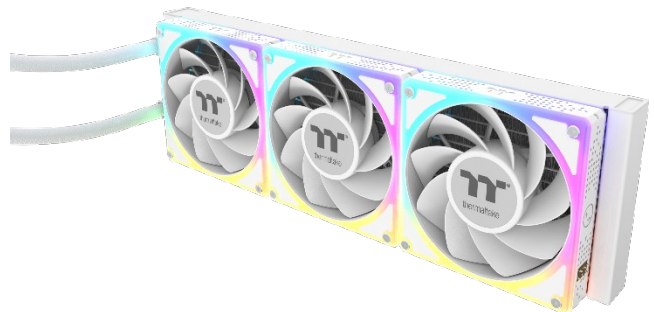

Reverse Fan Blade
Air Intake

MAGCurve 360 Ultra ARGB CPU AIO Liquid Cooler

-

**Appearan
ce**

Black



**TOUGHFAN EX ARGB
Sync**

MAGForce 2.0 Connection




Application

MAGCurve 360 Ultra ARGB CPU AIO Liquid Cooler

-

**Appearan
ce**

Snow Editon

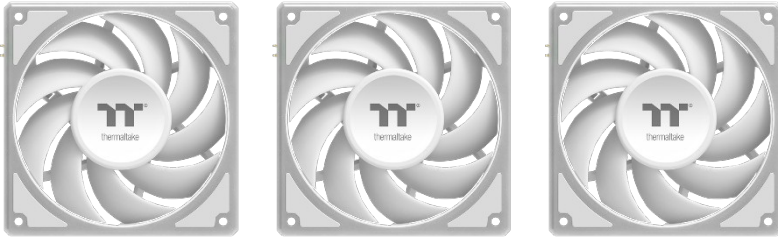

**TOUGHFAN EX ARGB
Sync**


MAGForce 2.0 Connection



Application

- **Appearance**

Support LGA1851
Support AM5

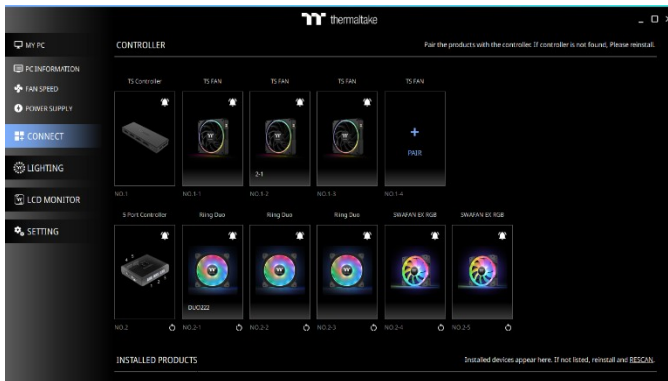

Digitally controlled with
RGB software

MAGCurve 360 Ultra ARGB CPU AIO Liquid Cooler

P/N: CL-W453-PL12SW-A CL-W454-PL12SW-A

MAGCurve 360 Ultra **ARGB** CPU AIO Liquid Cooler

Release the full CPU Horsepower



TT thermaltake

***Requires motherboard sync for ARGB lighting effect**