


PreDatasheet

- **Style: Simple**
- **Size: Mini Case supports up to Mini ITX MB**
- **Material: Steel Material & Wood**

Main Features

- **Connection:** Front I/O ports with 2 x USB 3.0 & 1 x USB 3.2 (Gen 2) Type C
- **Ventilation:** Supports 2 x 120/140mm fan (Non- Preinstalled)
- **Support:** 280mm AIO cooling solutions & 3.9" LCD Screen Kit (AC-073-001NAN-A1)

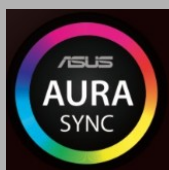

Specification

Model	TR100 WS Matcha Green
P/N	CA-11A-00SENN-WS
Color	Matcha Green
Case Type	Mini Case
Chassis Dimension (H*W*D)	294.3 x 179 x 396.5 mm (11.59 x 7.05 x 15.61inch)
Side Panel	Steel
Material	SPCC
Cooling System	-
Drive Bays	2 x 2.5" or 1 x 2.5"
Expansion Slots	3
Motherboards	6.7" x 6.7" (Mini ITX)
I/O Port	USB 3.2 (Gen 2) Type-C x 1, USB 3.0 x 2, HD Audio x 1
PSU	SFX / SFX-L (optional)
Fan Support	Top: 2 x 120mm, 1 x 120mm 2 x 140mm, 1 x 140mm
Radiator Support	Top Side(AIO): 1 x 240mm, 1 x 120mm 1 x 280mm, 1 x 140mm
Clearance	CPU cooler height limitation: 68mm VGA length limitation: 360mm VGA Width limitation: 70mm PSU length limitation: 130mm

Packaging

Package Information	TR100 WS Matcha Green
P/N	CA-11A-00SENN-WS
EAN Code	4711658546180
UPC Code	840480306182
N.W	4.05 kg / 8.93 lbs.
G.W	4.85 kg / 10.70 lbs.
Carton Size (L x W x H)	436 x 239 x 358 mm / 17.17 x 9.41 x 14.10 inch
Cuft	1.32
Container	w/o pallet
20'	749 pcs
40'	1553 pcs
40' HQ	1812 pcs

Appearance – Matcha Green version

Angle view

Left Side view

Front view

Right Side view

Internal Structure

Internal Structure

Rear view


Top view

Bottom view

Exploded View

Compatibility List

Fan Compatibility List			
	120mm	140mm	200mm
Front	-	-	-
Top	2	2	-
Rear	-	-	-

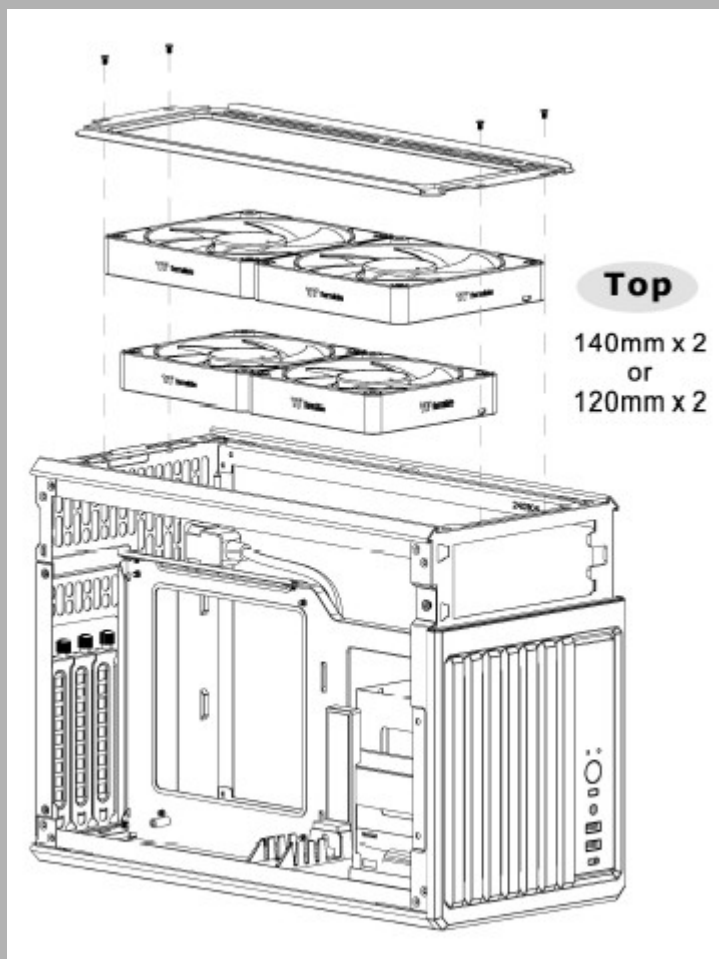

All-in-One Compatibility

All-in-One Compatibility List						
	120mm	240mm	360mm	140mm	280mm	420mm
Front	-	-	-	-	-	-
Top	●	●	-	●	●	-
Rear	-	-	-	-	-	-

