



A

User manual
Benutzerhandbuch
Notice d'emploi
Manual de usuário
Manual do usuário
Manuale d'uso




Signify
I.B.R.S. / C.C.R.I. Numéro 10461
5600 VB Eindhoven,
the Netherlands
00800-74454775
© 2025 Signify Holding
All rights reserved
Last update: 03/2025

www.philips-hue.com
442296691711



Incl.

A

B



7 m



14 m



21 m



EU



CH

 


UK



ANZ

Excl.



≤ Ø3,5 mm



2

B



EU

CH

UK

ANZ

IP44


IP55

IP20

IP20

IP65

 Model ID: A




1



2

A

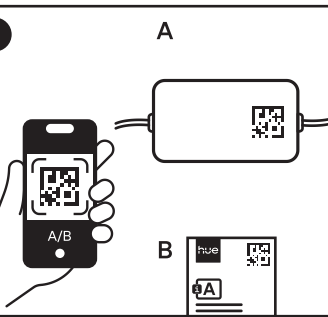

B




!



www.philips-hue.com

!

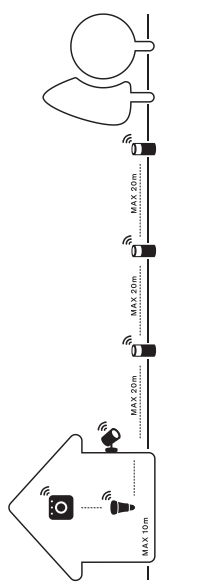


MAX 20m

MAX 20m

MAX 10m

!

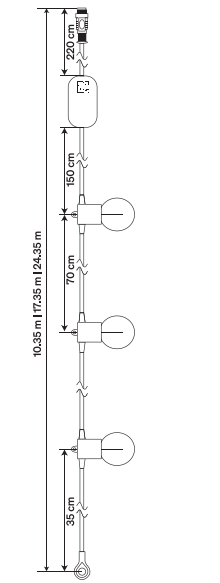

10,35 m 17,35 m 24,35 m


220 cm

150 cm

70 cm


35 cm

3a

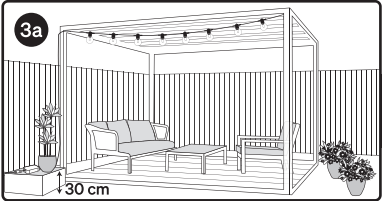

30 cm


!

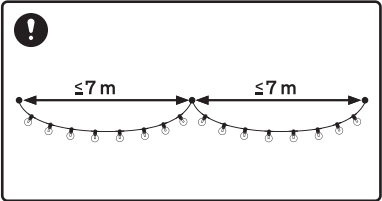

≤ 7 m

≤ 7 m


4

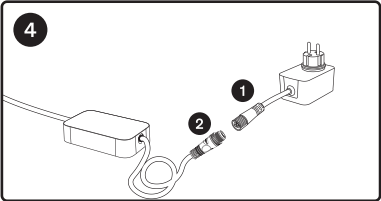

1

2

5

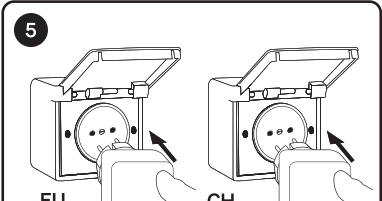

EU


CH

UK

ANZ

!

Compatible with outdoor
Hue Low-volt system

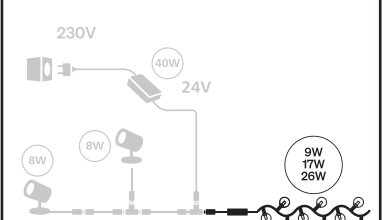

230V

24V

9W 17W 26W


8W

8W

9W 17W 26W

!

Use maximum of 10 m extension
cable for Festavia

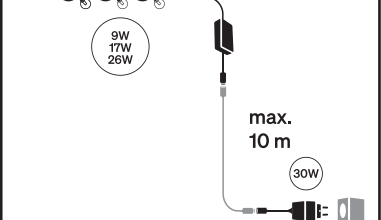


max.
10 m

24V

230V


!

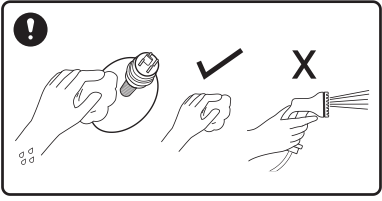


✓

X

3

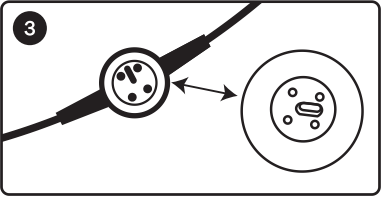


3b

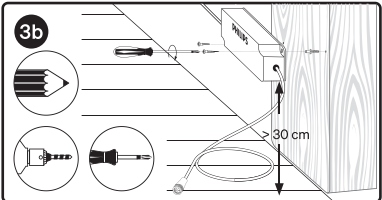


30 cm

!

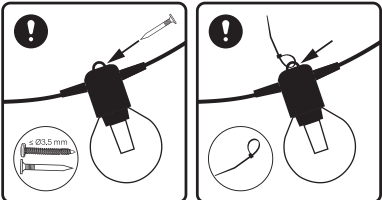

≤ Ø3,5 mm


!

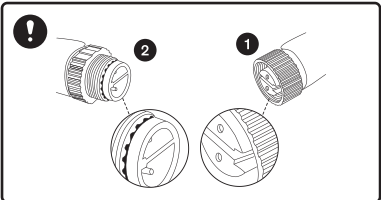

2

1

5

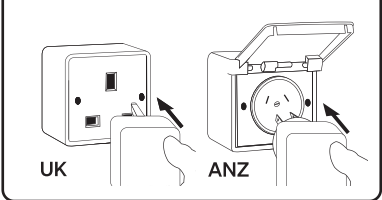

UK

ANZ

!

Sample set up, add up the wattage of the lights:


8W + 8W + 9W 17W 26W ≤ 40W

!

Sample set up, add up the wattage of the lights:


9W 17W 26W ≤ 30W

!

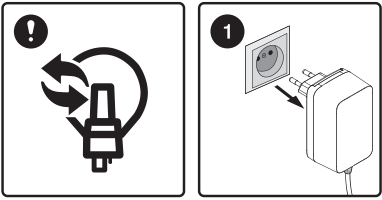

Model ID: A


4

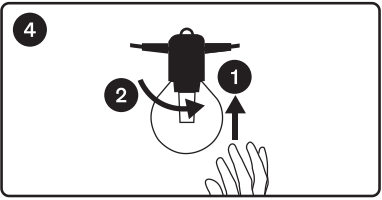

1


2

!

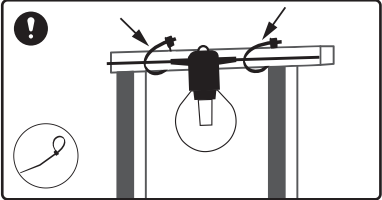

30 cm

!

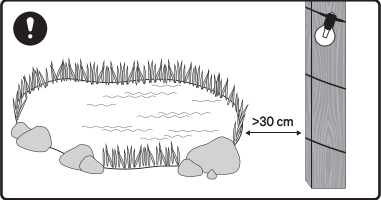


> 30 cm


!



!

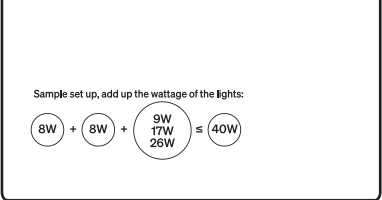

!

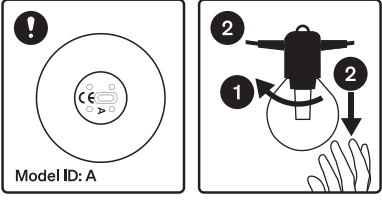

2

1

2

5

