


Samsung Galaxy Watch 8 Classic 3,3 cm (1.3") AMOLED 46 mm
Digital 438 x 438 Pixel Touchscreen Silber WLAN GPS

Marke : Samsung Artikel-Code: SM-L500NZWAEUE

Produktname : Galaxy Watch 8 Classic

Galaxy Watch 8 Classic, Bluetooth, 46mm
Samsung Galaxy Watch 8 Classic. Bildschirmdiagonale: 3,3 cm (1.3"), Bildschirmtechnologie: AMOLED, Display-Auflösung: 438 x 438 Pixel, Touchscreen. RAM-Kapazität: 2000 MB, Flash-Speicher: 64 GB. WLAN. GPS. Akku-/Batteriekapazität: 445 mAh. Gewicht: 63,5 g. Armbandfarbe: Weiß. Installiertes Betriebssystem: Wear OS

Bildschirm		Merkmale	
Bildschirmdiagonale *	3,3 cm (1.3")	Herzfrequenzmonitor *	✓
Bildschirmtechnologie *	AMOLED	Herzfrequenzsensortyp	Optisch
Marketingname Displaytechnologie	Super AMOLED	Beschleunigungsmesser	✓
Helligkeit	600 cd/m²	Gyroskop	✓
Pixeldichte	327 ppi	Aktivitäts-Tracker	✓
Immer eingeschaltetes Display	✓	Schlafqualität	✓
Farbdisplay	✓	Unterstützte Audioformate	3GA, AAC, AMR, AWB, M4A, MP3, OGA, OGG, WAV
Display-Typ *	Digital	Virtueller Assistent	Samsung Bixby
Display-Auflösung *	438 x 438 Pixel	Geomagnetischer Sensor	✓
Touchscreen *	✓	Kalender	✓
Anzahl der Farben des Displays	16 Millionen Farben	Barometer	✓
Prozessor		Militärstandard	MIL-STD-810H
Prozessorhersteller	Samsung	Netzwerk	
Prozessor	Exynos W1000	Mobile Netzwerkverbindung *	✗
Anzahl Prozessorkerne	5	GPS	✓
Design		BeiDou	✓
Form *	Rund	GLONASS	✓
Marktpositionierung *	Smartwatch	Galileo	✓
Größe des Uhrengehäuses *	46 mm	Anschlüsse und Schnittstellen	
Schnallenfarbe	Silber	WLAN-Standards	802.11a, 802.11b, 802.11g, Wi-Fi 4 (802.11n)
Hinter Material	Saphirglas	Bluetooth	✓
Farbe des Uhrengehäuses *	Silber	Nahfeldkommunikation (NFC) *	✓
Material des Uhrengehäuses *	Aluminium	WLAN *	✓
Armbandfarbe *	Weiß	Bluetooth-Version *	5.3
Verschlussart	Einzinken-Gurtschnalle	Energie	
Internationale Schutzart (IP-Code)	IP68	Akku-/Batterietyp *	Integrierte Batterie
Wasserbeständigkeit	5 ATM	Akku-/Batteriekapazität *	445 mAh
Leistungen		Akku-/Batteriebetriebsdauer *	40 h
Installiertes Betriebssystem	Wear OS	Kabelloses Aufladen	✓
RAM-Kapazität	2000 MB	Ladezeit	1,3 h
Flash-Speicher	64 GB	Software	
Eingebautes Mikrofon *	✓	Apps für Sportaktivitäten	Samsung Health
Eingebaute Lautsprecher *	✓	Gewicht und Abmessungen	
		Breite	46,4 mm
		Tiefe	46 mm
		Dicke	1,06 cm
		Gewicht	63,5 g

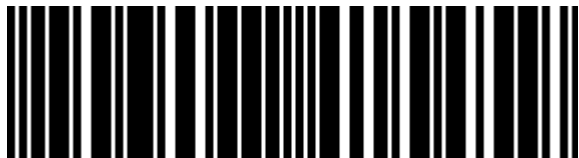

8806097415459

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.