

2104 : Copper Tube Cutter 6-28 mm

Description



Max thickness: 2 mm.

Soft Touch® non-slip knob : good hold in hand.

Quick and tool-less wheel change.

Equipped with a fold-away reamer blade.

Grooved rollers for cutting tight up against flanges.

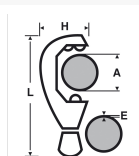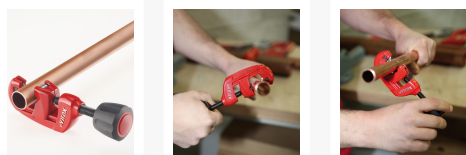

References

SKU	A mm	A " OD	L mm	H mm	E maxi mm	kg
210441	6 - 28	1/4 - 1.1/8	142	55	2	0,385

