


## 2104 : Stainless Steel Pipe Cutter 6-28 mm

### Description

**Max thickness: 3.2 mm.**

Soft Touch® non-slip knob: good hold in hand.

Quick and tool-less wheel change.

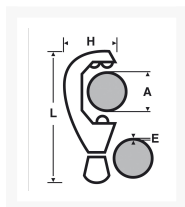

### References

| Sku    | A mm   | A " OD      | L mm | H mm | E maxi mm | kg    |
|--------|--------|-------------|------|------|-----------|-------|
| 210469 | 6 - 28 | 1/4 - 1.1/8 | 142  | 55   | 3,2       | 0,385 |

