

2104 : ZR 35 Stainless Steel Pipe-Cutter 3-35 mm



The + product :

Soft Touch® non-slip knob, fast action adjustment.

Quick, tool-less wheel change.

4 guide rollers to prevent wheel tracking.

Description


Max thickness: 3.2 mm .

Precise cutting from Ø 3 to Ø 35 mm according to the type of tube.

1 spare wheel.

Retractable rotating reamer with interchangeable blades.

Colour-coded end cap according to the material to be cut.

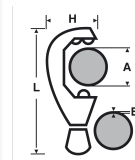

References

Sku	A mm	A " OD	L mm	H mm	E maxi mm	kg
210471	3 - 35	1/8 - 1.3/8	165	64	3,2	0,450

