


2511 : Bending Pliers

Description

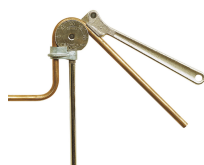

For hardened and annealed copper pipes: Ø 6 to 18 mm and Ø 1/4" to 5/8" O.D. / wall thickness 1 to 1.2 mm.

Bending radius: 2 to 3.5 D.

For forming very short radius bends and counter-bends.

Bending angle: up to 180°.

0 to 180° graduations.

Steel handle and body. Machined groove.

References

Sku	Pipe O.D.	Bending radius mm	kg
251106	6	11	0,310
251108	8	14	0,355
251110	10	23	0,850
251112	12	30	1,000
251114	14	42	2,100
251115	15	42	2,100
251116	16	54	2,740
251118	18	55	3,000

Sku	Pipe O.D.	Bending radius mm	kg
251121	1/4	15	0,355
251122	5/16	25	0,500
251123	3/8	35	1,015
251124	1/2	45	2,100
251125	5/8	54	2,700

