



Canon AS-120 II Taschenrechner Desktop Display-Rechner Schwarz

Marke : Canon


Artikel-Code: 4722C002

Produktname : AS-120 II

- Zwölfstelliger Tischrechner
- Elegantes Design und großes angewinkeltes LC-Display
- Duale Stromversorgung (Batterie und Solar)
- Mark-up-, Rückwärts- und Endsummenspeicher-Funktionen
- 12-stelligen, LC-Display, Batterie und Solar, 1x LR44 Batterie

Canon AS-120 II Taschenrechner Desktop Display-Rechner Schwarz:

Der AS-120 II ist ein Tischrechner mit einem 12-stelligen angewinkelten Display. Er unterstützt auch Markup- und Rückwärts-Funktionen. Die beeindruckende Gesamtsummenspeicher-Funktion erleichtert komplexe Berechnungen, indem sie die Zwischensummen nach jeder Berechnung speichert und die Gesamtsummen mit einem einzigen Tastendruck berechnet. Einige Teile des AS-120 II Rechners wurden aus recyceltem Material von Canon-Produkten hergestellt.
Canon AS-120 II. Formfaktor: Desktop, Typ: Display-Rechner. Stellen: 12 Ziffern, Display klappbar. Steuerberechnung. Energiequelle: Batterie/Solar. Produktfarbe: Schwarz

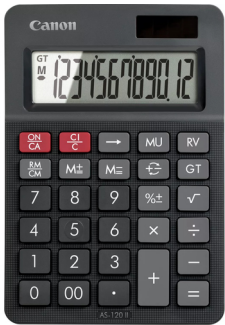

Design		Bildschirm	
Formfaktor *	Desktop	Stellen *	12 Ziffern
Typ *	Display-Rechner	Energie	
Produktfarbe *	Schwarz	Energiequelle *	Batterie/Solar
Gehäusematerial	Recyclbarer Kunststoff	Akku-/Batterietyp	LR44
Abdeckung *	✗	Automatische Abschaltung	✓
Steuerung	Tasten	Automatische Abschaltung nach	8 min
Leistungen		Gewicht und Abmessungen	
Steuerberechnung	✓	Breite	144 mm
Symbolische Schreibweise	Quadratwurzel	Tiefe	100 mm
Konvertierung zwischen	Dezimal, Prozent	Höhe	29 mm
Bildschirm		Gewicht	104 g
Display-Typ *	LCD	Lieferumfang	
Display klappbar *	✓	Betriebsanleitung	✓
Anzeigegerät	18,5 x 4,8 mm		



4549292108538

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.