

PATH TO THE FUTURE


Ob alltägliche Aufgaben oder Multitasking – die PRO DP80 Serie bietet zuverlässige Leistung in einem stilvollen, kompakten Design. Mit einem Core™ Prozessor von Intel® und DDR5-Arbeitsspeicher wird eine schnelle und effiziente Leistung auch bei anspruchsvollen Business-Aufgaben gewährleistet. Durch die Verwendung von umweltfreundlichen Materialien wie PCR-Kunststoff (Post-Consumer Recycled) sorgt MSI nicht nur für die Robustheit der Produkte, sondern leistet außerdem einen Beitrag zu einer grüneren Welt.



Picture and logos

SELLING POINTS

- Windows 11 Home - MSI empfiehlt Windows 11 Pro für Unternehmen.
- Bis zu Intel® Core™ i7 Prozessor 14700
- Optional mit NVIDIA GeForce RTX™ Grafikkarte
- Microsoft Copilot macht dich sofort produktiver
- Dual-Channel-DDR5-U-DIMMs des Arbeitsspeichers
- Wi-Fi 7 mit effizientem AI-Workload-Management
- Dual LAN Design (2.5G & 1G LAN)
- Integrierter Kartenleser für optimale Kompatibilität und Komfort
- Gehäuse-Einbruchserkennung, um unbefugten Zugriff zu verhindern
- Inspiriert von Militärstandards getestet für dauerhafte Robustheit und Leistung
- Hergestellt aus PCR-recyceltem Kunststoff; FSC™-zertifizierter Karton; Weniger Abfall dank recycelter Formmasse (100 % recycelbar); In der Fabrik zu 99 % mit erneuerbarer Energie produziert

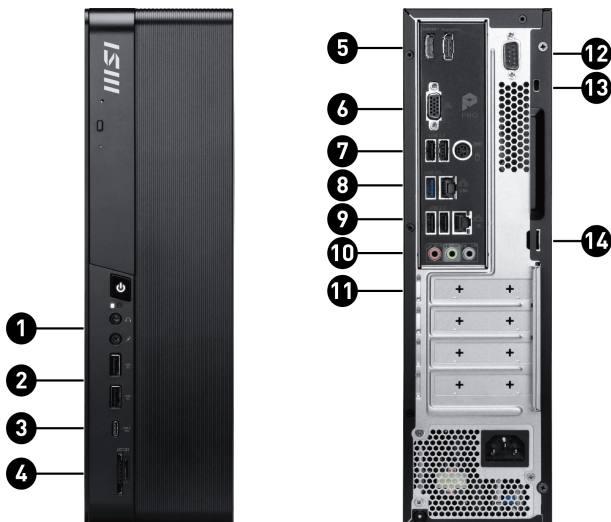

1. 1x Kopfhörerausgang ; 1x Mikrofoneingang
2. 2x USB 5Gbps Typ-A
3. 1x USB 10Gbps Typ-C
4. 1x Kartenleser (unterstützt SD & Micro SD Karten)
5. 1x HDMI ; 1x DisplayPort (1.4)
6. 1x VGA
7. 2x USB 2.0 Typ-A ; 1x PS/2
8. 1x USB 5Gbps Typ-A ; 1x RJ45 LAN (2.5G)
9. 2x USB 2.0 Typ-A ; 1x RJ45 LAN (1G)
10. 3x Audioanschlüsse
11. 1x Grafikkarte (*optional je nach Modell)
12. 1x COM Anschluss
13. 1x Kensington Lock
14. 1x Padlock

SPECIFICATION

Betriebssystem	Betriebssystem	N/A
Prozessor	CPU Number	Intel Core i3 Processor 14100
	CPU Clock	3.5GHz
	CPU Cores	4
	TDP	60W
	Cache	12 MB Intel® Smart Cache
	Threads	8
	Max Turbo Frequency	up to 4.70 GHz
	CPU Cooler	Air cooling 65W
Chipsatz	Chipsets	H610
Grafik	GPU1 VRAM Size	N/A
	VGA I/O Port	N/A
	GPU1 Vendor	N/A
	GPU1 MKT Name	N/A
Arbeitsspeicher	Memory Size	16GB(16GB*1)
	Memory Type	DDR5 SDRAM
	Module Type	U-DIMM
	Memory Slot (Total/Free)	2/1
	Max Capacity	Max 64GB
Speicher	SSD Interface	PCIe GEN4x4
	SSD Form Factor	M.2-2280 M-KEY
	SSD Config	256GB*1
	SSD Size	256GB
	HDD1 Interface	N/A
	HDD1 Form Factor	N/A
	HDD1 Size	N/A
	HDD1 RPM	N/A
	ODD(Type)	N/A
	ODD Height	N/A
	ODD Type	N/A
	M.2 slots (Total/Free)	1/0
	2.5" Drive Bays (Total/Free)	1/1
	3.5" Drive Bays (Total/Free)	1/1
Audio	Audio Chipset	Realtek ALC897
	Audio Type	7.1 Channel HD Audio
Kommunikation	LAN	1x Intel I226-V+1x Intel I219-V
	WLAN Version	Wi-Fi 6E+BT
	BT Version	5.3
	WLAN	INTEL/AX211.NG.WG.NV
Schnittstellen (Vorne)	Audio Mic-in	1
	Audio Headphone-out	1
	USB 3.2 Gen 2 (10G) Type C	1
	USB 3.2 Gen 1 (5G) Type A	2
	Card Reader	1
Schnittstellen (Rückseite)	USB 2.0 Type A (R)	4
	RJ45	2
	VGA out	1
	HDMI out	1x (v2.1)
	DP out	1x (v1.4)
	PS/2	1
	COM Port	1
	Audio jack	3x (Line in / Line out / MIC in)
	USB 3.2 Gen 1 (5G) Type A (R)	1
	Lock type	Kensington Lock, Padlock Lock
Power	Power	300W
	Power Certification	80PLUS BRONZE
	Formfactor	TFX
	Type	POWER SUPPLY

Abmessungen & Gewicht	Product Dimension (WxDxH) (mm)	95 x 296 x 330
	Product Dimension (WxDxH) (inch)	3.74 x 11.65 x 12.99
	Inside Carton Dimension (WxDxH) (mm)	N/A
	Inside Carton Dimension (WxDxH) (inch)	N/A
	Outer Carton Dimension Standard (WxDxH) (mm)	451 x 234 x 402
	Outer Carton Dimension Standard (WxDxH) (inch)	17.76 x 9.21 x 15.83
	Weight (Net kg)	4.03
	Net Weight (lbs)	8.88
	Weight (Gross kg)	6.10
	Gross Weight (lbs)	13.45
	Liter	8
	Pint	16.91
Lagerung & Zertifikationen	Operating, Storage Temperature	0° C ~ 35° C ; -20° C ~ 60° C
	Operating, Storage Humidity	0% ~ 85%;0% ~ 90%
	Regulatory Compliance	FCC(Class B), CB/CE, UL(CUL), BSMI, VCCI, RCM(C-Tick), Epeat Sliver, Energy Star, ERP lot 3, CEC
Garantie	Warranty	36months
Zubehör	Keyboard Interface	N/A
	Mouse Interface	N/A
	Power Cord	1
	AC Adaptor	N/A
	Warranty Card	N/A
	Quick Guide	3
	User Manual	N/A
	VESA Mount kit	N/A
	Keyboard	N/A
	Mouse	N/A
	Power Switch	N/A
Barcode Info	EAN	4711377412568
Model	Part No	9S6-B20821-204
	MKT Name	PRO DP80 A14G
	MKT Spec	PRO DP80 A14G-204XDE
	Color	ID1/Black-Black-Black
	Model	B208
Security	TPM module	N/A
	Chassis Lock	N/A
	Chassis Intrusion	N/A