


DAMPPROOF 5X THROUGHWIRING IP65


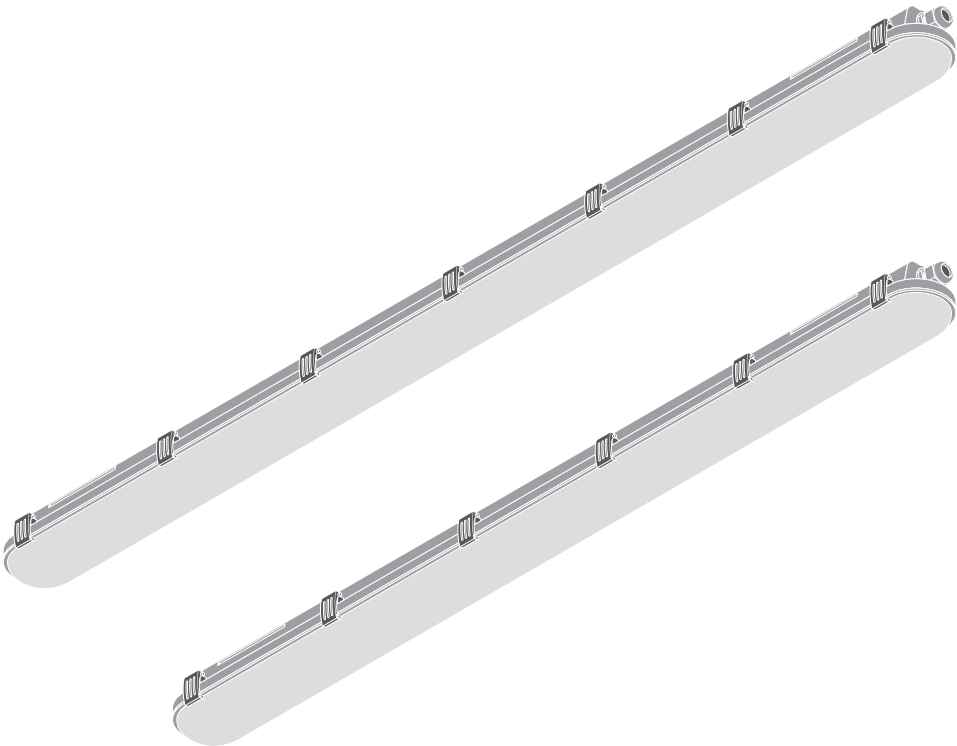


	EAN	I x w x h [mm]	W	VAC	Hz	lm	lm/W	K
DP 5TH 1200 32W 840 IP65 GY	4058075541924	1200 x 82 x 68	32	220-240 V	50/60 Hz	4400	135	4000
DP 5TH 1500 46W 840 IP65 GY	4058075541948	1500 x 82 x 68	46	220-240 V	50/60 Hz	6400	135	4000
DP 5TH 1500 58W 840 IP65 GY	4099854312465	1500 x 82 x 68	58	220-240 V	50/60 Hz	8000	135	4000
DP 5TH 1500 81W 840 IP65 GY	4099854312489	1500 x 82 x 68	81*	220-240 V	50/60 Hz	11000*	135*	4000

	EAN	IP	IK		Ra	 (°C)	PF	
DP 5TH 1200 32W 840 IP65 GY	4058075541924	65	08	110	> 80	-25...+40	> 0.9	1.6 kg
DP 5TH 1500 46W 840 IP65 GY	4058075541948	65	08	110	> 80	-25...+40	> 0.9	1.9 kg
DP 5TH 1500 58W 840 IP65 GY	4099854312465	65	08	110	> 80	-25...+40	> 0.9	1.9 kg
DP 5TH 1500 81W 840 IP65 GY	4099854312489	65	08	110	> 80	-25...+40	> 0.9	1.9 kg




DAMPPROOF 5X THROUGHWIRING IP65

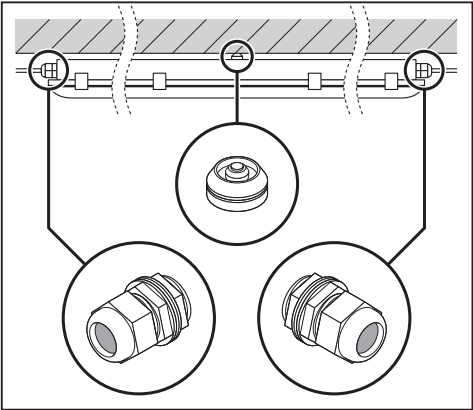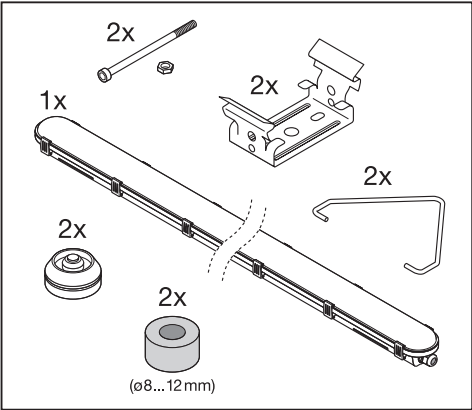

1x DAMPPROOF 5TH IP65 2x DAMPPROOF 5TH IP65 3x DAMPPROOF 5TH IP65 ... nx DAMPPROOF 5TH IP65









n	B16	C10	C16
DP 5TH 1200 32W	27	24	39
DP 5TH 1500 46W	26	23	37
DP 5TH 1500 58W	26	23	38
DP 5TH 1500 81W	13	16	26







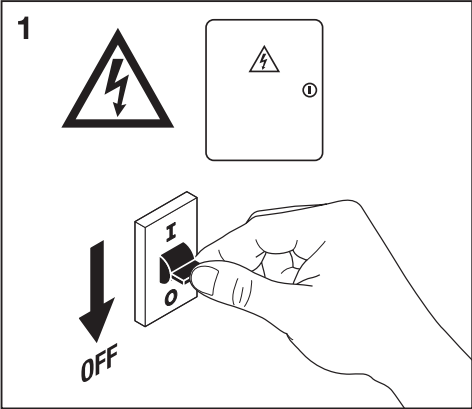


2

[mm]	X	Y
DP 1200	27 ± 1	850 ± 100
DP 1500	27 ± 1	1120 ± 100

DAMPPROOF 5X THROUGHWIRING IP65

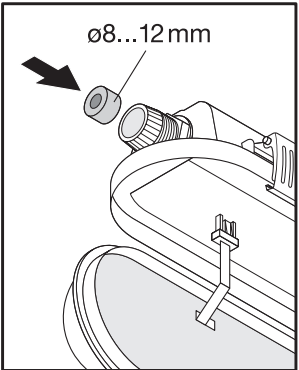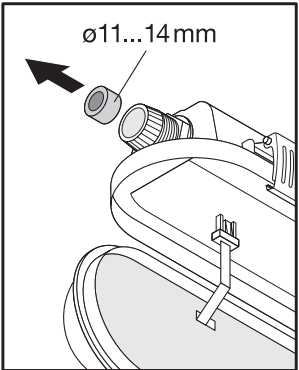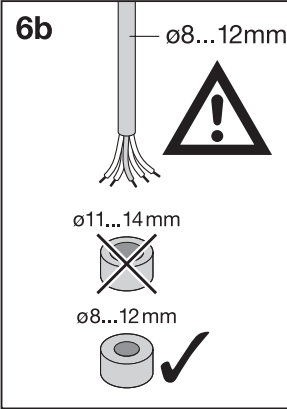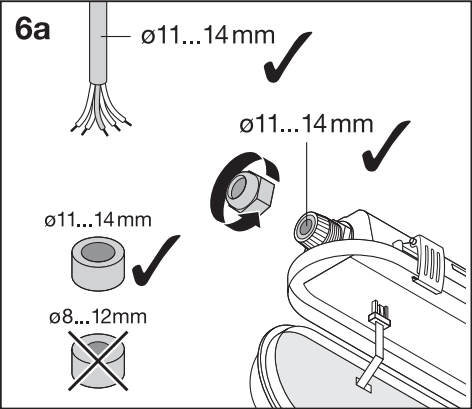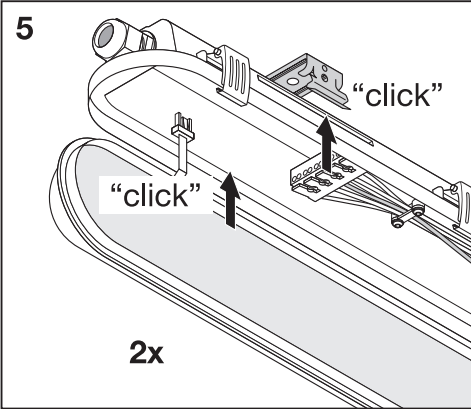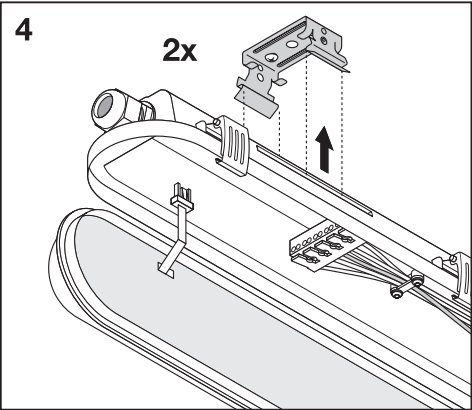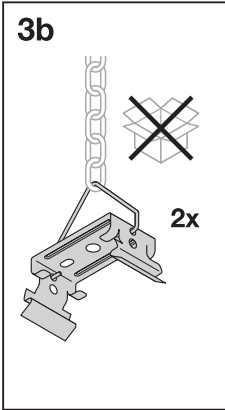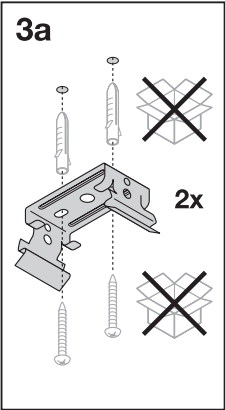

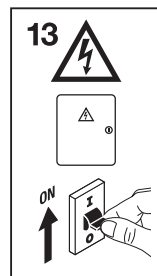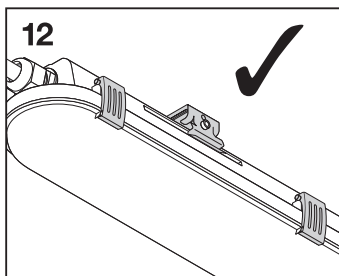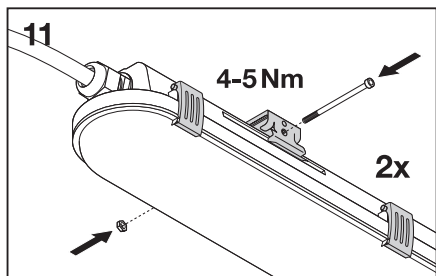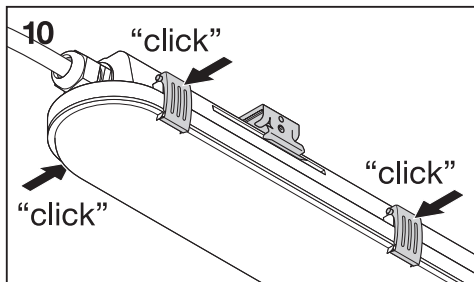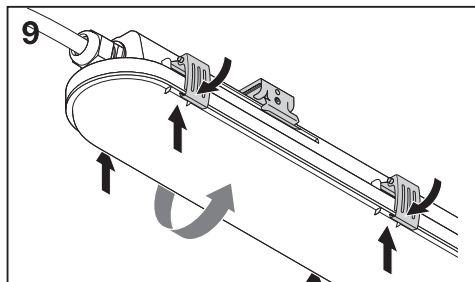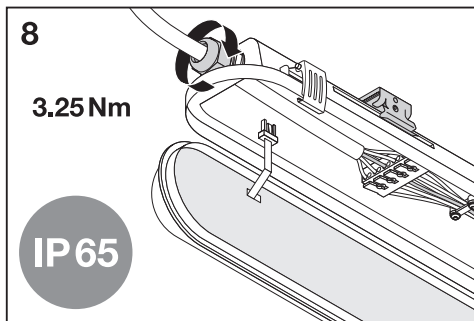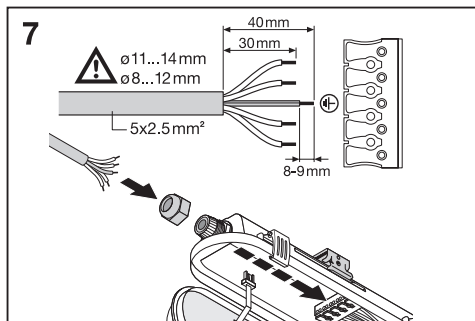

DP 5TH 1500 81W 840 IP65 GY		PIN1	PIN2	W	Im	Im/W	Input current driver [mA]	Output current [mA]
230V		ON ↔ OFF	ON ↔ OFF					
		ON	ON	81	11000	135	390	350
		ON	OFF	69	9600	139	340	300
		OFF	ON	57	8200	143	280	250
		OFF	OFF	46	6600	143	230	200



LEDVANCE GmbH
Steinerne Furt 62
86167 Augsburg, Germany
www.ledvance.com

© LEDVANCE Ltd, Sterling House,
810 Mandarin Court, Warrington,
Cheshire, WA1 1GG, United Kingdom

C10449057
G11140181
13.05.24