

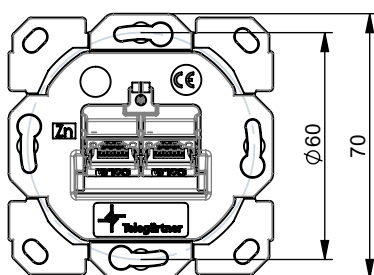
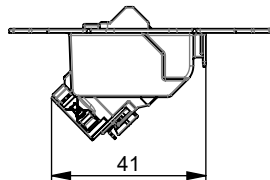



Module carrier AMJ-SL incl. AMJ-SL Module Cat.6_A T568

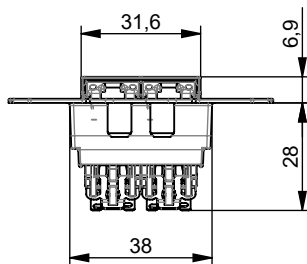


Double gang module carrier UP/0 flex

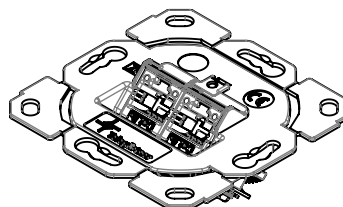


Anschlussbelegung / PIN assignment T568A
nach / according to TIA-568.2-D

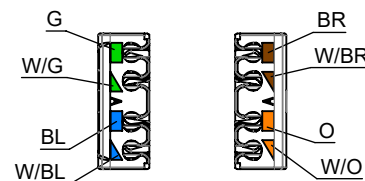

Anschlussbelegung / PIN assignment T568B
nach / according to TIA-568.2-D

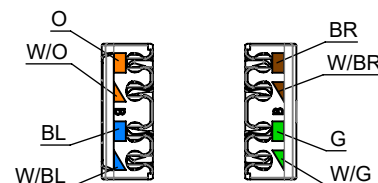

Single gang module carrier UP/0 flex

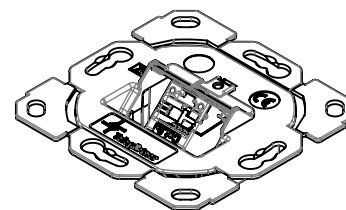

Bestell-Nr. Order no	Bezeichnung Description	Barcode EAN 13	VPE PU
J00020A0528	Modulaufnahme AMJ-SL 2-fach UP/0 flex inkl. 2 AMJ-SL Module Cat.6 _A T568A Double gang module carrier AMJ-SL UP/0 flex inkl. 2 AMJ-SL Module Cat.6 _A T568A	4018359562038	1
J00020A0529	Modulaufnahme AMJ-SL 2-fach UP/0 flex inkl. 2 AMJ-SL Module Cat.6 _A T568B Double gang module carrier AMJ-SL UP/0 flex inkl. 2 AMJ-SL Module Cat.6 _A T568B	4018359562045	1
J00020A0530	Modulaufnahme AMJ-SL 1-fach UP/0 flex inkl. 1 AMJ-SL Modul Cat.6 _A T568A Single gang module carrier AMJ-SL UP/0 flex inkl. 1 AMJ-SL Module Cat.6 _A T568A	4018359562052	1
J00020A0531	Modulaufnahme AMJ-SL 1-fach UP/0 flex inkl. 1 AMJ-SL Modul Cat.6 _A T568B Single gang module carrier AMJ-SL UP/0 flex inkl. 1 AMJ-SL Module Cat.6 _A T568B	4018359562069	1

Bestell-Nr. Order no	Verpackung Packing	VPE PU	Karton Carton	UPE OPU	Karton Carton	UPE OPU	Karton Outer carton
J00020A0528	1 pcs in carton	1 pcs in carton	87x78x52 [mm]	-	-	120 cartons in outer carton	530x380x260 [mm]
J00020A0529	1 pcs in carton	1 pcs in carton	87x78x52 [mm]	-	-	120 cartons in outer carton	530x380x260 [mm]
J00020A0530	1 pcs in carton	1 pcs in carton	87x78x52 [mm]	-	-	120 cartons in outer carton	530x380x260 [mm]
J00020A0531	1 pcs in carton	1 pcs in carton	87x78x52 [mm]	-	-	120 cartons in outer carton	530x380x260 [mm]

Montageanleitung siehe: www.telegaertner.com
Mounting instructions see: www.telegaertner.com

Module carrier AMJ-SL incl. AMJ-SL Module Cat.6_A T568



Technische Daten / Technical Data		
Frontplatte-Spezifikation siehe	F00020A0113 / F00020A0123	Faceplate specification see
Steckverbinder-Spezifikation siehe	J00029A6000 / J00029A6001 J00029A6110 / J00029A6111	Connector specification see