


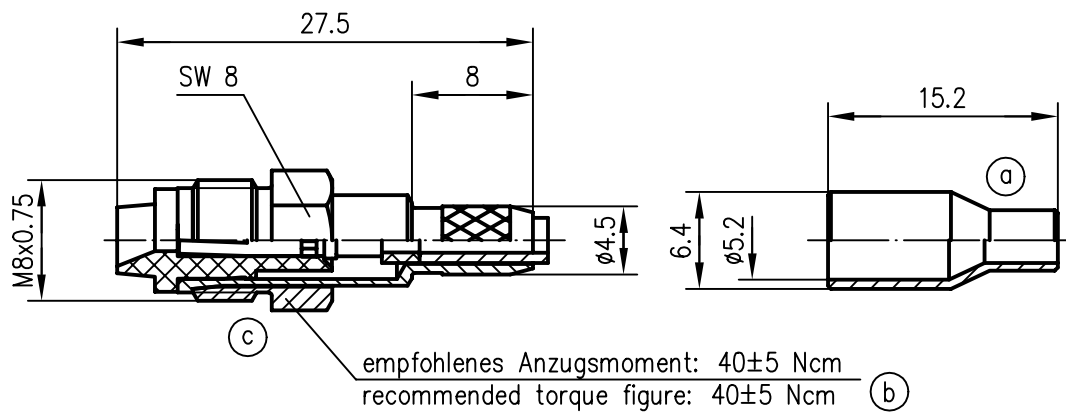

Außenleiter / outer conductor
Innenleiter / inner conductor
Isolierung / insulator
Crimprohr / crimp ferrule

CuZn39Pb3
CuPb1.15Ni1
PP, POM
CuZn38Pb1.5
Cu2Ni5
Cu2Ag5 pas.(INOVAN-SP)

Kabel / cable
Montage / assembly

RG-174/U, RG-188A/U, RG-316/U
B2005

c b a	6562 6061 5077	26.03.96 27.10.95 25.10.94	UE BJ BJ	93	Datum/date	Name/name	Werkstoff/ material	
				gez./drawn	08.06.	JB		
				gepr./appr.	14.06.93	MaH	Oberfläche/ finish	
				Norm/stand.				
				Maßstab/scale	Benennung/title			 Telegärtner
2:1	FME-Kabelbuchse FME-Straight-Jack							
untol. Maße/ dim. without tolerances according to	Unterl./doc.type	Zeichnungsnr./drawing no.		 Maße/dimensions: mm				
	K	J01701A0008						
Änd./rev. Index	Änderungsmittelteil/ revision code	Datum/ date	Name/ name	Ersatz für/ replaces	EW930026-10			Original: DIN A4