 



Data Sheet for XCell CR2032

Nominal Voltage	3 V	Dimensions (mm) 
Nominal Capacity	220 mAh	
Standard Load	15 KΩ	
Standard Current	0.2 mA	
Max. Continuous Current	3 mA	
Max Pulse Current	15 mA	
Operating Temperature	-20~60°C	
Weight	2.9 (g)	
Chemistry	Lithium / Manganese Dioxide	
UL Certification	MH10136	


A	$\Phi 17.75^{+0}_{-0.04}$
B	$\Phi 20.0^{+0}_{-0.20}$
C	$2.57^{+0.02}_{-0.02}$
D	$3.2^{+0}_{-0.2}$

Note: Capacity is obtained at standard cc load to 2.0V at 23°C.


Discharge Characteristics

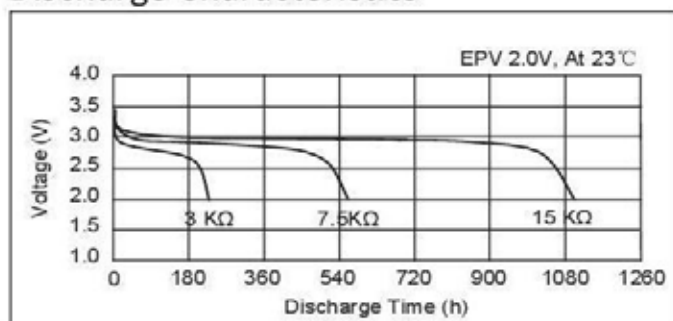

Temperature Characteristics

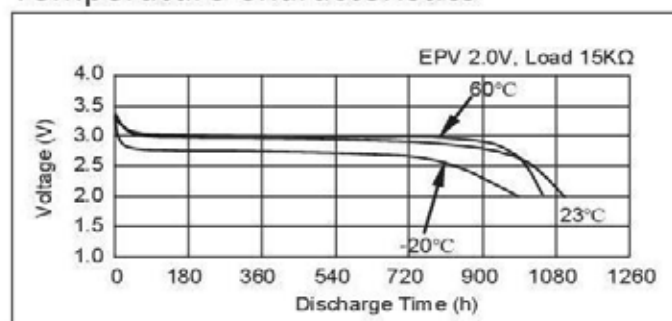

Pulse Discharge Characteristics

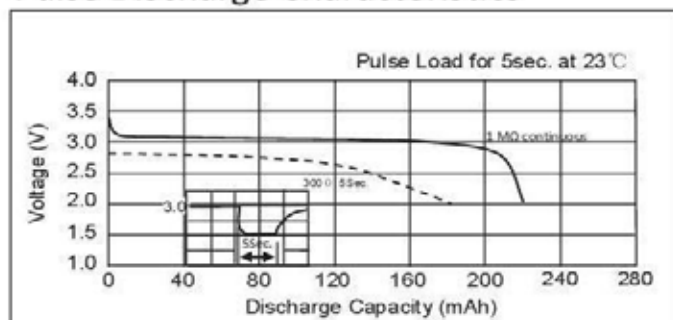

Load vs. Capacity

