 



Data Sheet for XCell CR2430

Nominal Voltage	3 V	Dimensions (mm) 
Nominal Capacity	290 mAh	
Standard Load	15 KΩ	
Standard Current	0.2 mA	
Max. Continuous Current	4 mA	
Max Pulse Current	18 mA	
Operating Temperature	-20~60°C	
Weight	4.00 (g)	
Chemistry	Lithium / Manganese Dioxide	
UL Certification	MH10136	


A	Φ21.87 ⁺⁰ _{-0.04}
B	Φ24.50 ⁺⁰ _{-0.15}
C	2.28 ⁺⁰ _{-0.05}
D	3.00 ⁺⁰ _{-0.2}

Note: Capacity is obtained at standard cc load to 2.0V at 23 °C.


Discharge Characteristics

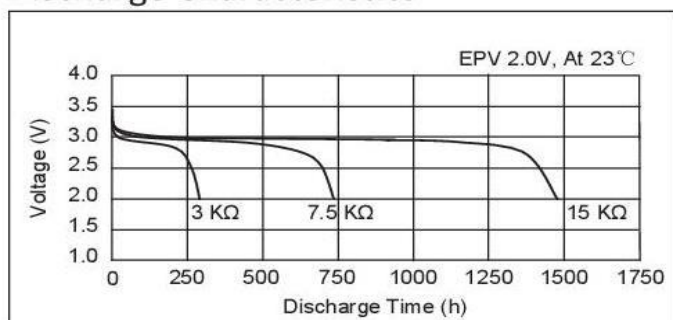


Temperature Characteristics

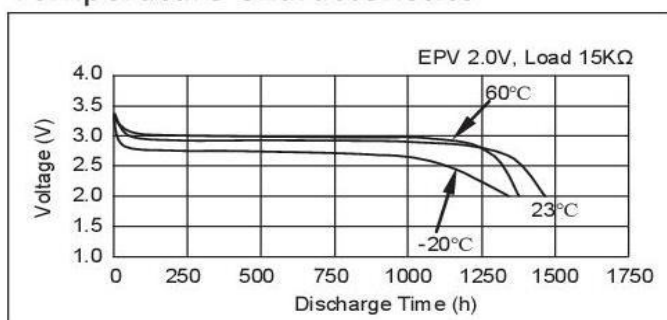

Pulse Discharge Characteristics

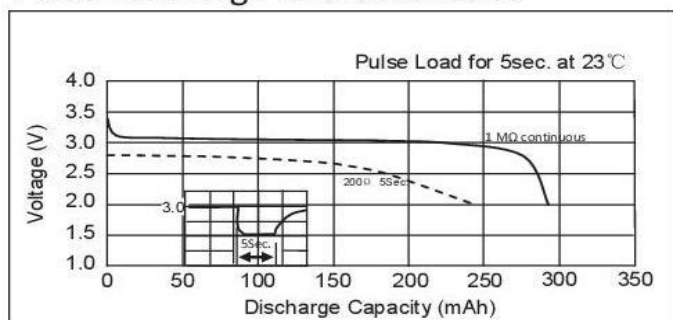

Load vs. Capacity

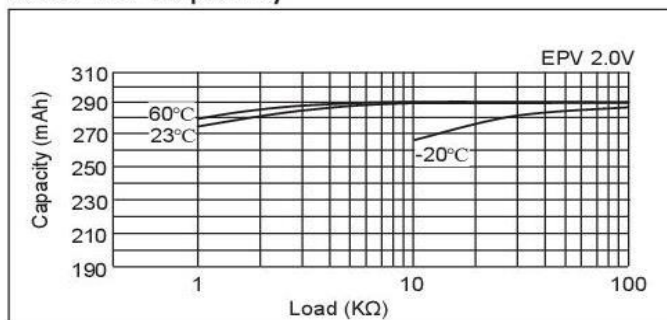

All data contained herein is for single cell and may vary for cell with specific configuration, subject to change without prior notice.