




NEEDED TO START (EXCL.)

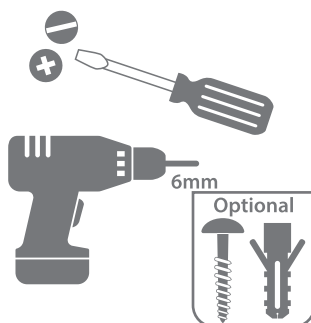


BOX CONTENT | INHALT | CONTENUS | INHOUD DOOS | CONTENUTO | CONTENIDO DE LA CAJA

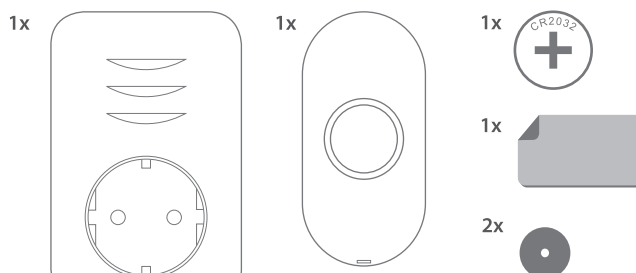


FIRST SET-UP | ERSTEINRICHTUNG | PREMIÈRE CONFIGURATION | EERSTE INSTALLATIE | PRIMO SET-UP | PRIMERA CONFIGURACIÓN

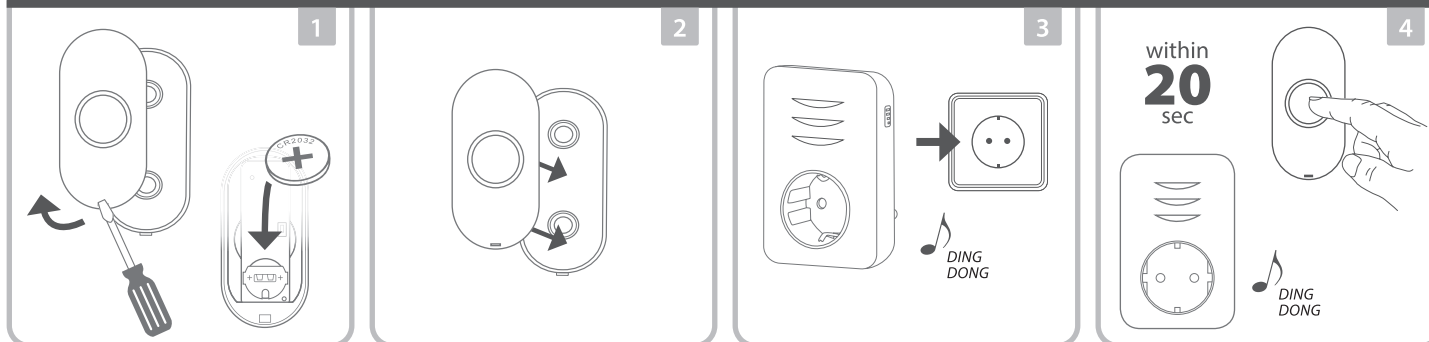

INSTALLATION | INSTALLATION | INSTALLATION | INSTALLATIE | INSTALLAZIONE | INSTALACIÓN

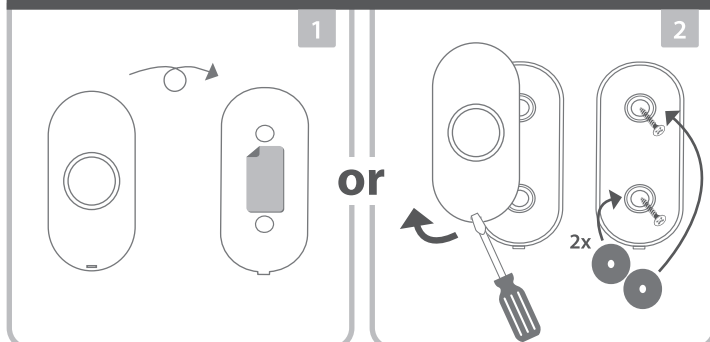


PAIRING MULTIPLE CHIMES | KOPPELN MEHRERER KLINGELN | JUMELAGE DE PLUSIEURS CARILLONS | MEERDERE DEURBELLEN KOPPELEN | ACCOPPIAMENTO MULTIPLO | EMPAREJANDO MÚLTIPLES TIMBRES

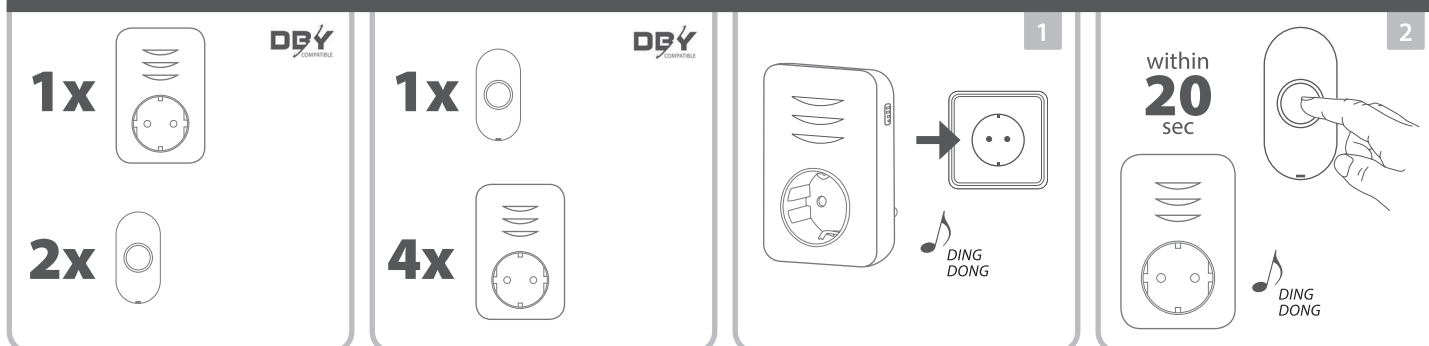


FEATURES | EIGENSCHAFTEN | CARACTÉRISTIQUES | KENMERKEN | CARATTERISTICHE | CARACTERÍSTICAS



TROUBLESHOOTING | FEHLERBEHEBUNG | RÉOLUTION DE PROBLÈMES | PROBLEMEN OPLOSSEN | RISOLUZIONE DEI PROBLEMI | SOLUCIÓN DE PROBLEMAS

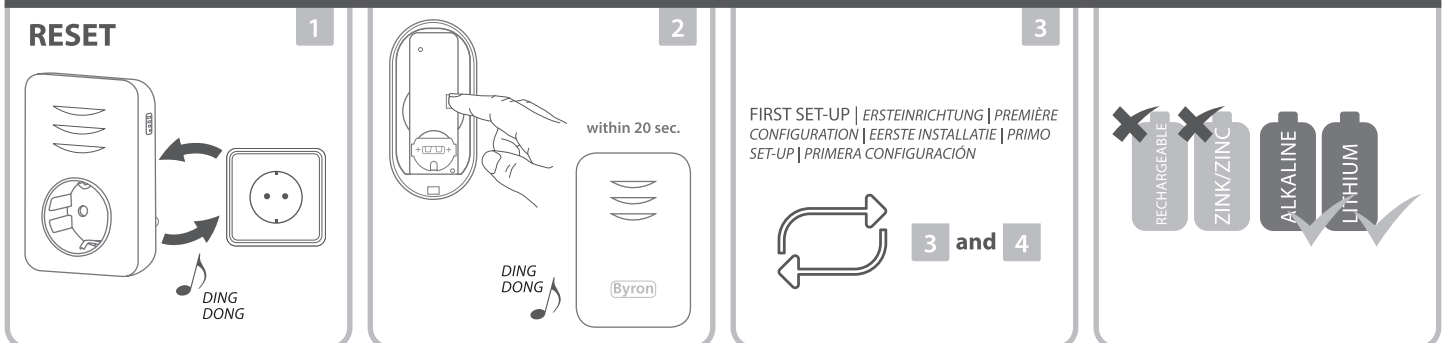

WWW.CHBYRON.EU

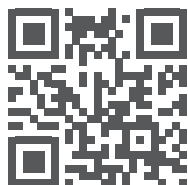

Find us on



Or contact us directly:



Conforms to all relevant European Directives.

Frequency band: 433.92MHz (433.050 - 434.790 MHz)
Maximum radio-frequency power: +5.92dB
Maximum wattage: 3680W
Range: 150 meters

Wireless Doorbell DBY-22313

Power: 220-240V~ 50 Hz
Indoor Use Only



Push button DBY-23510

Power supply: 1 x CR2032 3V
IP44 Weather Resistant

