



X3



General data

Viewing distance	21 m
Mounting	Wall, ceiling
Type	Self-contained
Mode of operation	Maintained / non-maintained
Monitoring	Manual test (MT), automatic test (AT)
Emergency duration	1/2/3/8 h (selectable)
Ambient temp.	0 °C to +40 °C

Mechanical properties

Housing material	ABS, PP
Housing colour	White, RAL 9003
Insulation class	II
IP rating	IP 54
IK rating	
Dimensions (L x W x H)	358.4 x 88.4 x 112 mm
Weight	0.46 kg


Electrical properties

Rated voltage	220-240 V AC, 50/60 Hz
Rated wattage	3.5 W (500 cd/m2), 0.5 W (50 cd/m2)
Battery	LiFePO4 3.2 V/1.5 Ah

Photometric properties

CCT	6500 K
CRI	
Luminance	500 / 50 cd/m2 (selectable)

Dimensional sketch (mm)

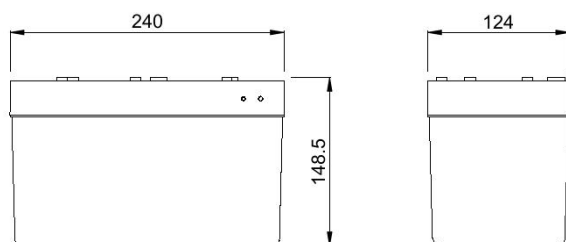

Article number	Description	Version
X3 LFP	Escape sign luminaire X3, 21 m, universal mounting, LiFePO4, 1/2/3/8 h	AT/MT

AT = automatic test

MT = manual test

Pictograms

	X3-PICTO-D	X3 Pictogram, ISO7010-E002, Exit Down
	X3-PICTO-U	X3 Pictogram, ISO7010-E002, Exit Up
	X3-PICTO-L	X3 Pictogram, ISO7010-E001, Exit Left
	X3-PICTO-R	X3 Pictogram, ISO7010-E002, Exit Right
	X3-PICTO-UR	X3 Pictogram, ISO7010-E002, Exit Up Right
	X3-PICTO-DR	X3 Pictogram, ISO7010-E002, Exit Down Right
	X3-PICTO-UL	X3 Pictogram, ISO7010-E001, Exit Up Left
	X3-PICTO-DL	X3 Pictogram, ISO7010-E001, Exit Down Left