


Inhalt content contenu :

1x	 ↔ 220 mm P=5/8W
1x	 ↔ 280 mm ↔ 42 mm ↔ 36 mm ↔ 110 mm

LED module = 680/960 lm
DE Eisen gebürstet **EN** Brushed iron
FR Acier brossé

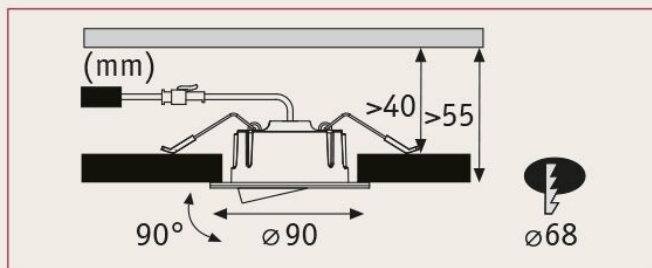


DE Lichtfarbe vor Montage wählbar
EN Select the light colour before mounting
FR Couleur de lumière réglable avant installation

white select



DE Leistungsaufnahme (W) vor der Montage wählbar
EN Power consumption (W) selectable before installation
FR Puissance (W) réglable avant montage

power select



DE CRI > 90 – natürliche & brillante Farbwiedergabe
EN CRI > 90 – natural & brilliant color rendering
FR CRI > 90 – rendu des couleurs naturel & brillant

CRI > 90












www.paulmann.com/symbols

92412



4 000870 924129 >



