




Inhalt content contenu :


1x

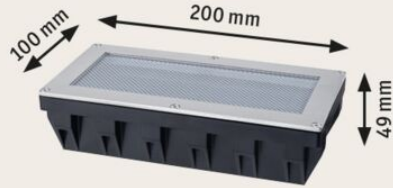

LED module = 27 lm

DE Goldlicht EN Goldlight FR Lumière dorée


incl. 2x 14500 900 mAh Li-Ion Accu

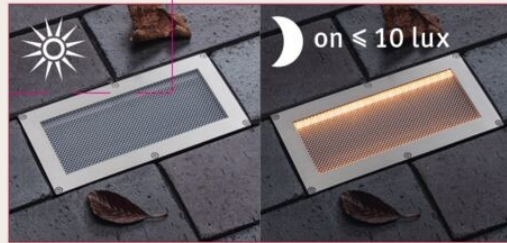

6-8 h



8-10 h

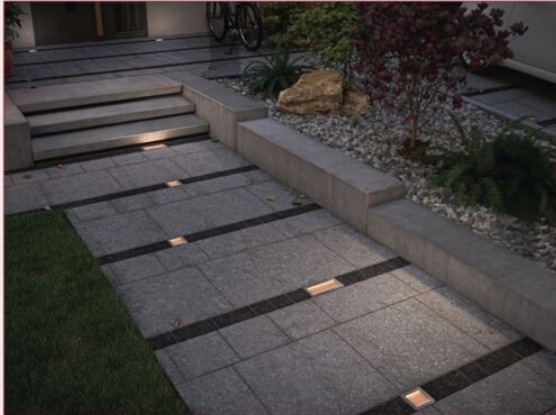

exchangeable
Accu

Insect friendly
gold light

others



gold light

warm
white

neutral white

daylight

1500 K-2700 K

2700 K-3300 K

3300 K-5200 K

> 5200 K



IP67

DE Wasserdicht bei zeitweiligem Untertauchen

EN Water proof during temporary immersion

FR Étanche à l'immersion temporaire

BE Герметичный в выпадку часового погружения в воду BG Водостойчиво при временно потапяне BS Nepromočivo kod povremenog potapanja CS Vodotěsné při dočasném ponoření DA Midlertidig vandtæt under vand EL Αβιόβροχο υπό προσωρινή βύθιση ES resistente al agua en caso de inmersión temporánea ET veekindel lühiajalisel sukeldamisel FI vesitiivis tilapäisen veteen upottamisen yhteydessä HR Nepromočivo kod povremenog potapanja HU vízálló időszaks vízbemerítés ellen IS Vatnsþétt þótt fari stundum í kaf IT Impermeabile all'immersione temporanea LT nepralaidi vandeniui trumpai nardant LV blīvs pret ūdeni īslaicīgi īgremdējot MK Водостойно при повремено потапяње NL waterdicht bij tijdelijke onderdompeling NO Vanntett ved midlertidig nedsenkning i vann PL wodoodzczelne przy chwilowym zanurzeniu PT A prova de água no caso de submersão temporária RO Etanș la apă în caz de scufundare temporară RU Герметичный при временном погружении в воду SK Vodotesné pri dočasnom potopení SL Vodotesen pri začasni potopitvi SQ rezistente ndaj ujt gjatë zhytjes së përkohshme në të SR Nepromočivo kod povremenog potapanja SV Vattentät vid tillfällig nedsänkning i vatten TR suya kısa bir süre batırıldığında su geçirmez UK Герметичний при тимчасовому зануренні у воду



500



DE Belastbar

EN Resistant

FR Résistant

BE Zedolny vytrımlıvace narušku BG Натоварване BS Opteretivo CS Zatıřitelné DA Belastbar EL Avtoxón ES Resistente ET Koormatav FI Kestää kuormitusta HR Opteretivo HU Terhelhető IS Pollir IT Caricabile LT apkrova LV Noslogojams MK За оптоварување NL Belastbaar NO Belastbarhet PL Obciążalna PT Carga RO Sarcina max. RU Способный выдерживать нагрузку SK Zatařitelné SL Obremenljivost SQ Rezistente SR Opteretivo SV Belastbarhet TR Yüklenebilir UK Здатний витримувати навантаження



rost
frei



30.000 h

IT Raccolta differenziata.
Verifica le disposizioni del
tuo Comune.



LED



incl.
Accu



95745

4 000870 957455 >