




DEHNventil modular DV M2 TNC 255 FM

DE Einbauanleitung
GB Installation instructions
IT Istruzioni di montaggio
FR Instructions de montage
NL Montagehandleiding
ES Instrucciones de montaje
PT Instruções de montagem
DK Monteringsvejledning
SE Monteringsanvisning
FI Asennusohje
GR Οδηγίες συναρμολόγησης
PL Instrukcja montażu
CZ Návod k montáži
TR Montaj kılavuzu
RU Инструкция по монтажу
CN 安装说明
HU Szerelési útmutató
JP 設置説明書




I+II+III IEC 61643-11...
1+2+3 EN 61643-11...

PZ 2 (4 Nm)

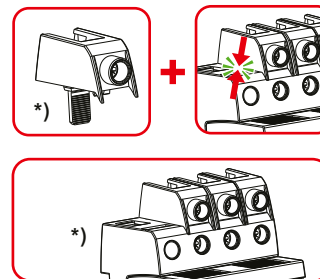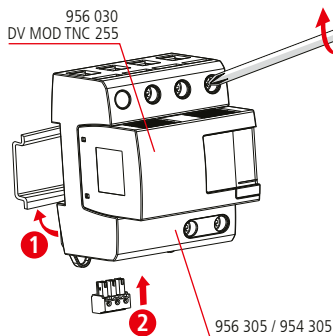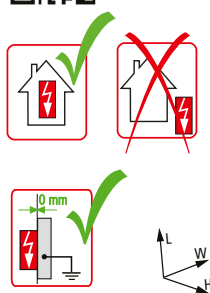


*) Optional available, **STAK25** (Part No. 952 589) for serial connection
*) Optional erhältlich, **STAK25** (Art.-Nr. 952 589) für serielle Verdrahtung

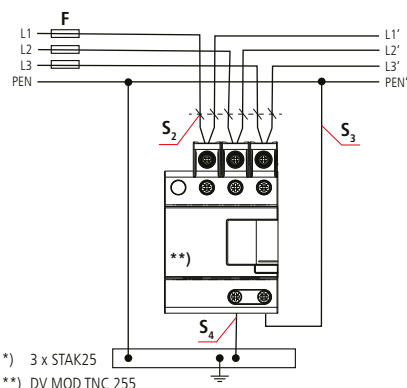1) TNC


DEHNventil modular DV M2 TNC 255 FM	
	$F \leq 100 \text{ A gG}$
	$F > 100 \text{ A gG}$


F A gG	S_2 / mm^2	S_3 / mm^2	S_4 / mm^2
25	6	16	16
35	6	16	16
40	6	16	16
50	10	16	16
63	10	16	16
80	16	16	16
100	25	16	16

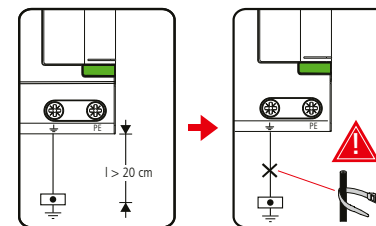

min.	6 mm ²		
max.	25 mm ² *)	35 mm ²	
	16 mm ² Cu		≥ 15.5 mm


*) 3 x STAK25

**) DV MOD TNC 255

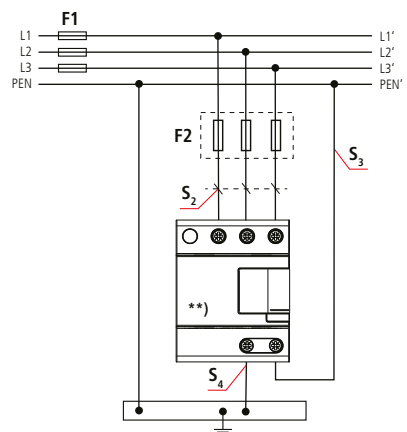2) TNC


DEHNventil modular DV M2 TNC 255 FM	
	$F1 > 250 \text{ A gG}$
	$F2 \leq 250 \text{ A gG}$
	$F1 \leq 250 \text{ A gG}$
	$F2 > 250 \text{ A gG}$

F1 A gG	S_2 / mm^2	S_3 / mm^2	S_4 / mm^2	F2 A gG
25	6	16	16	---
35	6	16	16	---
40	6	16	16	---
50	6	16	16	---
63	10	16	16	---
80	10	16	16	---
100	16	16	16	---
125	16	16	16	---
160	16	16	16	---
200	25	25	25	---
250	25	25	25	---
>250	25	25	25	250

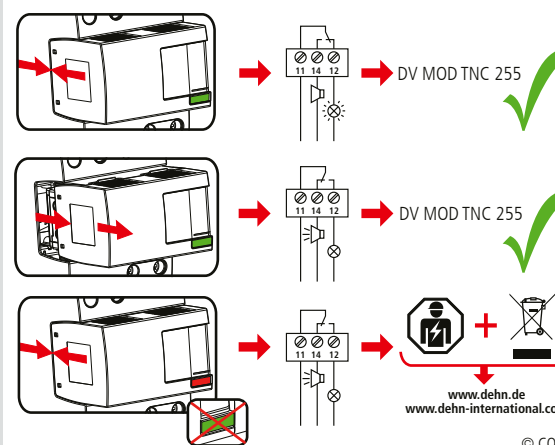

DEHNventil modular DV M2 TNC 255 FM	
	AC: 250 V / 0.5 A
	DC: 250 V / 0.1 A
	125 V / 0.2 A
	75 V / 0.5 A

**) DV MOD TNC 255

