
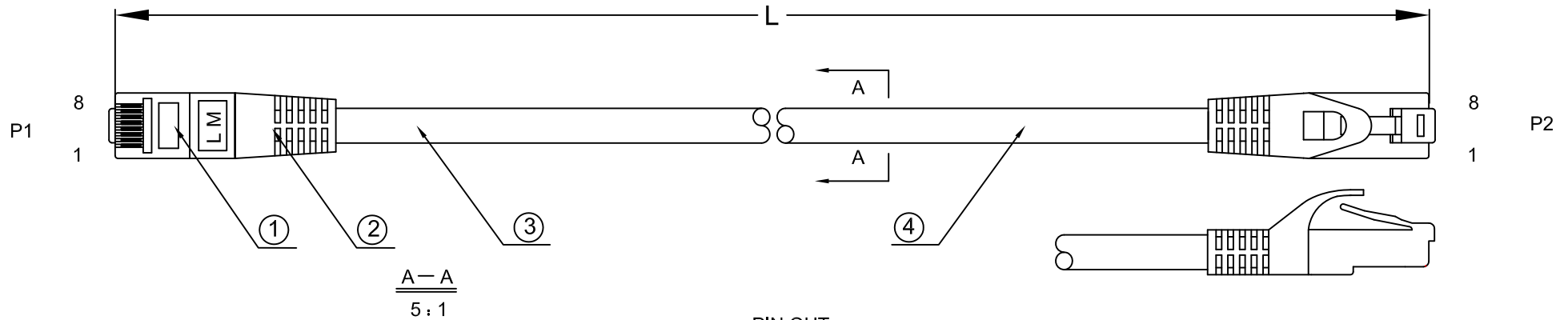


NOTE:


Raw cable:
S/FTP Cat.7 AWG26/7 stranded 4 pairs cable 600MHz.

Electrical test:
100% open short & miss wire test.
Pass Fluke test.
RoHS Compliant, REACH Compliant.

PIN OUT

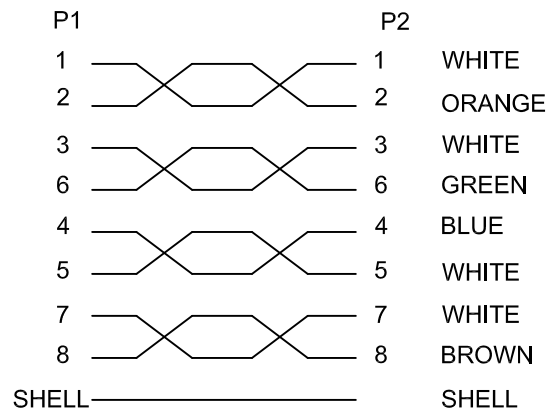

PACKING DRAW

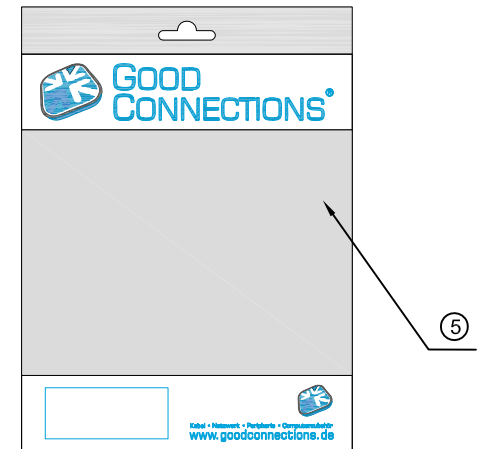

MATERIAL LIST

⑤	PACKAGE	GOOD CONNECTIONS ZIP BAG	1
④	PRINTING	Good Connections Cat.7 raw cable S/FTP 4x2xAWG26/7 PIMF 600MHz ISO/IEC 11801 & EN50173-1 TIA/EIA 568B-2.1 Halogen Free***10GIGABIT***	
③	CABLE	S/FTP CAT.7 PiMF CABLE, 4X(2X7/0.16 BC+AL)+B(16X5/0.12 AL-MG)+LSZH, OD=6.2±0.2mm	L
②	MOLD HOOD	PVC, LENGTH ON MOULDING	2
①	CONNECTOR	CAT.6A RJ45 PLUG, 500 MHz, SHIELD, 3U', COLOR: TRANSPARENT YELLOW	2
No.	PART NAME	DESCRIPTION	QTY

Good Connections®

RJ45 Patchcord with Cat. 7 raw cable, 500 MHz

DRAW No.		NAME	
CUSTOMER		MAPE	TOLERANCE
MODEL No.	8070R SERIES		X. ±1.00 X.X ±0.50
APPROVE BY	CHECK BY	DATE	SCALE
KH	GR	26.09.2017	MM
		PAGE	1/1