

LogiLink®

Monitor Mount Stand with Adjustable Arm for 13"-27" Monitor


Art. No.: BP0020



Easy installation and compatible with VESA standard max. 100x100mm

Features:

- » Super strong mounting brackets: Solid-reinforced Cold Steel, durable product with maximum capacity of 8kg
- » Maximum arm extension length is 274mm, Tilt capacity: 45°~ -45°, Swivel capacity: 90°~ -90° and Rotation capacity: 360°
- » Compatible with VESA 75x75mm, 100x100mm
- » Clamp and grommet mount included
- » Easy to install
- » Fit for 13-27 inch LCD Monitor

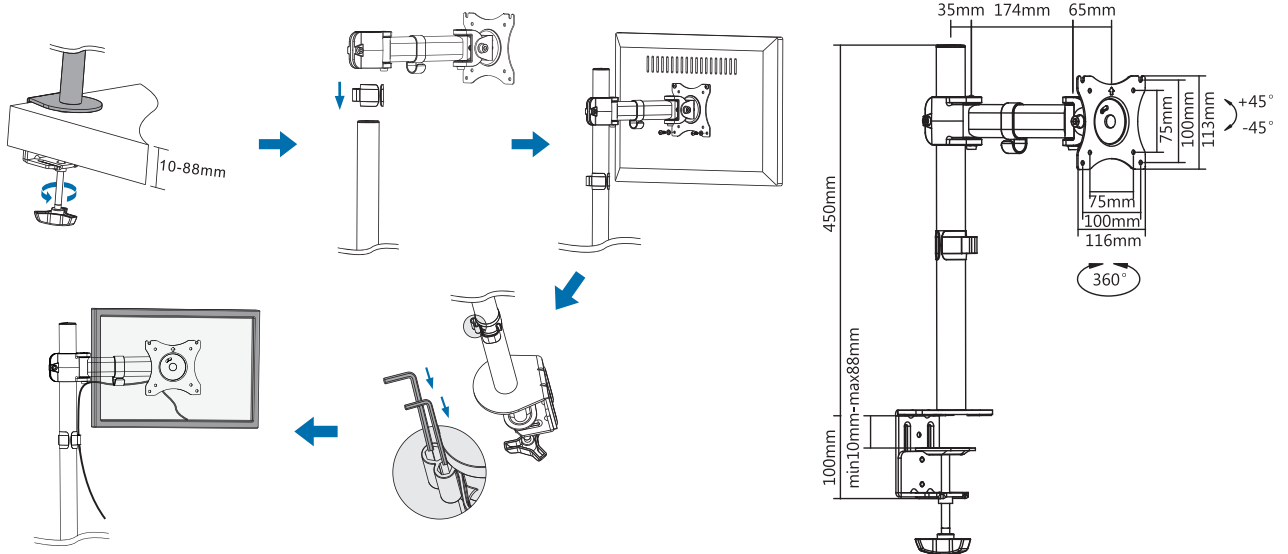

RoHS
compliant

* The specifications and pictures are subject to change without notice.
* All trade names referenced are the registered namework of their respective owners.



BP0020



4 052792 042672

Made in China

Best Connectivity

LogiLink®

Monitor Mount Stand with Adjustable Arm for 13"-27" Monitor

Art. No.: BP0020



Specification:

Screen Size	13"-27"
Rated Load	8kg/17.6lbs
VESA	75x75, 100x100
Installation	Clamp, Desk mount
Tilt	45°~ -45°
Swivel	180°
Rotate	360°
Arm Extend	274mm
Clamp Thickness	10mm-88mm
Height	450mm
Product Size	335 x 550 x 116mm

Fits
13"-27"
Monitor

VESA
Max.
100x100mm

Arm
Extend
274mm

rated
8kg/17.6lbs

360°
ROTATION

45°
-45°
TILT

180°
SWIVEL

↑
Direction
Indicator

Package Contents:

- » 1 x Monitor Mount Stand
- » 1 x Screw Package
- » 1 x User Manual

Package Informations:

- » Packing Dimension: 478 x 163 x 110mm
- » Packing Weight: 3.34kg
- » Carton Dimension: 495 x 340 x 350mm
- » Carton Q'ty: 6pcs
- » Carton Weight: 21.1kg



This product is designed to be installed on wood stud walls, solid concrete walls or brick walls. Make sure that the supporting surface will safely support the combined weight of the equipment and all attached hardware and components. This product is intended for indoor use only. Using this product outdoors could lead to product failure and personal injury.

RoHS
compliant

* The specifications and pictures are subject to change without notice.
* All trade names referenced are the registered trademark of their respective owners.



BP0020



4 052792 042672

Made in China