

ICY BOX IB-235-U3

External enclosure for
2.5" SATA HDD/SSD

Key features

- External enclosure for 2.5" SATA HDD/SSD
- Interface to PC: USB 3.0 Type-A, up to 5 Gbit/s
- HDD height up to 9.5 mm, unlimited capacity
- Toolless installation
- Compatible with Windows, macOS, Linux



Packing content

1x IB-235-U3, 1x manual


Everything on board

You know the situation, you want to connect a device but one thing is missing, the appropriate cable. With the IB-235-U3 those are moments of the past, since the USB cable is integrated into the case. The lightweight plastic housing with the simple hinged lid enables tool-free installation with a maximum hard disk height of 9.5 mm.

Technical data

Model	IB-235-U3
Article no.	60330
EAN code	4250078166535
Brand	ICY BOX
Colour	Black
Material	Plastic
HDD interface	1x SATA 2.5" HDD/SSD
Chipset	JM578

External data interface	USB 3.0 Type-A
Transfer rate	Up to 5 Gbit/s
HDD height	Up to 9.5 mm
HDD capacity	Unlimited
HotSwap	Yes
Plug & Play	Yes
Operating system	Windows, macOS, Linux
LED	Power and HDD access
Power supply	Bus power

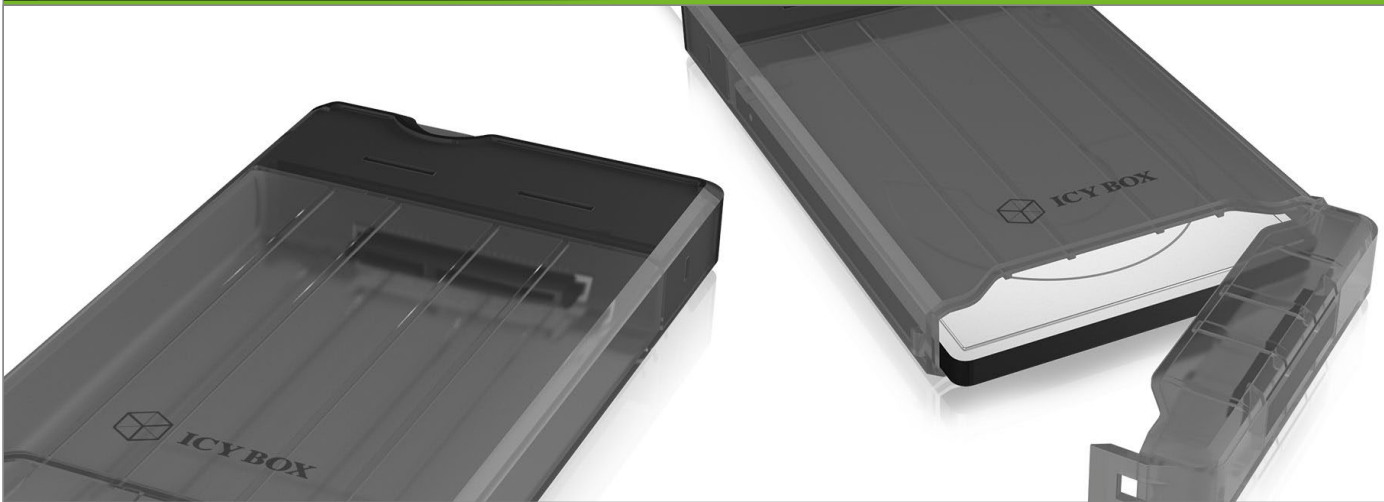

ICY BOX IB-235-U3 External enclosure for 2.5" SATA HDD/SSD



The height is crucial

HDDs and SSDs with a height of up to 9.5 mm can be accommodated in the enclosure. It's especially suitable for SSDs, since they can work even faster than the conventional HDDs.



Well thought out

Thanks to the well-thought-out design, the integrated USB cable can be hidden in the enclosure, which makes the use of an external cable unnecessary. This makes the enclosure very space-saving and it can be connected anywhere with a USB 3.0 capable device.



Well packed

This enclosure protects a hard disk or SSD of up to 9.5 mm height against shocks and dust. With the USB Type-A connection you will see fast data transfer rates almost anywhere.

Logistical data

Packing unit:	60 pcs./carton
Total weight:	8.640 kg/carton
Gross weight: (with packing):	0.132 kg
Net weight:	0.057 kg

Dimension/carton:	440x295x335 mm
Dimension (with packing):	100x25x200 mm
Dimension of article:	140x75x15 mm
Country of origin:	China

