

ProductSheet
HP Laptop 15s-eq2252ng (365C7EA)



Power through your day

Stay connected to what matters most with long-lasting battery life and a thin micro-edge bezel design. Built to keep you productive and entertained from anywhere, the HP 15.6 inch Laptop features reliable performance and an expansive display, so you can stream, surf and speed through tasks.[1]



View more, carry less

Thin, light, and designed to travel. See more of your photos, videos and projects on a 6.5 mm micro-edge bezel display.

Reliable performance

Tackle your busiest days with the performance of a reliable processor. Save more of what you love with abundant storage for all your photos, videos and documents.

Go longer, faster

Long-lasting battery life and HP Fast Charge technology lets you work, watch, and stay connected all day. Integrated precision touchpad with multi-touch support speeds up navigation and productivity.

Featuring

 Windows 10



Windows 10

Do great things confidently with the familiar feel of Windows - only better. [2]

AMD Ryzen™ 5000 U Series Mobile Processors

If juggling video conferences, web browsing, building spreadsheets, and creating presentations is the norm, then AMD Ryzen™ 5000 Series Mobile Processor-powered devices are built with you in mind.

Full HD display


Sit back and enjoy crystal-clear visuals and images with the vibrant quality of 2 million pixels. The 1920 x 1080 resolution gives all your digital content a new dimension. [3]


Anti-glare panel

Enjoy the sun and your favorite content with this anti-glare panel. Non-reflective and low gloss means you'll get less glare while you're outside.

PCIe SSD storage

Boot up in seconds with lightning fast speed with up to 256 GB PCIe SSD storage.

 1080p

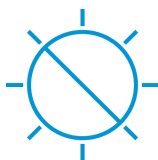

 SSD

Specifications

Operating system	Windows 10 Home 64
Product color	Jet black
Processor family	AMD Ryzen™ 5 processor
Processor	AMD Ryzen™ 5 5500U (2.1 GHz base clock, up to 4.0 GHz max boost clock, 8 MB L3 cache, 6 cores, 12 threads) ^[6,7]
Chipset	AMD Integrated SoC
Memory	8 GB DDR4-3200 MHz RAM (2 x 4 GB)
Internal Storage	256 GB PCIe® NVMe™ M.2 SSD
Product design	Mesh knit pattern with texture finish
Optical drive	Optical drive not included
Graphics	Integrated
Graphics (integrated)	AMD Radeon™ Graphics
Display	39.6 cm (15.6") diagonal, FHD (1920 x 1080), micro-edge, anti-glare, 250 nits, 45% NTSC
Display	15.6" diagonal, FHD (1920 x 1080), micro-edge, anti-glare, 250 nits, 45% NTSC
Display size (diagonal)	39.6 cm (15.6")
Display size (diagonal)	15.6"
Audio features	Dual speakers
Minimum dimensions (W x D x H)	35.85 x 24.2 x 1.79 cm <i>(Dimensions vary by configuration)</i>
Minimum dimensions (W x D x H)	14.11 x 9.53 x 0.71 in
Weight	1.69 kg <i>(Weight varies by configuration)</i>
Weight	3.75 lb
Keyboard	Full-size, jet black keyboard with numeric keypad
Pointing device	HP Imagepad with multi-touch gesture support; Precision Touchpad Support
Webcam	HP True Vision 720p HD camera with integrated dual array digital microphones
Ports	1 SuperSpeed USB Type-C® 5Gbps signaling rate; 2 SuperSpeed USB Type-A 5Gbps signaling rate; 1 HDMI 1.4b; 1 AC smart pin; 1 headphone/microphone combo
Expansion slots	1 multi-format SD media card reader
Package dimensions (W x D x H)	6.9 x 30.5 x 52 cm
Package weight	2.21 kg
Wireless	Realtek RTL8821CE-M 802.11a/b/g/n/ac (1x1) Wi-Fi® and Bluetooth® 4.2 combo
Power supply type	45 W Smart AC power adapter
Battery type	3-cell, 41 Wh Li-ion
Battery recharge time	Supports battery fast charge: approximately 50% in 45 minutes ^[5]
Battery weight	0.46 lb
Battery weight	210 g
Ecolabels	ENERGY STAR® certified; EPEAT® Silver registered
Pre-installed software	Netflix
Software included	McAfee LiveSafe™
Software - Productivity & finance	1 month trial for new Microsoft 365 customers ^[24]
Cloud service	Dropbox ^[1]
UPC number	195697829680

Top Recommended Displays, Accessories and Services

Backpacks

HP 15.6 in Value Backpack	K0B39AA
HP 15.6 in Value Topload Case	K0B38AA

Keyboard and Mouse Kits

HP Pavilion Wireless Keyboard and Mouse 800	4CE99AA
HP Pavilion Keyboard and Mouse 200	9DF28AA
HP Wired Keyboard and Mouse 160	6HD76AA

Mice

HP Wireless Mouse 220	3FV66AA
HP Wireless Mouse 200	X6W31AA

AC Adapters

HP Travel Power Adapter 65W	X7W51AA
-----------------------------	---------

Messaging Footnotes

[1] Internet service required and not included.

[2] Not all features are available in all editions or versions of Windows. Systems may require upgraded and/or separately purchased hardware, drivers, software or BIOS update to take full advantage of Windows functionality. Windows 10 is automatically updated, which is always enabled. ISP fees may apply and additional requirements may apply over time for updates. See <http://www.microsoft.com>.

[3] Full high-definition (FHD) content is required to view FHD images.

Technical Specifications Footnotes

[1] New Dropbox users are eligible to get 25 GB of Dropbox space free for 12 months from date of registration. For complete details and terms of use, including cancellation policies, visit the Dropbox website at <https://www.dropbox.com/help/space/hp-promotion>. Internet service required and not included.

[5] Recharges your battery up to 50% within 45 minutes when the system is off (using "shut down" command). Recommended for use with the HP adapter provided with the notebook, not recommended with a smaller capacity battery charger. After charging has reached 50% capacity, charging speed will return to normal speed. Charging time may vary +/-10% due to System tolerance. Available on select HP products. See <http://store.hp.com> for a full list of product features.

[6] Multi-core is designed to improve performance of certain software products. Not all customers or software applications will necessarily benefit from use of this technology. Performance and clock frequency will vary depending on application workload and your hardware and software configurations. AMD's numbering is not a measurement of clock speed.

[7] Max Boost clock frequency performance varies depending on hardware, software and overall system configuration.

[24] Must activate within 180 days of Windows activation.

© Copyright 2021 HP Development Company, L.P. The information contained herein is subject to change without notice. The only warranties for HP products and services are set forth in the express warranty statements accompanying such products and services. Nothing herein should be construed as constituting an additional warranty. HP shall not be liable for technical or editorial errors or omissions contained herein.

Intel, Core, Optane, Celeron, Pentium, Iris, XMM, and Thunderbolt are trademarks or registered trademarks of Intel Corporation or its subsidiaries in the United States and other countries. AMD, Ryzen, Athlon, and Radeon are trademarks of Advanced Micro Devices, Inc. Bluetooth is a trademark owned by its proprietor and used by HP Inc. under license. NVIDIA and GeForce are trademarks and/or registered trademarks of NVIDIA Corporation in the U.S. and other countries. USB Type-C® and USB-C® are registered trademarks of USB Implementers Forum. DisplayPort™ and the DisplayPort™ logo are trademarks owned by the Video Electronics Standards Association (VESA®) in the United States and other countries. McAfee and McAfee LiveSafe are trademarks or registered trademarks of McAfee LLC in the United States and other countries. ENERGY STAR is a registered trademark of the U.S. Environmental Protection Agency. All other trademarks are the property of their respective owners.

