

RFF 605 54/230V GY**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com



The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

Általános rendelési adatok

Típus	RFF 605 54/230V GY
Rendelési szám	2557730000
Verzió	Filter fan, 230 V, 230 V, IP54, szürke
GTIN (EAN)	4050118568370
Menny.	1 Stück

RFF 605 54/230V GY

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Műszaki adatok

Méretek és tömegek

Szélesség	436 mm	Szélesség (coll)	17,165 inch
Magasság	436 mm	Magasság (coll)	17,165 inch
Mélység	430 mm	Mélység (coll)	16,929 inch
Nettó tömeg	4 800 g		

General data

Csatlakozás típusa	Csatlakozósáv	EMC változat	No
Felszerelés típusa	Felpattintható	Filter class	G 3
Height of installation cut-outs	291 mm	Mounting depth	34 mm
Mounting height	72 mm	Noise emission	67 dB (A)
Névleges AC feszültség	230 V AC	Supply voltage, max	230 V
Supply voltage, min.	230 V	Volume flow, free-blowing	350 m ³ /h
Width of installation cut-outs	291 mm	With filter	Igen

Besorolások

ETIM 6.0	EC000320	eClass 6.2	27-18-07-16
eClass 9.1	27-18-07-16		

Jóváhagyások

Jóváhagyások



ROHS Megfelel

Letöltések


Approval/Certificate/Document of Conformity	EU Declaration of Conformity
Engineering Data	STEP

RFF 605 54/230V GY

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Rajzok

Graph

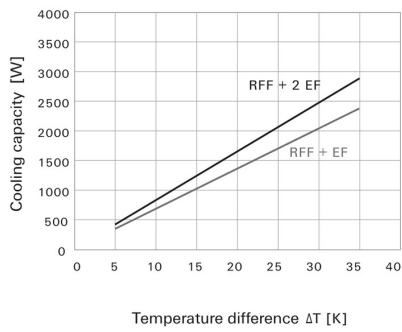

Graph

