



KERN & Sohn GmbH

Ziegelei 1
72336 Balingen-Frommern
Germany

☎ +0049-[0]7433-9933-0
FAX +0049-[0]7433-9933-149
✉ info@kern-sohn.com

Installation instructions

Tripod

KERN BFS

Type BFS A07

Version 1.2
2024-08
E



BFS_A07-IA-2412



Tripods

Version 1.2 2024-08

Installation instructions

Table of contents

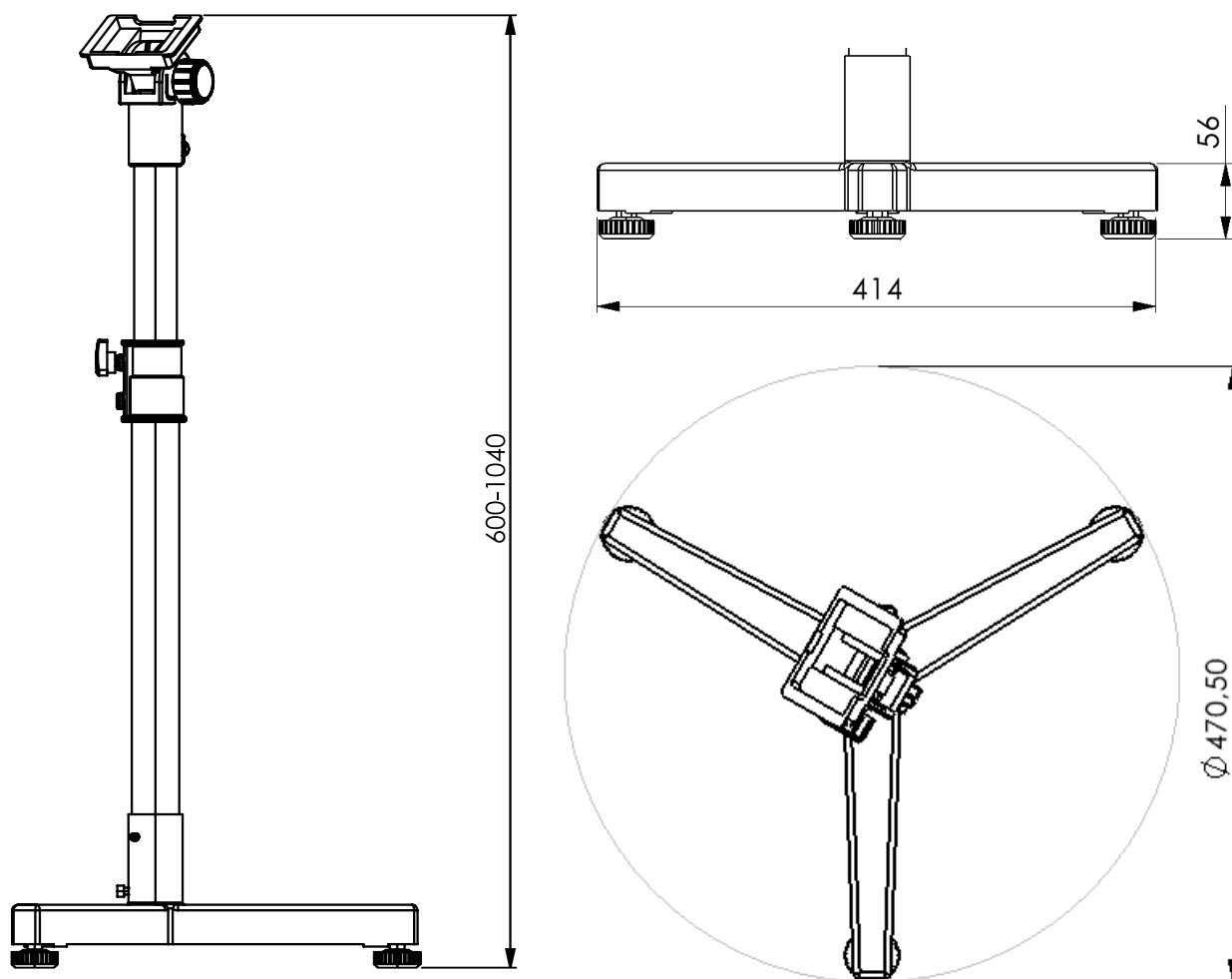
1	Technical data.....	3
1.1	Dimensions	3
2	Scope of delivery	4
3	Installation.....	6

1 Technical data





CORE	BFS-A07
Tripod height (mm)	600-1040






1.1 Dimensions

- Dimensions in mm



2 Scope of delivery

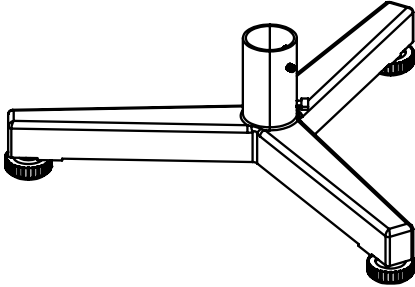 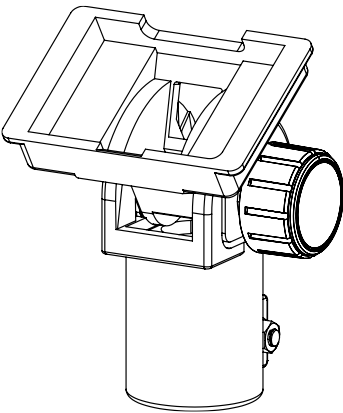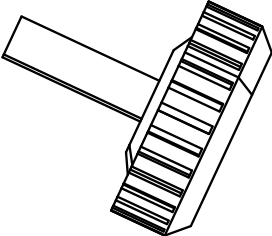
 A Tripod base 1 x	 B* Tripod tube at the bottom 1 x	 C Holder for display unit 1 x
 D* Tripod tube top 1 x	 E Display unit holder 1 x	 F Foot screws 4 x

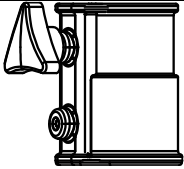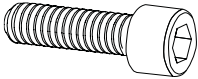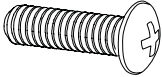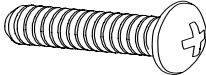  G* Pipe connector 1 x	 S1 M6 x 20 1 x	 S2 M8 nut 4 x
 S3 Washer 1 x  S7 M4 x 10 4 x	 S5 M7 x 10 1x  S8 M6 x 10 grub screw 2 x	 S6 M5 x 16 3 x

B, D and G are supplied in pre-assembled condition.


3 Installation

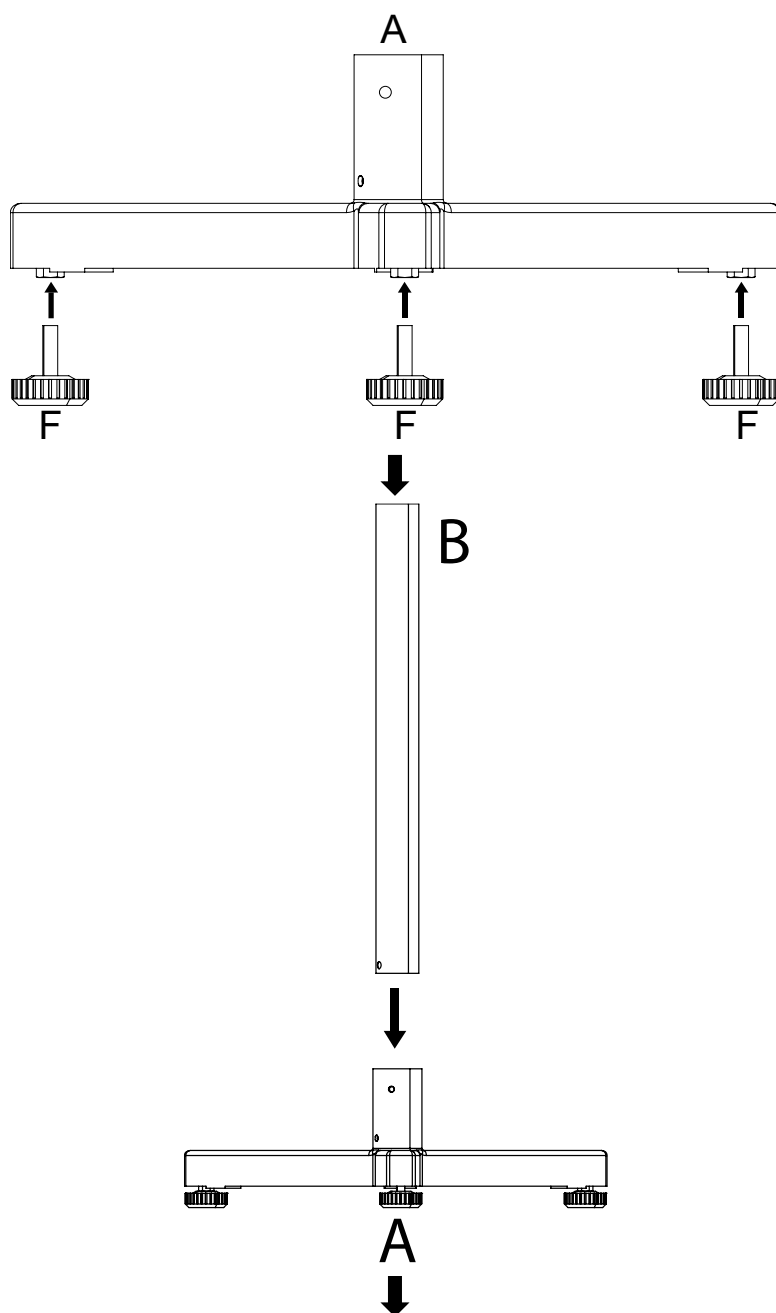Realisation:




⇒ Screw the foot screws into the tripod base

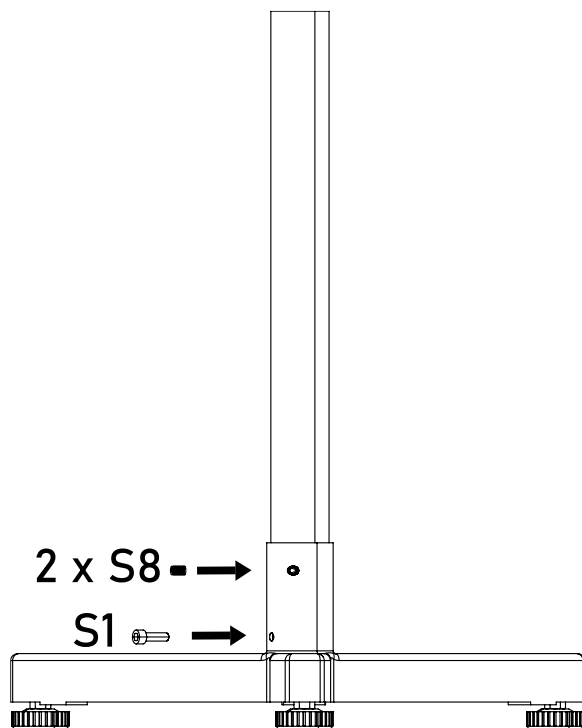
⇒ Insert the lower tube **(B)** into the stand base



⇒ Secure the pipe using the screws

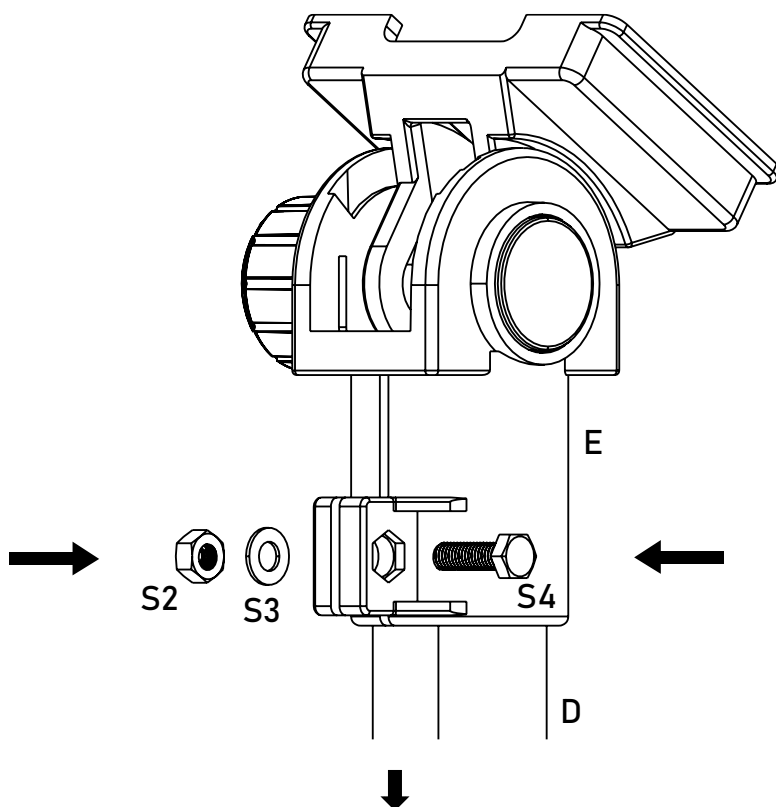

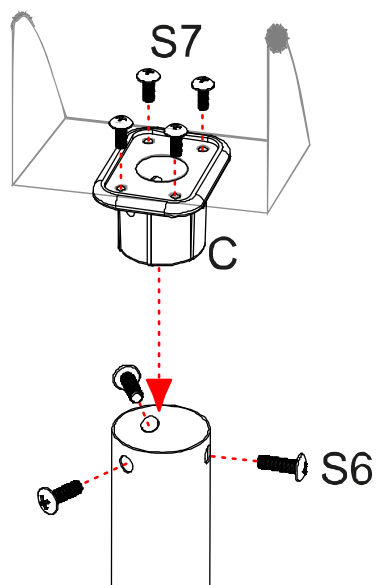⇒ Insert the holder **(E)** for the display unit into the upper end of the stand tube **(D)** and fasten with the screw **(S4)**. Lock on the opposite side with the washer **(S3)** and the nut **(S2)**



- ⇒ Insert the adapter (**C**) for the display unit into the upper end of the stand tube (**D**) and fasten with the screws (**S6**).
- ⇒ Fasten the display unit to the holder for the display unit using the screws (**S7**).