



Over 38 Million Belkin Surge Protectors in use Worldwide!

SURGEMASTER® SURGEPROTECTION

SURGE, SPIKE AND LIGHTNING SURGE PROTECTION

Power surges and lightning strikes are not the only things that can damage your home electronic equipment. Simply switching appliances on and off can create electrical imbalances that cause cumulative, permanent damage to your computers, peripherals and electronic equipment.

Our decades of research and power protection development have led us to the release of this breakthrough SurgeMaster® series. Using advanced design elements and top-quality construction as well as superior circuitry, the SurgeMaster® offers the most complete protection from power surges, AC contamination and spikes available. As the leading developer of surge protection solutions, Belkin engineers and rigorously tests all its products to ensure your equipment will be safe from harmful electrical imbalances, whatever your configuration and whichever grade you choose.

The Belkin SurgeMaster® is your premiere solution for clean, safe power and the industry's best in construction, ratings and safety standards. Over 38 million Belkin SurgeMaster® units are protecting consumer electronics worldwide!



BENEFITS:

- Earths AC power with 3-line protection through all 7 sockets
- Delivers optimal, safe AC power through a heavy-duty cable
- Safeguards your DSL, dedicated fax/modem or 2-line phone with 6-pin protection
- Protects home cinema systems with a pair of gold connectors designed to improve signal
- Protects your TV, VCR, DVD and cable modem from damaging power surges and spikes
- Creates an uncluttered workstation area free of cable-tangling mess
- Accommodates large, AC block-style plugs without covering an unused socket
- Lifetime Product Warranty

SPECIFICATIONS:

- Continuous Duty Electrical Rating: 250V/13A/50Hz/3,250W
- Maximum Energy Dissipation: 3,240 Joules
L-N: 2,160J • L-E: 540J • N-E: 540J
- Maximum Spike Current: 90,000 Amps
L-N: 60,000A • L-E: 15,000A • N-E: 15,000A
- Maximum Spike Voltage: 6,000 Volts
- Response Time: <1 Nanosecond
- EMI/RFI Noise Filtration: 150kHz~100MHz up to 75 dB Reduction

DATA RECOVERY WARRANTY

**£UNLIMITED
CONNECTED EQUIPMENT WARRANTY
LIFETIME PRODUCT WARRANTY**




This product is certified to applicable British safety standards: BS1363/A; BS5733



Part Number	Description
F9G726uk3M-GRY	7-Way SurgeProtector, TEL/RJ45, COAX protection, 3m cable

PRODUCT FEATURES

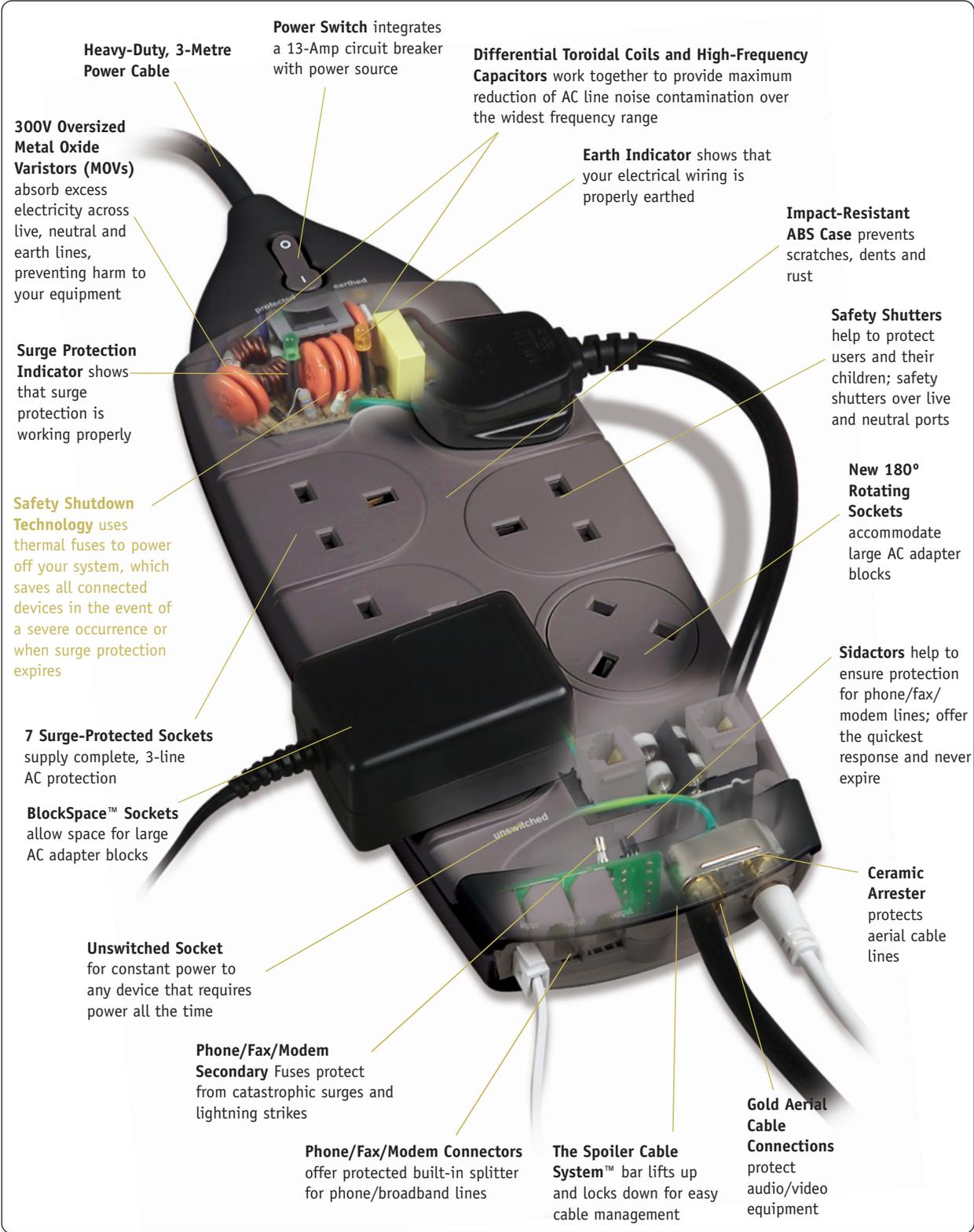

Heavy-Duty, 3-Metre Power Cable

Power Switch integrates a 13-Amp circuit breaker with power source

Differential Toroidal Coils and High-Frequency Capacitors work together to provide maximum reduction of AC line noise contamination over the widest frequency range

300V Oversized Metal Oxide Varistors (MOVs) absorb excess electricity across live, neutral and earth lines, preventing harm to your equipment

Earth Indicator shows that your electrical wiring is properly earthed

Impact-Resistant ABS Case prevents scratches, dents and rust

Surge Protection Indicator shows that surge protection is working properly

Safety Shutters help to protect users and their children; safety shutters over live and neutral ports

Safety Shutdown Technology uses thermal fuses to power off your system, which saves all connected devices in the event of a severe occurrence or when surge protection expires

New 180° Rotating Sockets accommodate large AC adapter blocks

7 Surge-Protected Sockets supply complete, 3-line AC protection

Sidactors help to ensure protection for phone/fax/modem lines; offer the quickest response and never expire

BlockSpace™ Sockets allow space for large AC adapter blocks

Ceramic Arrester protects aerial cable lines

Unswitched Socket for constant power to any device that requires power all the time

Phone/Fax/Modem Secondary Fuses protect from catastrophic surges and lightning strikes

Phone/Fax/Modem Connectors offer protected built-in splitter for phone/broadband lines

The Spoiler Cable System™ bar lifts up and locks down for easy cable management

Gold Aerial Cable Connections protect audio/video equipment