

Auxiliary current switch low power rating, 2 NO for miniature circuit breaker 5SL, 5SY, 5SP Incorporated switch 5TL1, RCBO 5SU1, FI 5SV (for 5SU1 handle coupler 5ST3805-1 is required)



Versie	
productmerknaam	SETRON
productbenaming	hulpcontact
uitvoering van het product	aanbouwbaar
elektrische levensduur (schakelcycli) / typisch	20 000

Voedingsspanning	
bedrijfsspanning	
<ul style="list-style-type: none"> • nominale waarde 	30 V
beschermingsklasse IP	IP20

Product Details	
productbestanddeel	
<ul style="list-style-type: none"> • hulpschakelaar 	Ja
productuitbreiding	hulpschakelaar

Aantal	
aantal foutsignaalshakelaars	0
aantal verbreekcontacten	0
aantal maakcontacten	2
aantal wisselcontacten	0


Aansluitingen

aansluitbare kabeldoorsnede	0,5 ... 2,5 mm ²
aanhaalmoment / bij schroefaansluiting	0,5 N·m
aard van de aansluitbare kabeldoorsnede / bij AWG-leidingen	24 ... 12

Mechanical Design

hoogte	90 mm
breedte	9 mm
diepte	70 mm
nettogewicht	67 g
• tijdens bedrijf	-25 ... +55 °C
• tijdens opslag	-40 ... +75 °C

Certificaten

General Product Approval	Declaration of Conformity	Shipping Approval	other	Railway
 UR	 VDE	 EG-Konf.	 LRS	Miscellaneous Vibration and Shock

Verdere informatie

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/nl/nl/Catalog/product?mfb=5ST3014>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/nl/ps/5ST3014>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)



http://www.automation.siemens.com/bilddb/cax_en.aspx?mfb=5ST3014

CAX-Online-Generator


<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

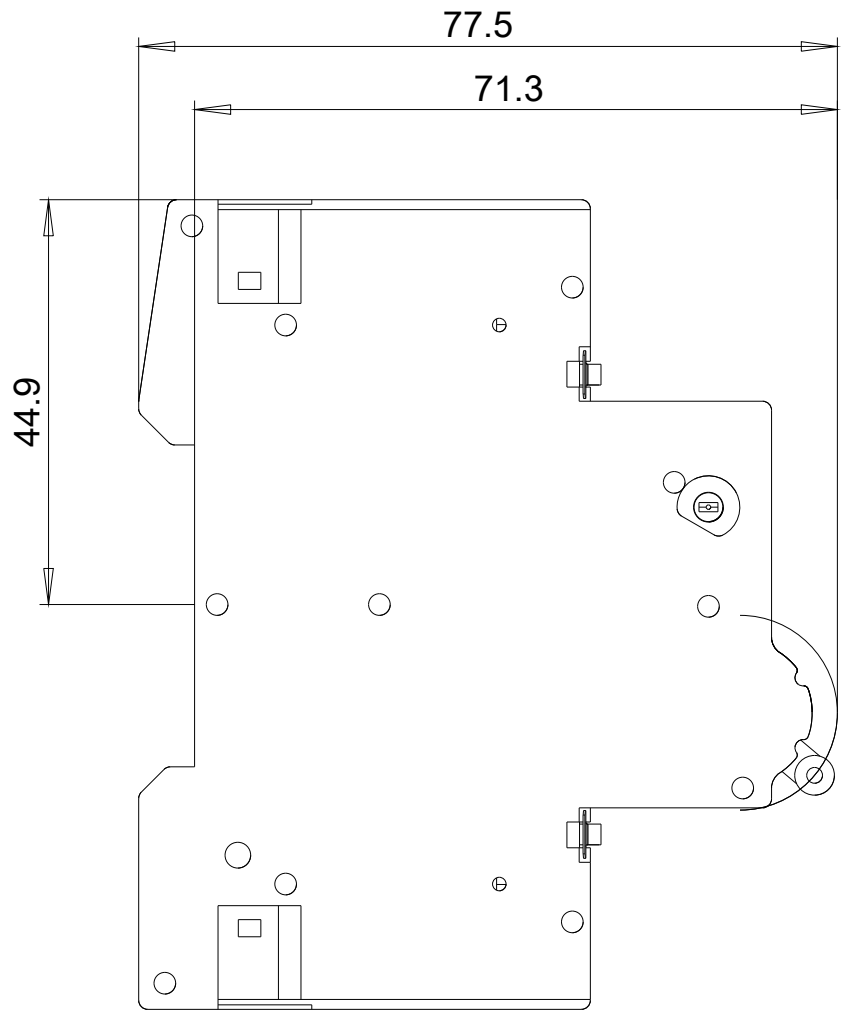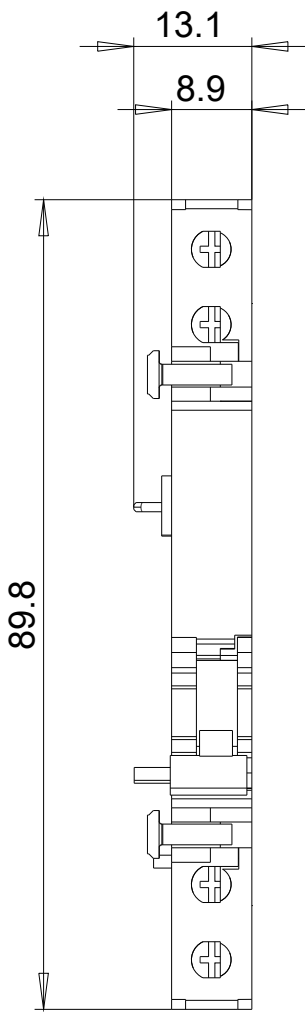

13 23

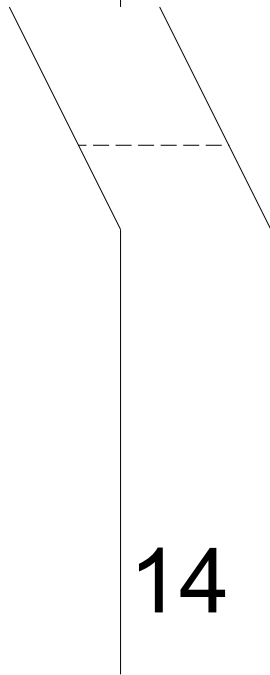

14 24

