

Fault signal contact 1 NO+1 NC, for miniature circuit breaker 5SL, 5SY, 5SP RCBO 5SU1, FI 5SV (for 5SU1 handle coupler 5ST3805-1 is required)



Versie	
productmerknaam	SETRON
productbenaming	foutsignaalschakelaar
uitvoering van het product	aanbouwbaar
elektrische levensduur (schakelcycli) / typisch	20 000
beschermingsklasse IP	IP20

Product Details	
productbestanddeel	
<ul style="list-style-type: none"> foutsignaalschakelaar 	Ja
productuitbreiding	Storingssignaalschakelaar

Aantal	
aantal foutsignaalschakelaars	1
aantal verbreekcontacten	1
aantal maakcontacten	1
aantal wisselcontacten	0






Aansluitingen	
aansluitbare kabeldoorsnede	0,5 ... 2,5 mm ²
aanhaalmoment / bij schroefaansluiting	0,5 N·m

aard van de aansluitbare kabeldoorsnede / bij AWG-leidingen	24 ... 12
---	-----------

Mechanical Design

hoogte	90 mm
breedte	9 mm
diepte	70 mm
nettogewicht	56 g
<ul style="list-style-type: none"> • tijdens bedrijf • tijdens opslag 	-25 ... +55 °C -40 ... +75 °C

Certificaten

General Product Approval	Declaration of Conformity	Test Certificates	Shipping Approval
 CCC	 UR	 VDE	 EG-Konf.
		Miscellaneous	 LRS

other	Railway
Miscellaneous	Vibration and Shock

Verdere informatie

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/nl/nl/Catalog/product?mfb=5ST3020>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/nl/ps/5ST3020>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)



http://www.automation.siemens.com/bilddb/cax_en.aspx?mfb=5ST3020

CAX-Online-Generator


<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

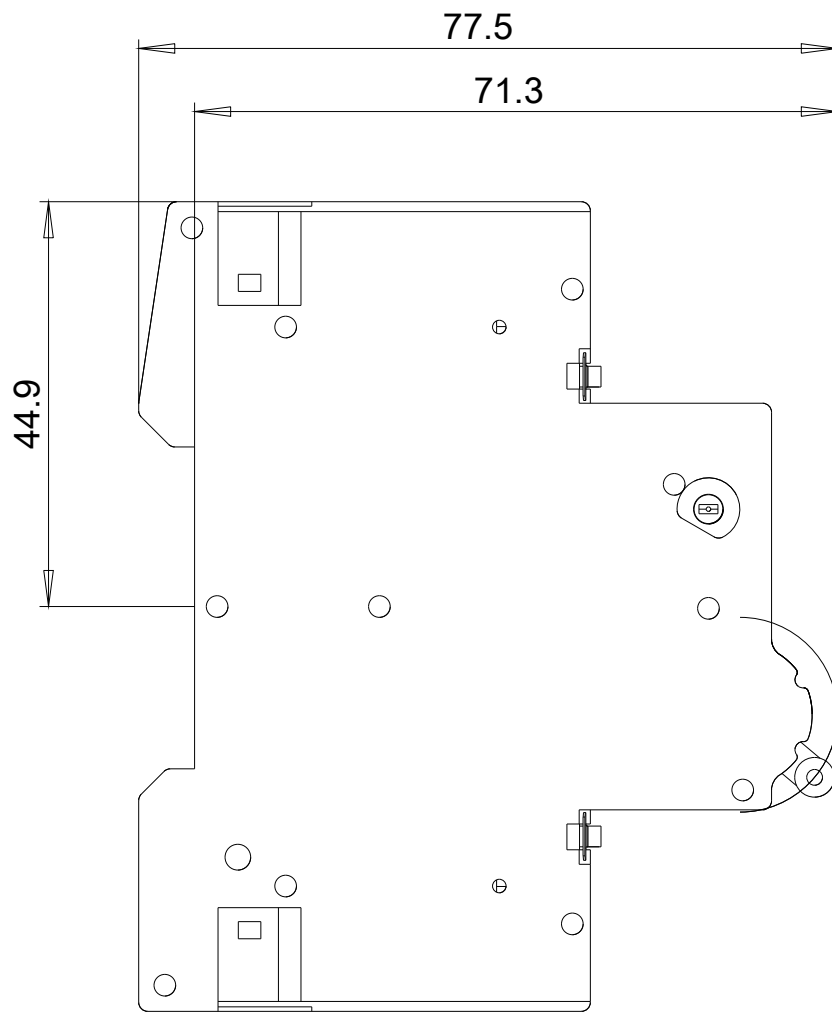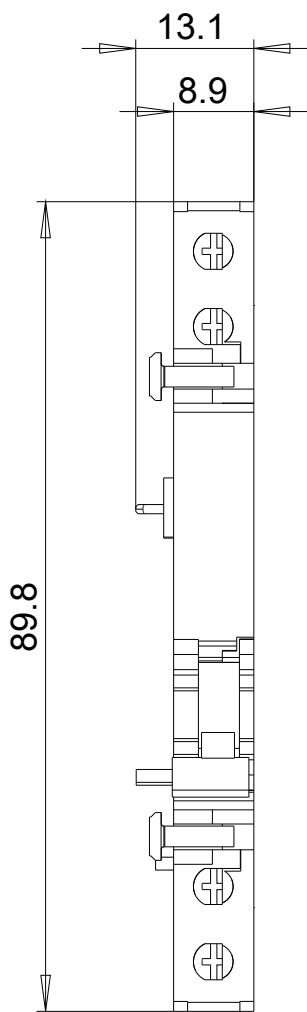

13 21

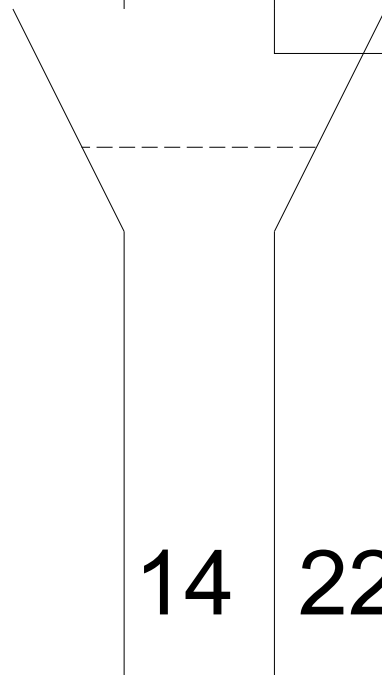

14 22

