

SETRON, cylindrical fuse holder, 10x38 mm, 2-pole, In: 32 A, Un AC: 690 V, LED signal detector



Versão	
Nome da marca do produto	SETRON
Designação do produto	Suporte de encaixe de fusível cilíndrico
Execução do produto	Sinalizador LED
Dados técnicos gerais	
Quantidade de pólos	2
Tamanho do cartucho de fusíveis	10x38 mm
Tensão de alimentação	
Corrente / com AC / valor estipulado	32 A
Tensão de serviço	690 V
• com AC / valor estipulado	
Classe de protecção IP	IP20
Projeto mecânico	
Altura	81 mm
Largura	36 mm
Profundidade	64 mm
Peso líquido	136 g

## Certificados

### Indicadores de referência

- |                              |   |
|------------------------------|---|
| • segundo a DIN EN 61346-2   | F |
| • segundo a IEC 81346-2:2009 | F |

### General Product Approval

### Declaration of Conformity



UR



EG-Konf.

## Outras informações

### Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

### Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/pt/pt/Catalog/product?mlfb=3NW7024>

### Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/pt/ps/3NW7024>

### Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)



[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=3NW7024](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NW7024)

### CAX-Online-Generator

<http://www.siemens.com/cax>

### Tender specifications

<http://www.siemens.com/specifications>

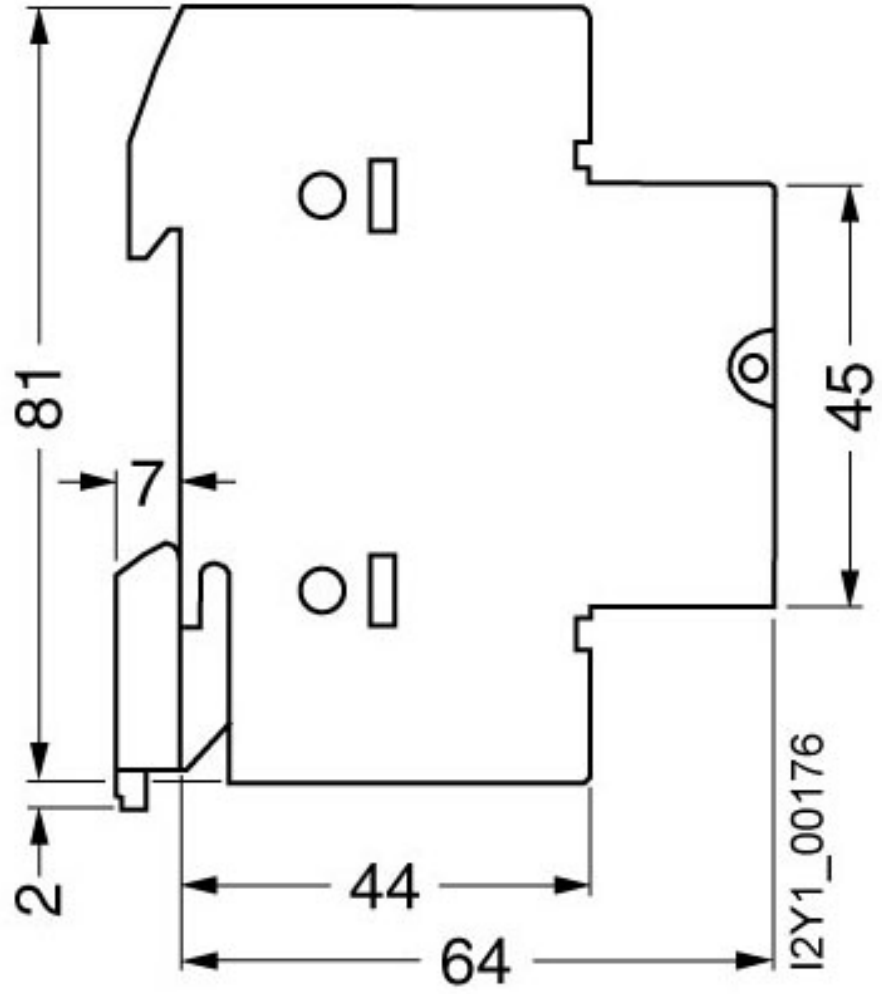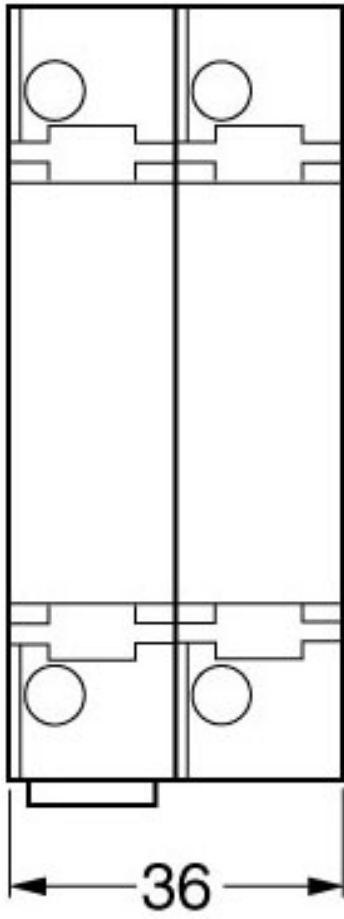

I2Y1\_00176

