

**Industriellt Ethernet  
IE-BHD-V01M-SCA**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com



Bajonett stickkontakt enligt IEC 61076-3-106 var.1  
(EtherNet/IP) i metall, tom kapsling

**Allmänna beställningsdata**

Typ	IE-BHD-V01M-SCA
Art.nr.	<a href="#">1221030000</a>
Artikelbeteckning	Tom kapsling, Flänskapsling, Variant 1 enligt IEC 61076-3-106, IP67
GTIN (EAN)	4050118003956
Frp	10 Stück

**Industriellt Ethernet  
IE-BHD-V01M-SCA**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Tekniska data****Mått och vikter**

Nettovikt	57,7 g
-----------	--------

**Temperaturer**

Driftstemperatur, max	70 °C	Driftstemperatur, min.	-40 °C
Drifttemperatur	-40 °C...70 °C	Lagertemperatur	
Installation temperature			

**Environmental Product Compliance**

REACH SVHC	Lead 7439-92-1
------------	----------------

**Allmänna data**

Färgkod	övriga	Kapslingsmaterial	Zinkpressgjutning
Monteringstyp	4 screws, Centralmutter	Skyddsklass	IP67
Stickcykler	750	Tätningmaterial	EPDM

**Normer**

KontaktDon Norm	IEC 61076-3-106 var. 1	Certifikat-Nr. (cULus)	E316369
-----------------	------------------------	------------------------	---------

**Klassificeringar**

ETIM 4.0	EC001121	ETIM 5.0	EC001121
ETIM 6.0	EC001031	eClass 6.2	27-26-12-03
eClass 7.1	27-25-05-04	eClass 8.1	19-17-01-25
eClass 9.0	27-18-27-02	eClass 9.1	27-18-27-02

**Godkännanden**

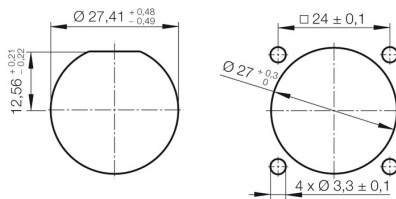
Godkännanden

**Downloads**

Användardokumentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a>
Broschyr/Katalog	<a href="#">CAT 9 IETH 15/16 EN</a> <a href="#">MB FREECONTACT EN</a> <a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a>
Godkännande/Certifikat/Dokument om överensstämmelse	<a href="#">DUXR.E316369</a>

**Industriellt Ethernet  
IE-BHD-V01M-SCA**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

**Ritningar****Montageurtag**

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws