 


**Industriellt Ethernet
IE-BS-V04P-RJ45-C**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com



PushPull stickkontaktsats enligt IEC 61076-3-106 var.4
(IEC24702) i plast, inkl. RJ45-insats

Allmänna beställningsdata

Typ	IE-BS-V04P-RJ45-C
Art.nr.	1963490000
Artikelbeteckning	Fläns RJ45, IP67, Variant 4, Koppling, Cat.6 _A / Class E _A (ISO/IEC 11801 2010)
GTIN (EAN)	4032248645589
Frp	10 Stück

**Industriellt Ethernet
IE-BS-V04P-RJ45-C**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Tekniska data**Mått och vikter**

Nettovikt	39,8 g
-----------	--------

Temperaturer

Driftstemperatur, max	70 °C	Driftstemperatur, min.	-40 °C
Drifttemperatur	-40 °C...70 °C	Lagertemperatur	
Installation temperature			

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
------------	----------------

Allmänna data

Anslutning 1	RJ45	Anslutning 2	RJ45
Artikelbeskrivning	Variant 4, Koppling	Tätningmaterial	NBR
Kapslingsmaterial		Kategori	Cat.6 _A / Class E _A (ISO/IEC 11801 2010)
Kontaktyta	PA UL 94 V0	Avskärmning	360° runtom slutet
Skyddsklass	Guld över nickel	Stickcykler	750
	IP67		

Normer

Kontaktton Norm	IEC 61076-3-106 var. 4, IEC 60603-7-5 1	Certifikat-Nr. (cULus)	E316369
-----------------	--	------------------------	---------

Klassificeringar

ETIM 3.0	EC001121	ETIM 4.0	EC000437
ETIM 5.0	EC000437	ETIM 6.0	EC001121
UNSPSC	30-21-18-17	eClass 5.1	27-26-12-03
eClass 6.2	27-26-12-03	eClass 7.1	27-25-05-04
eClass 8.1	19-17-01-25	eClass 9.0	27-44-03-90
eClass 9.1	27-44-03-90		

Godkännanden

Godkännanden



ROHS	Uppfyllelse
------	-------------

Downloads


Användardokumentation	MAN IE GUIDE DE MAN IE GUIDE EN
Broschyr/Katalog	CAT 9 IETH 15/16 EN MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN
Godkännande/Certifikat/Dokument om överensstämmelse	GOST Approval DUXR.E316369
Teknikuppgifter	WSCAD

Skapandedatum den 11 juli 2019 18:09:00 CEST

Katalogversion 07.06.2019 / Tekniska ändringar förbehållna

**Industriellt Ethernet
IE-BS-V04P-RJ45-C**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

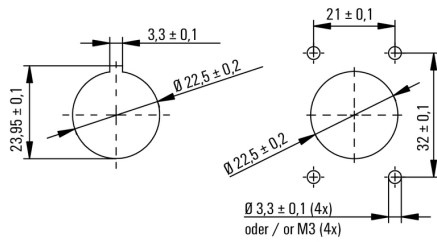Ritningar**Montageurtag**

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws