

**Industriellt Ethernet
IE-BH-V04P****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com



PushPull stickkontakt enligt IEC 61076-3-106 var.4
(IEC24702) i plast, tom kapsling

Allmänna beställningsdata

Typ	IE-BH-V04P
Art.nr.	1963520000
Artikelbeteckning	Tom kapsling, Flänskapsling, Variant 4 enligt IEC 61076-3-106, IP67
GTIN (EAN)	4032248645619
Frp	10 Stück

Industriellt Ethernet IE-BH-V04P

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Tekniska data

Mått och vikter

Nettovikt	18,2 g
-----------	--------

Temperaturer

Driftstemperatur, max	70 °C	Driftstemperatur, min.	-40 °C
Drifttemperatur	-40 °C...70 °C	Lagertemperatur	
Installation temperature			

Allmänna data

Färgkod	övriga	Kapslingsmaterial	PA UL 94 V0
Manteldiameter, max.	10 mm	Manteldiameter, min.	5 mm
Monteringstyp	4 screws, Centralmutter	Skyddsklass	IP67
Stickcykler	750	Tätningmaterial	NBR

Normer

Kontaktdon Norm	IEC 61076-3-106 var. 4	Certifikat-Nr. (cULus)	E316369
-----------------	------------------------	------------------------	---------

Klassificeringar

ETIM 3.0	EC001121	ETIM 4.0	EC001121
ETIM 5.0	EC001121	ETIM 6.0	EC001031
UNSPSC	30-21-18-17	eClass 5.1	27-26-12-03
eClass 6.2	27-25-05-04	eClass 7.1	27-25-05-04
eClass 8.1	19-17-01-25	eClass 9.0	27-18-27-02
eClass 9.1	27-18-27-02		

Godkännanden

Godkännanden



ROHS	Uppfyllelse
------	-------------

Downloads


Användardokumentation	MAN IE GUIDE DE MAN IE GUIDE EN
Broschyr/Katalog	CAT 9 IETH 15/16 EN MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN
Godkännande/Certifikat/Dokument om överensstämmelse	GOST Approval DUXR.E316369

Industriellt Ethernet IE-BH-V04P

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Ritningar

Montageurtag

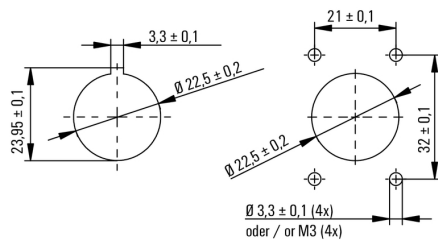

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws