

**Industriellt Ethernet
IE-TO-SCD-MM****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com



Bärskenutgångar, utförande koppling SC-Duplex enligt
IEC 61754-4

Allmänna beställningsdata

Typ	IE-TO-SCD-MM
Art.nr.	8946970000
Artikelbeteckning	Montageskena-utgång FO, SC-Duplex, Multimode, POF, IP20
GTIN (EAN)	4032248734979
Frp	10 Stück

**Industriellt Ethernet
IE-TO-SCD-MM****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Tekniska data**Mått och vikter**

Längd	59,6 mm	Bygglängd (tum)	2,346 inch
Bredd	17,5 mm	Byggbredd (tum)	0,689 inch
Djup	67 mm	Byggdjup (tum)	2,638 inch
Nettovikt	40,2 g		

Temperaturer

Driftstemperatur, max	70 °C	Driftstemperatur, min.	-40 °C
Drifttemperatur	-40 °C...70 °C	Lagertemperatur	
Temperaturområde Montage, min.	-25 °C	Installation temperature	
Temperaturområde Montage, max.	70 °C		

Allmänna data

Anslutning 1	SC-Duplex	Anslutning 2	SC-Duplex
Dämpning	≤ 0,4 dB	Fibertyp	Multimode, POF
Färgkod	ljusgrå	Kapslingsmaterial	PA UL 94 V0
Monteringstyp	TS 35	Skyddsklass	IP20
Stickcykler	1000		

Normer

Kontaktidon Norm	IEC 61754-4	Certifikat nr. (UL)	E477798
------------------	-------------	---------------------	---------

Klassificeringar

ETIM 3.0	EC000018	ETIM 4.0	EC000018
ETIM 5.0	EC000018	ETIM 6.0	EC000313
UNSPSC	30-21-18-01	eClass 6.2	27-25-05-04
eClass 7.1	27-25-05-04	eClass 8.1	19-17-01-25
eClass 9.0	27-44-03-20	eClass 9.1	19-17-01-25

Godkännanden

Godkännanden



ROHS Uppfyllelse

Downloads

Användardokumentation	MAN IE GUIDE DE MAN IE GUIDE EN
Broschyr/Katalog	CAT 9 IETH 15/16 EN FL FIELDWIRING EN PI PROFINET CABLING EN
Teknikuppgifter	EPLAN, WSCAD, Zuken E3.S

**Industriellt Ethernet
IE-TO-SCD-MM****Weidmüller Interface GmbH & Co. KG**

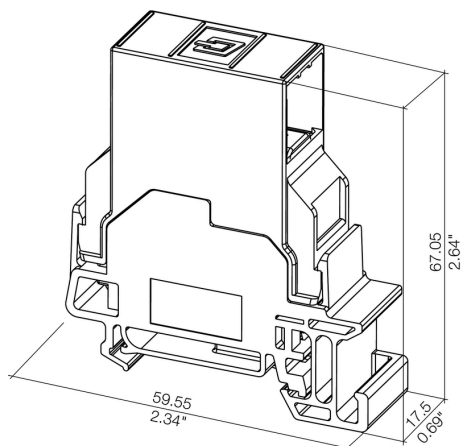
Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com**Ritningar****Profilritning****Ritning**